

IE-OP-V01P-1S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Junction box, design for bayonet plug-in connectors ver.1
according to IEC 61076-3-106, plastic

General ordering data

Version	Wall-mounted junction box, IP67, Variant 1 to IEC 61076-3-106
Order No.	1061830000
Type	IE-OP-V01P-1S
GTIN (EAN)	4032248811182
Qty.	10 pc(s).

IE-OP-V01P-1S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	114 mm	Depth (inches)	4.488 inch
Height	65.2 mm	Height (inches)	2.567 inch
Width	41.8 mm	Width (inches)	1.646 inch
Net weight	74 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	black	Housing main material	PA UL 94 V0
Plugging cycles	750	Protection degree	IP67
Type of mounting	Floor-mounted, for exposed connections, Wall mounting	UL 94 flammability rating	V-0

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-03-92
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-OP-V01P-1S

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

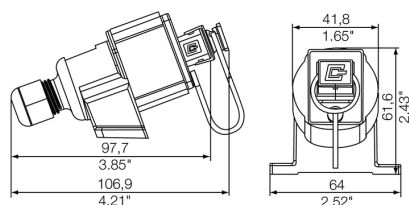

IE-OP-V01P-1S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****RJ45**

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

General ordering data

Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	

Sets - RJ45

Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (Ethernet/IP), RJ45 plastic insert incl.
RJ45 insert

General ordering data

Type	IE-PS-V01P-RJ45-FH	Version
Order No.	1012490000	RJ45 plug, no tools required, Variant 1 plastic, Cat.6 _A / Class E _A (ISO/
GTIN (EAN)	4032248720132	IEC 11801 2010)
Qty.	10 pc(s).	