

**SCM-I QV S****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Cross-connection for the sockets in the D-SERIES DRM.

**General ordering data**

Version	RIDERSERIES RCM, Cross-connector
Order No.	<a href="#">1132080000</a>
Type	SCM-I QV S
GTIN (EAN)	4032248912193
Qty.	10 pc(s).

**SCM-I QV S****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Net weight	6.5 g
------------	-------

**Temperatures**

Storage temperature	-40 °C...85 °C	Operating temperature	-45 °C...70 °C
---------------------	----------------	-----------------------	----------------

**Cross-connection data**

Rated current	12 A	Insulation	Yes
Touch-safe protection	Yes	Colour	white
Number of cross-connected terminals	6	Pitch in mm (P)	27 mm
Version	can be cut to length		

**General data**

Version	can be cut to length	Colour	white
---------	----------------------	--------	-------

**Connection data**

Pitch in mm (P)	27 mm
-----------------	-------

**Classifications**

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ECLASS 9.1	27-37-16-92	ECLASS 10.0	27-37-16-92
ECLASS 11.0	27-37-16-92	ECLASS 12.0	27-37-16-92
ECLASS 13.0	27-37-16-92		

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

## SCM-I QV S


**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Example of use

#### How to install cross connection

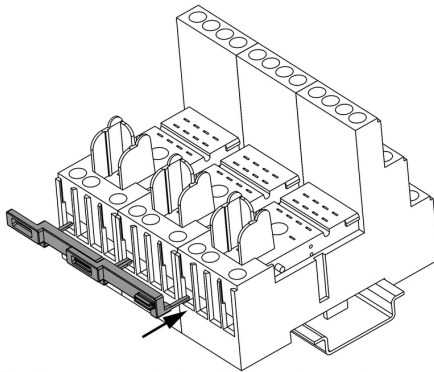

Plug the cross connection into wire-connection opening  
and fix it with tighten the screw  
Plug the cross-connection in the cable connections

### Example of use

