

SRD ECO 3CO**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image

Relay sockets for the D-SERIES DRR relays

- 2 or 3 CO contacts
- Screw connection

General ordering data

| | |
|------------|---|
| Version | D-SERIES DRR, Relay socket, Number of contacts: 3, CO contact, Continuous current: 12 A, Screw connection |
| Order No. | 1132820000 |
| Type | SRD ECO 3CO |
| GTIN (EAN) | 4032248952670 |
| Qty. | 10 pc(s). |

SRD ECO 3CO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|---------|-----------------|------------|
| Depth | 27 mm | Depth (inches) | 1.063 inch |
| Height | 76.7 mm | Height (inches) | 3.02 inch |
| Width | 38 mm | Width (inches) | 1.496 inch |
| Net weight | 60.2 g | | |

Temperatures

| | | | |
|---------------------|--|-----------------------|----------------|
| Storage temperature | -40 °C...85 °C | Operating temperature | -40 °C...65 °C |
| Humidity | 35...85 % rel. humidity, no condensation | | |

Rated data UL

| | |
|-------------------------|---------|
| Certificate No. (cURus) | E355547 |
|-------------------------|---------|

Load side

| | | | |
|----------------------------|----------|--------------------|--------------|
| Rated switching voltage | 250 V AC | Continuous current | 12 A |
| Max. switching voltage, AC | 300 V | Contact type | 3 CO contact |

General data

| | | | |
|------------------------------------|--------------------------|----------------|--|
| Rail | TS 35 | | |
| Colour | black | | |
| UL94 flammability rating component | Component | Housing | |
| | UL94 flammability rating | V-2 | |
| | Component | Mounting foot | |
| | UL94 flammability rating | HB | |
| | Component | Retaining clip | |
| | UL94 flammability rating | HB | |

Insulation coordination

| | | | |
|---|--------------------------------|--|--------------------------------|
| Pollution severity | 2 | Surge voltage category | III |
| Clearance and creepage distances for control side - load side | ≥ 4 mm | Dielectric strength for control side - load side | 2.5 kV _{eff} / 1 Min. |
| Dielectric strength of neighbouring contacts | 2.21 kV _{eff} / 1 min | Impulse withstand voltage | 4.8 kV (1.2/50 µs) |
| Protection degree | IP20 | | |

Further details of approvals / standards

| | |
|-------------------------|---------|
| Certificate No. (cURus) | E355547 |
|-------------------------|---------|

SRD ECO 3CO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Connection data

| | | | |
|---|---------------------|---|---------------------|
| Wire connection method | Screw connection | Stripping length, rated connection | 7 mm |
| Tightening torque, min. | 0.5 Nm | Tightening torque, max. | 1 Nm |
| Clamping range, min. | 0.5 mm ² | Clamping range, max. | 2.5 mm ² |
| Wire cross-section, solid, min. | 0.5 mm ² | Wire cross-section, solid, max. | 2.5 mm ² |
| Wire connection cross section, finely stranded, min. | 0.5 mm ² | Wire connection cross section, finely stranded, max. | 2.5 mm ² |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.5 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 2.5 mm ² |
| Conductor cross-section, flexible, AEH (DIN 46228-1), min. | 0.5 mm ² | Conductor cross-section, flexible, AEH (DIN 46228-1), max. | 2.5 mm ² |
| Wire connection cross section, finely stranded, two clampable wires, min. | 0.5 mm ² | Wire cross-section, finely stranded, two clampable wires, max. | 1 mm ² |
| Blade size | size PH1 | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001456 | ETIM 7.0 | EC001456 |
| ETIM 8.0 | EC001456 | ETIM 9.0 | EC001456 |
| ECLASS 9.0 | 27-37-16-03 | ECLASS 9.1 | 27-37-16-03 |
| ECLASS 10.0 | 27-37-16-03 | ECLASS 11.0 | 27-37-16-03 |
| ECLASS 12.0 | 27-37-16-03 | ECLASS 13.0 | 27-37-16-03 |

Important note

| | |
|---------------------|---|
| Product information | For this socket, a cross connection is not available. |
| | For this socket, markers are not available. |

Approvals

Approvals



| | |
|-------------------------|------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate No. (cURus) | E355547 |

Downloads

| | |
|---|---|
| Approval/Certificate/Document of Conformity | EU Konformitätserklärung / EU Declaration of Conformity |
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |
| Brochures | |


SRD ECO 3CO

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensional drawing

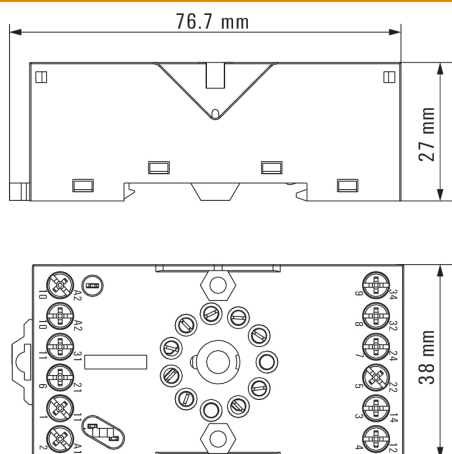

Dimensional drawing

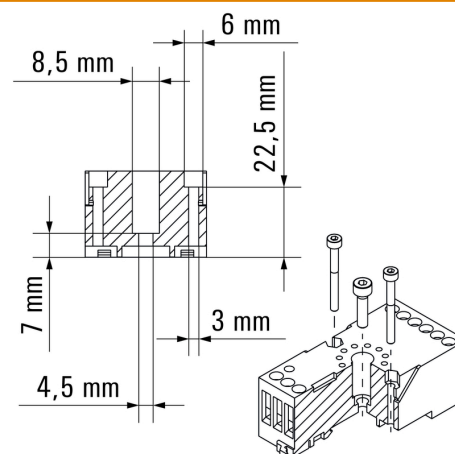

SRD ECO 3CO**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Retaining clips**

Retaining clip for D-SERIES DRR relays

- Metal retaining clip

General ordering data

| | | |
|------------|----------------------------|------------------------------|
| Type | DRR CLIP M | Version |
| Order No. | 1134160000 | D-SERIES DRR, Retaining clip |
| GTIN (EAN) | 4032248953479 | |
| Qty. | 10 pc(s). | |

Crosshead screwdriver, Phillips

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SDIK SLIM PH1 X 80 | Version |
| Order No. | 2749650000 | Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): 1 |
| GTIN (EAN) | 4050118896398 | |
| Qty. | 1 pc(s). | |

SRD ECO 3CO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Protection modules



Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With free-wheeling diode or RC filter

General ordering data

| | | |
|------------|----------------------------|---|
| Type | RIM 5 6/230VDC | Version |
| Order No. | 1174650000 | D-SERIES, Free-wheeling diode, Rated control voltage: 6...230 V DC, |
| GTIN (EAN) | 4032248971305 | Plug-in connection |
| Qty. | 10 pc(s). | |
| Type | RIM 5 6/230VAC | Version |
| Order No. | 1174670000 | D-SERIES, RC filter, Rated control voltage: 6...230 V AC, Plug-in |
| GTIN (EAN) | 4032248971312 | connection |
| Qty. | 10 pc(s). | |

Crosshead screwdriver Phillips



Crosshead screwdriver, Phillips, SDK PH DIN 5262, ISO 8764/2-PH, output to ISO 8764-PH, ChromTop tip, SoftFinish grip

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SDK PH1 X 80 | Version |
| Order No. | 2749410000 | Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): |
| GTIN (EAN) | 4050118895636 | |
| Qty. | 1 pc(s). | |

SRD ECO 3CO**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Crosshead screwdriver Phillips**

VDE insulated crosshead screwdriver, for Phillips screws, SDIK PH DIN 7438, ISO 8764/2-PH, output to ISO 8764-PH, SoftFinish grip

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SDIK PH1 X 80 | Version |
| Order No. | 2749890000 | Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): 1 |
| GTIN (EAN) | 4050118897098 | |
| Qty. | 1 pc(s). | |