

**IE-BIC-HYB-P-0,2-300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

**General ordering data**

Version	Crimp contact, for flange insert, Hybrid
Order No.	<a href="#">1135160000</a>
Type	IE-BIC-HYB-P-0,2-300
GTIN (EAN)	4032248915477
Qty.	300 pc(s).

**IE-BIC-HYB-P-0,2-300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Net weight	0.29 g
------------	--------

**General data**

Wire connection cross section, finely stranded, max.	0.2 mm <sup>2</sup>	Wire connection cross section, finely stranded, min.	0.08 mm <sup>2</sup>
--	---------------------	--	----------------------

**Electrical properties**

Rated voltage	24 V
---------------	------

**Classifications**

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-09-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
------------	----------------

**Important note**

Product information	Hybrid, 10-pole. Inserts for plug-in connectors Variant 14
---------------------	--

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-BIC-HYB-P-0,2-300

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Dimensioned drawing

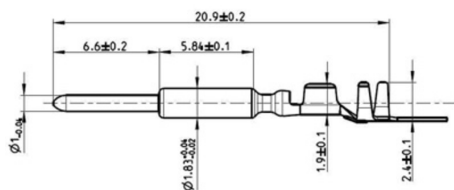

**IE-BIC-HYB-P-0,2-300****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Crimping tools****Crimping tools for Weidmüller contacts for RSV and DSTV-HD systems**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With end stop for exact positioning of the contacts

**General ordering data**

Type	HTF HYB	Version
Order No.	<a href="#">1119580000</a>	Pressing tool, Crimping tool for contacts, 0.08mm <sup>2</sup> , 1mm <sup>2</sup> ,
GTIN (EAN)	4032248900626	FoderBcrimp
Qty.	1 pc(s).	