

ZQV 1.5N/R6.4/10 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image****General ordering data**

Version	TERMSERIES, Cross-connector
Order No.	1193680000
Type	ZQV 1.5N/R6.4/10 GE
GTIN (EAN)	4032248976454
Qty.	10 pc(s).
Delivery status	This article will no longer be available in the future.
Available until	2021-06-30
Alternative product	2556360000

ZQV 1.5N/R6.4/10 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	4.9 mm	Depth (inches)	0.193 inch
Height	13.1 mm	Height (inches)	0.516 inch
Width	61 mm	Width (inches)	2.402 inch
Net weight	3.54 g		

Temperatures

Storage temperature	-40 °C...85 °C	Operating temperature	-40 °C...60 °C
---------------------	----------------	-----------------------	----------------

Rated data UL

Rated current (UL)	10 A
--------------------	------

General data

Version	can be cut to length	Colour	yellow
---------	----------------------	--------	--------

Insulation coordination

Rated voltage	250 V
---------------	-------

Connection data

Pitch in mm (P)	6.4 mm
-----------------	--------

Classifications

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ECLASS 9.1	27-37-16-92	ECLASS 10.0	27-37-16-92
ECLASS 11.0	27-37-16-92	ECLASS 12.0	27-37-16-92
ECLASS 13.0	27-37-16-92		

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
User Documentation	Beipackzettel / Package Insert - multilingual
Catalogues	Catalogues in PDF-format
Brochures	

ZQV 1.5N/R6.4/10 GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Drawings

Dimensional drawing

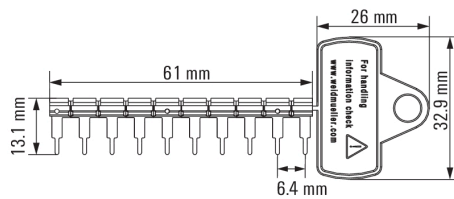

ZQV 1.5N/R6.4/10 GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cutting and notching tools for cross-connections



- for Weidmüller Z-Series cross-connections
- for cross-connections from WQV 2.5 to WQV 35
- for cross-connection window of the terminal WSI 6

General ordering data

Type	KT ZQV	Version
Order No.	9002170000	Cutting tool for one-hand operation
GTIN (EAN)	4032248291670	
Qty.	1 pc(s).	
Type	WAW 1 NEUTRAL	Version
Order No.	9004500000	Miscellaneous tools
GTIN (EAN)	4008190053925	
Qty.	1 pc(s).	

Cutting tools



Cutting tools for conductors up to 8 mm, 12 mm, 14 mm and 22 mm outside diameter. The special blade geometry allows pinch-free cutting of copper and aluminium conductors with minimum physical effort. The cutting tools (KT 8 to KT 22) also come with VDE and GS-tested protective insulation up to 1,000 V in accordance with EN/IEC 60900.

General ordering data

Type	KT 14	Version
Order No.	1157820000	Cutting tools, Cutting tool for one-hand operation
GTIN (EAN)	4032248945344	
Qty.	1 pc(s).	