

**HDC 24B ABU****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp not replaceable, Standard
Order No.	<a href="#">1212400000</a>
Type	HDC 24B ABU
GTIN (EAN)	4008190083939
Qty.	1 pc(s).

## HDC 24B ABU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Height	29.3 mm	Height (inches)	1.154 inch
Width	55 mm	Width (inches)	2.165 inch
Mounting dimension - height	32 mm	Mounting dimension - width	130 mm
Net weight	174 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Height of base B1	5.3 mm	Height of housing B	30 mm
Hole pitch length A2	130 mm	Total length housing	120 mm
Width base C1	47 mm	Width housing C	43 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection degree	IP65 (in plugged condition)
Surface finish	Powder coating		

## Version

BG	8	Clamp version	Side-locking clamp
Colour (RAL)	RAL 7035	Design	Standard
Design of housing		Design of locking system	Side-locking clamp on lower side, Side-locking clamp not replaceable
	Bulkhead housing		
Sealing	NBR	Size	8
Suitable for ModuPlug®	Yes	Top part/bottom part/lid	lower part
Type	Bulkhead (feed-through)		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant

Creation date April 29, 2024 9:46:09 AM CEST

## HDC 24B ABU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 Potassium perfluorobutane sulfonate 29420-49-3
SCIP	e98b2b24-ba23-41bf-8d19-Odda3647412f
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@393ac356 de.myview.objectmodel.impl.BlockImpl@2c8db6f de.myview.objectmodel.impl.BlockImpl@5797315 de.myview.objectmodel.impl.BlockImpl@39e8700e de.myview.objectmodel.impl.BlockImpl@56a72416 de.myview.objectmodel.impl.BlockImpl@12709e0e de.myview.objectmodel.impl.BlockImpl@5cdfb68e de.myview.objectmodel.impl.BlockImpl@26cdc51b de.myview.objectmodel.impl.BlockImpl@4925c240 de.myview.objectmodel.impl.BlockImpl@5fb3b584 de.myview.objectmodel.impl.BlockImpl@7ef9033a de.myview.objectmodel.impl.BlockImpl@36d4e4e3 de.myview.objectmodel.impl.BlockImpl@510417bb

## Important note

Product information	When mounting the housings, make sure that the flat gasket is correctly seated.
---------------------	---

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

## HDC 24B ABU

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Downloads

Approval/Certificate/Document of Con-  
formity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Engineering Data

[Zuken E3.S](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)  
[20220214 Technische Änderung bei HDC-Gehäusen](#)

Technical Documentation

[1212400000\\_HDC\\_24B\\_ABU\\_STP\\_Blatt\\_\\_1.pdf](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures


[FL FIELDWIRING EN](#)  
[FL FIELDWIRING EN](#)

## HDC 24B ABU

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

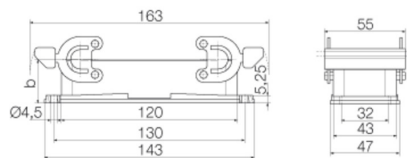

## HDC 24B ABU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Cover



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B DODQ 4BO	Version
Order No.	<a href="#">1665630000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for lower part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4008190422653	
Qty.	1 pc(s).	

## Hood, Cable Entry at top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 64D TOBU 1M40G	Version
Order No.	<a href="#">1045560000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 40
GTIN (EAN)	4032248780532	
Qty.	1 pc(s).	
Type	HDC 64D TOBU 2M32G	Version
Order No.	<a href="#">1009710000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248771394	
Qty.	1 pc(s).	

## HDC 24B ABU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 24B TOBU 1PG29G	Version
Order No.	<a href="#">1661380000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190417932	
Qty.	1 pc(s).	
Type	HDC 64D TOBU 1M32G	Version
Order No.	<a href="#">1786830000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204076	
Qty.	1 pc(s).	
Type	HDC 24B TOBU 1M40G	Version
Order No.	<a href="#">1902980000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 40
GTIN (EAN)	4032248585274	
Qty.	1 pc(s).	
Type	HDC 64D TOBU 1PG29G	Version
Order No.	<a href="#">1661460000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418014	
Qty.	1 pc(s).	
Type	HDC 24B TOBU 1M32G	Version
Order No.	<a href="#">1787810000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205257	
Qty.	1 pc(s).	
Type	HDC 24B TOBU 1PG21G	Version
Order No.	<a href="#">1661370000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190417925	
Qty.	1 pc(s).	
Type	HDC 24B TOBU 1M25G	Version
Order No.	<a href="#">1787820000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205264	
Qty.	1 pc(s).	
Type	HDC 64D TOBU 1PG21G	Version
Order No.	<a href="#">1661440000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: PG 21
GTIN (EAN)	4008190417994	
Qty.	1 pc(s).	

## HDC 24B ABU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## XXL plug housing, cable entry on top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 64D TOBU 1M50G	Version
Order No.	<a href="#">1111140000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from top, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 50
GTIN (EAN)	4032248964413	
Qty.	1 pc(s).	

## XXL plug housing, cable entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 64D TSBU 1M50G	Version
Order No.	<a href="#">1111130000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 50
GTIN (EAN)	4032248967711	
Qty.	1 pc(s).	

## HDC 24B ABU

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Hood, Cable Entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 24B TSBU 1PG29G	Version
Order No.	<a href="#">1661240000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190417796	
Qty.	1 pc(s).	
Type	HDC 64D TSBU 1M25G	Version
Order No.	<a href="#">1786780000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248204021	
Qty.	1 pc(s).	
Type	HDC 24B TSBU 1PG21G	Version
Order No.	<a href="#">1661230000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190417789	
Qty.	1 pc(s).	
Type	HDC 24B TSBU 1M40G	Version
Order No.	<a href="#">1902480000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 40
GTIN (EAN)	4032248592944	
Qty.	1 pc(s).	
Type	HDC 64D TSBU 1PG29G	Version
Order No.	<a href="#">1661320000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190417871	
Qty.	1 pc(s).	
Type	HDC 24B TSBU 1M32G	Version
Order No.	<a href="#">1787750000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205097	
Qty.	1 pc(s).	
Type	HDC 64D TSBU 1M32G	Version
Order No.	<a href="#">1786770000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204014	
Qty.	1 pc(s).	
Type	HDC 24B TSBU 1M25G	Version
Order No.	<a href="#">1787760000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205103	
Qty.	1 pc(s).	

**HDC 24B ABU****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

Type	HDC 64D TSBU 1M40G	Version
Order No.	<a href="#">1809630000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged
GTIN (EAN)	4032248284986	condition), Cable entry from side, Plug housing, Side-locking clamp on
Qty.	1 pc(s).	lower side, high, Size of cable entries: M 40
Type	HDC 64D TSBU 1PG21G	Version
Order No.	<a href="#">1661300000</a>	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged
GTIN (EAN)	4008190417857	condition), Cable entry from side, Plug housing, Side-locking clamp on
Qty.	1 pc(s).	lower side, high, Size of cable entries: PG 21