

**IE-CD-V14MSCRJ-MM-C-MA****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Coupling FreeCon design for Fibre-optic plug-in connectors PushPull Var.14 according to IEC 61076-3-117, metal

**General ordering data**

Version	Junction box, FreeCon, SCRJ, Plug-in connector, IP65
Order No.	<a href="#">1318150000</a>
Type	IE-CD-V14MSCRJ-MM-C-MA
GTIN (EAN)	4050118123982
Qty.	1 pc(s).

## IE-CD-V14MSCRJ-MM-C-MA

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	43.9 mm	Depth (inches)	1.728 inch
Height	52 mm	Height (inches)	2.047 inch
Width	41 mm	Width (inches)	1.614 inch
Net weight	224.56 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Colour	silver	Housing main material	Aluminium profile, Cover: die-cast zinc, painted
Protection degree	IP65	Type of mounting	Screw mounting

## General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
-------------------------	---------	--------------------	---------------------------------------

## Optical properties of fibre-optic coupling

Insertion attenuation (fibre-optic coupling)	<0.2 dB
--	---------

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-03-92
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

## Approvals

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E316369

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

Creation date May 2, 2024 5:33:05 AM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.


## IE-CD-V14MSCRJ-MM-C-MA

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)


## Drawings

### Dimensioned drawing

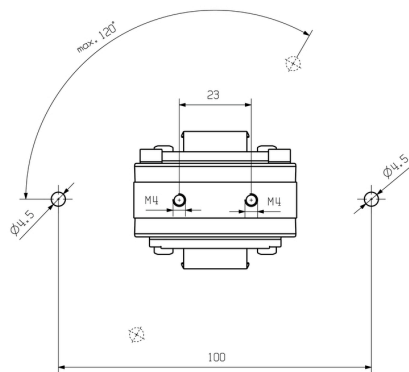


Bottom view

### Dimensioned drawing

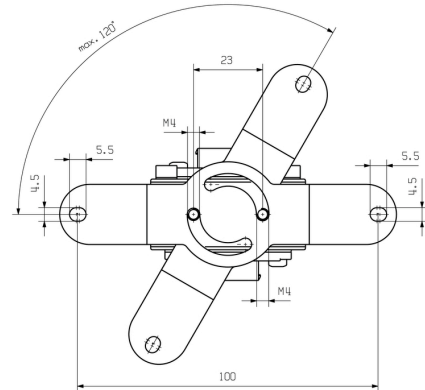


Bottom view with mounting foot

### Dimensioned drawing

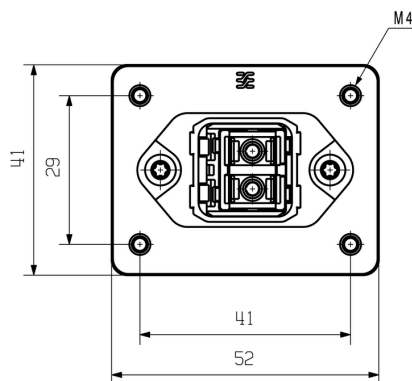

Front view

### Dimensioned drawing

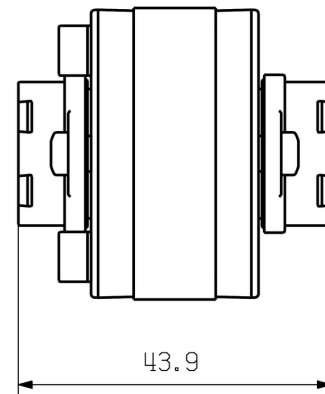

Side view

**IE-CD-V14MSCRJ-MM-C-MA**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V14P	Version
Order No.	<a href="#">1058310000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248799404	
Qty.	10 pc(s).	

**SC-RJ**

PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. SC insert

**General ordering data**

Type	IE-PS-V14M-2SC-POF	Version
Order No.	<a href="#">1191550000</a>	FO connector, Version 14, SC-RJ POF, IP67
GTIN (EAN)	4032248974436	
Qty.	10 pc(s).	