

IE-CDM-V14MRJSCP/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Delivery incl. dust caps

FreeCon Active PROFINET media converter with diagnostic functionality, for PushPull Var. 14 plug-in connector acc. to IEC 61076-3-117 with RJ45 and SC-RJ POF acc. to IEC 61754-24 and PushPull Power acc. to PROFINET specification.

General ordering data

Version	POF media converter, FreeCon, IP65
Order No.	1324440000
Type	IE-CDM-V14MRJSCP/VAPM-C
GTIN (EAN)	4050118128208
Qty.	1 pc(s).

IE-CDM-V14MRJSCP/VAPM-C

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	130.4 mm	Depth (inches)	5.134 inch
Height	53 mm	Height (inches)	2.087 inch
Width	100 mm	Width (inches)	3.937 inch
Net weight	722.04 g		

Temperatures

Operating temperature	-20 °C...55 °C
-----------------------	----------------

General data

Data interface	PROFINET PushPull SCRJ POF (V14), PROFINET PushPull RJ45 (V14)	Housing main material	Aluminium profile, Cover: die-cast zinc, painted
Plugging cycles	≥ 100	Power interface	PROFINET PushPull Power
Protection degree	IP65	UL 94 flammability rating	V-0
Wiring	PROFINET		

Electrical properties

Baud rate	100 MB	Current consumption	200 mA typical
LED indicator	P1: port active, P2: port active, SF: general error, BF: bus error, US1: voltage 1 (electronics), US2: voltage 2	Operating voltage	24 V
Operational voltage range	18...30 V DC	Protocol	PROFINET IRT

General standards

Certificate no. (cULus)	E141197	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24, IEC 60603-7-51
Network standard	IEC 61158, IEC 61784		

Classifications

ETIM 6.0	EC001467	ETIM 7.0	EC001467
ETIM 8.0	EC001467	ETIM 9.0	EC001467
ECLASS 9.0	19-17-01-14	ECLASS 9.1	19-17-01-14
ECLASS 10.0	19-17-01-32	ECLASS 11.0	19-17-01-32
ECLASS 12.0	19-17-01-32	ECLASS 13.0	19-17-01-14

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

IE-CDM-V14MRJSCP/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E141197

Downloads

Approval/Certificate/Document of Conformity

[PI_Zertifikat_1324440000](#)

Engineering Data

[CAD data – STEP](#)

Software

[Device description – GSDML-V2.25-Weidmuller-FCAPIMPOF-20130124.zip](#)[Runtime Software – WM_FCA_PIM_POF_V_1_04_01.zip](#)[Runtime Software – CFG configurator - Weidmueller_FreeCon_08042011](#)

User Documentation

[Manual EN](#)[MAN IE GUIDE DE](#)[MAN IE GUIDE EN](#)[Firmware update manual](#)[Manual DE](#)[installation instructions](#)

Catalogues

[Catalogues in PDF-format](#)


Brochures

[FL FIELDWIRING EN](#)[PI PROFINET CABLING EN](#)[PI PROFINET CABLING EN](#)

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

Drawings

Dimensioned drawing

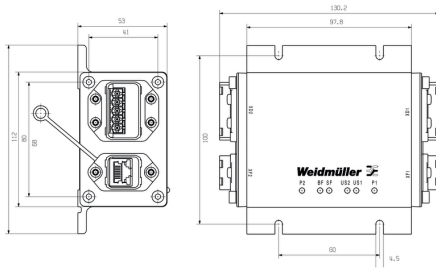

RJ45	POF	Power	Power
1		1	1
2		2	2
3		3	3
6		4	4
		5	5

IE-CDM-V14MRJSCP/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****SC-RJ**

PushPull plug-in connector set according to IEC
61076-3-117 ver.14 (PROFINET), metal incl. SC insert

General ordering data

Type	IE-PS-V14M-2SC-POF	Version
Order No.	1191550000	FO connector, Version 14, SC-RJ POF, IP67
GTIN (EAN)	4032248974436	
Qty.	10 pc(s).	

Sets

PushPull Power plug-in connector according to PROFINET
specification

General ordering data

Type	IE-PS-VAPM-5P-2.5	Version
Order No.	2465440000	Power connector, Plug, PROFINET, Set of connectors
GTIN (EAN)	4050118522136	
Qty.	1 pc(s).	

IE-CDM-V14MRJSCP/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Sets - RJ45**

PushPull plug-in connector set according to IEC
61076-3-117 ver.14 (PROFINET), metal incl. RJ45 insert

General ordering data

Type	IE-PS-V14M-RJ45-FH-P	Version
Order No.	1012170000	Plug insert RJ45 tool-free, Variant 14 metal, Cat.5 (ISO/IEC 11801)
GTIN (EAN)	4032248719815	
Qty.	10 pc(s).	