

**ZQV 1.5N/R6.4/19 SW****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image****General ordering data**

Version	TERMSERIES, Cross-connector
Order No.	<a href="#">1391600000</a>
Type	ZQV 1.5N/R6.4/19 SW
GTIN (EAN)	4050118191806
Qty.	10 pc(s).
Delivery status	<b>This article will no longer be available in the future.</b>
Available until	2021-06-30
Alternative product	<a href="#">2556490000</a>

**ZQV 1.5N/R6.4/19 SW****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	4.9 mm	Depth (inches)	0.193 inch
Height	13.1 mm	Height (inches)	0.516 inch
Width	119 mm	Width (inches)	4.685 inch
Net weight	4.65 g		

**Temperatures**

Storage temperature	-40 °C...85 °C	Operating temperature	-40 °C...60 °C
---------------------	----------------	-----------------------	----------------

**Rated data UL**

Rated current (UL)	10 A
--------------------	------

**General data**

Version	can be cut to length	Colour	black
---------	----------------------	--------	-------

**Insulation coordination**

Rated voltage	250 V
---------------	-------

**Connection data**

Pitch in mm (P)	6.4 mm
-----------------	--------

**Classifications**

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ECLASS 9.1	27-37-16-92	ECLASS 10.0	27-37-16-92
ECLASS 11.0	27-37-16-92	ECLASS 12.0	27-37-16-92
ECLASS 13.0	27-37-16-92		

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">Beipackzettel / Package Insert - multilingual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	


## ZQV 1.5N/R6.4/19 SW

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Dimensional drawing

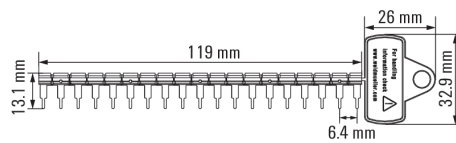

## ZQV 1.5N/R6.4/19 SW

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Cutting and notching tools for cross-connections



- for Weidmüller Z-Series cross-connections
- for cross-connections from WQV 2.5 to WQV 35
- for cross-connection window of the terminal WSI 6

#### General ordering data

Type	WAW 1 NEUTRAL	Version
Order No.	<a href="#">9004500000</a>	Miscellaneous tools
GTIN (EAN)	4008190053925	
Qty.	1 pc(s).	
Type	KT ZQV	Version
Order No.	<a href="#">9002170000</a>	Cutting tool for one-hand operation
GTIN (EAN)	4032248291670	
Qty.	1 pc(s).	

### Cutting tools



Cutting tools for conductors up to 8 mm, 12 mm, 14 mm and 22 mm outside diameter. The special blade geometry allows pinch-free cutting of copper and aluminium conductors with minimum physical effort. The cutting tools (KT 8 to KT 22) also come with VDE and GS-tested protective insulation up to 1,000 V in accordance with EN/IEC 60900.

#### General ordering data

Type	KT 14	Version
Order No.	<a href="#">1157820000</a>	Cutting tools, Cutting tool for one-hand operation
GTIN (EAN)	4032248945344	
Qty.	1 pc(s).	