

**SSR 10-32VDC/0-35VDC 5A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration

Individual relays for TERMSERIES

- Solid-state relays
- Different output versions

**General ordering data**

Version	TERMSERIES, Solid-state relay, Rated control voltage: 10...32 V DC , Rated switching voltage: 0...35 V DC, Continuous current: 5 A, Plug-in connection
Order No.	<a href="#">1421450000</a>
Type	SSR 10-32VDC/0-35VDC 5A
GTIN (EAN)	4050118235302
Qty.	20 pc(s).

## SSR 10-32VDC/0-35VDC 5A

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	15.7 mm	Depth (inches)	0.618 inch
Height	29 mm	Height (inches)	1.142 inch
Width	12.7 mm	Width (inches)	0.5 inch
Net weight	9.87 g		

## Temperatures

Storage temperature	-40 °C...100 °C	Operating temperature	-20 °C...80 °C
---------------------	-----------------	-----------------------	----------------

## Probability of failure

MTTF	1,099 Jahre
------	-------------

## Control side

Rated control voltage	10...32 V DC	Nominal control current	3...13 mA
Status indicator	No		

## Load side

Rated switching voltage	0...35 V DC	Continuous current	5 A
Rated switching current	5 A	Switch-on delay	<55 µs
Switch-off delay	<310 µs	Voltage drop at max. load	≤ 0.3 V
Leakage current	<20 µA	Min. switching current	1 mA
Protective circuit, load side	Free-wheeling diode	Contact type	1 NO contact (MOS-FET)

## General data

Colour	black
--------	-------

## Insulation coordination

Dielectric strength for control side - load side	2.5 kV <sub>eff</sub>	Impulse withstand voltage	2.5 kV
--	-----------------------	---------------------------	--------

## Connection data

Wire connection method	Plug-in connection	Pitch in mm (P)	5 mm
------------------------	--------------------	-----------------	------

## Classifications

ETIM 6.0	EC001504	ETIM 7.0	EC001504
ETIM 8.0	EC001504	ETIM 9.0	EC001504
ECLASS 9.0	27-37-16-04	ECLASS 9.1	27-37-16-04
ECLASS 10.0	27-37-16-04	ECLASS 11.0	27-37-16-04
ECLASS 12.0	27-37-16-04	ECLASS 13.0	27-37-16-04

## Approvals

ROHS	Conform
------	---------

### SSR 10-32VDC/0-35VDC 5A

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Downloads

Engineering Data

[CAD data – STEP](#)

Catalogues

[Catalogues in PDF-format](#)

## SSR 10-32VDC/0-35VDC 5A

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26


D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Wiring diagram

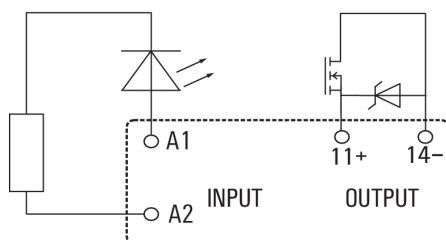

View of pins from below

### Dimensional drawing

