

**PZ PK 6/70****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Crimping tools for tubular and compression cable lugs with swivel crimping star.**

- Integrated crimping star for different cross-sections
- Hexagon crimping tools for compression cable lugs
- WM-From crimping tools for tubular cable lugs
- wide processing range up to 70 or 120 mm<sup>2</sup>

**General ordering data**

Version	6mm <sup>2</sup> , 70mm <sup>2</sup>
Order No.	<a href="#">1500470000</a>
Type	PZ PK 6/70
GTIN (EAN)	4050118309263
Qty.	1 pc(s).

**PZ PK 6/70****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Depth	515 mm	Depth (inches)	20.276 inch
Net weight	2,040 g		

**Technical data**

Version	Mechanical, without inter-changeable inserts
---------	--

**Crimp inserts**

Crimp cross-section aluminium	10 ... 50 mm <sup>2</sup>	Crimping width	5 mm
-------------------------------	---------------------------	----------------	------

**Description of contact**

Crimping range, max.	70 mm <sup>2</sup>	Crimping range, min.	6 mm <sup>2</sup>
----------------------	--------------------	----------------------	-------------------

**Classifications**

ETIM 6.0	EC000168	ETIM 7.0	EC000168
ETIM 8.0	EC000168	ETIM 9.0	EC000168
ECLASS 9.0	21-04-38-11	ECLASS 9.1	21-04-38-11
ECLASS 10.0	21-04-38-11	ECLASS 11.0	21-04-38-11
ECLASS 12.0	21-04-38-11	ECLASS 13.0	21-04-38-11

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
------------	----------------

**Downloads**

User Documentation	<a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

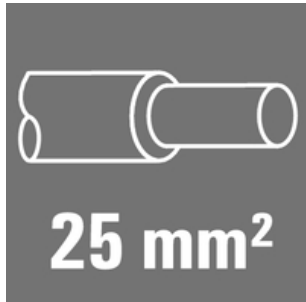
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

25 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M8/-25	Version
Order No.	<a href="#">1497980000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118307528	
Qty.	100 pc(s).	
Type	KP-M6/-25	Version
Order No.	<a href="#">1497970000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118307412	
Qty.	100 pc(s).	
Type	KP-M10/-25	Version
Order No.	<a href="#">1497990000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118307535	
Qty.	100 pc(s).	
Type	KP-M16/-25	Version
Order No.	<a href="#">1498010000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118307443	
Qty.	100 pc(s).	
Type	KP-M12/-25	Version
Order No.	<a href="#">1498000000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118307504	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

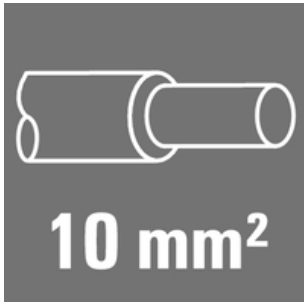
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

10 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KWPN-M8/-10 90	Version
Order No.	<a href="#">1497430000</a>	cable lug, terminal end, 10 mm <sup>2</sup>
GTIN (EAN)	4050118306927	
Qty.	100 pc(s).	
Type	KWPN-M6/-10 90	Version
Order No.	<a href="#">1497420000</a>	cable lug, terminal end, 10 mm <sup>2</sup>
GTIN (EAN)	4050118307023	
Qty.	100 pc(s).	

10 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M6/-10	Version
Order No.	<a href="#">1497880000</a>	cable lug, terminal end, 10 mm <sup>2</sup>
GTIN (EAN)	4050118307283	
Qty.	100 pc(s).	
Type	KP-M8/-10	Version
Order No.	<a href="#">1497890000</a>	cable lug, terminal end, 10 mm <sup>2</sup>
GTIN (EAN)	4050118307573	
Qty.	100 pc(s).	
Type	KP-M10/-10	Version
Order No.	<a href="#">1497910000</a>	cable lug, terminal end, 10 mm <sup>2</sup>
GTIN (EAN)	4050118307276	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	KP-M5/-10	Version
Order No.	<a href="#">1497870000</a>	cable lug, terminal end, 10 mm <sup>2</sup>
GTIN (EAN)	4050118307252	
Qty.	100 pc(s).	

35 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

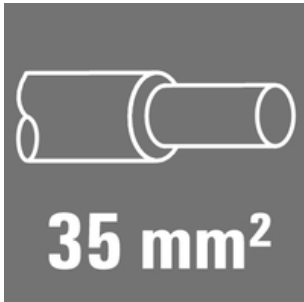
Type	KWPN-M8/-35 90	Version
Order No.	<a href="#">1497550000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307146	
Qty.	100 pc(s).	
Type	KWPN-M6/-35 90	Version
Order No.	<a href="#">1497540000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118306996	
Qty.	100 pc(s).	
Type	KWPN-M10/-35 90	Version
Order No.	<a href="#">1497570000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307153	
Qty.	100 pc(s).	
Type	KWPN-M12/-35 90	Version
Order No.	<a href="#">1497580000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118306682	
Qty.	100 pc(s).	

**PZ PK 6/70****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****35 mm<sup>2</sup>**

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

**General ordering data**

Type	VPN/-35	Version
Order No.	<a href="#">1498650000</a>	cable lug, terminal end, 35 mm <sup>2</sup> , 35 mm <sup>2</sup>
GTIN (EAN)	4050118308143	
Qty.	100 pc(s).	

**10 mm<sup>2</sup>**

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

**General ordering data**

Type	VPN/-10	Version
Order No.	<a href="#">1498620000</a>	cable lug, terminal end, 10 mm <sup>2</sup> , 10 mm <sup>2</sup>
GTIN (EAN)	4050118308136	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

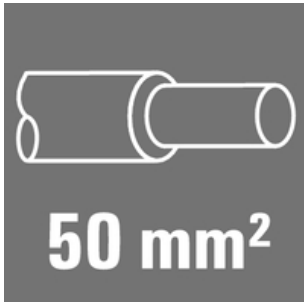
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

50 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M20/-50	Version
Order No.	<a href="#">1498120000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307597	
Qty.	100 pc(s).	
Type	KP-M6/-50	Version
Order No.	<a href="#">1498510000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118308006	
Qty.	100 pc(s).	
Type	KP-M10/-50	Version
Order No.	<a href="#">1498080000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307559	
Qty.	100 pc(s).	
Type	KP-M16/-50	Version
Order No.	<a href="#">1498110000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307474	
Qty.	100 pc(s).	
Type	KP-M8/-50	Version
Order No.	<a href="#">1498070000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307566	
Qty.	100 pc(s).	
Type	KP-M14/-50	Version
Order No.	<a href="#">1498570000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118308105	
Qty.	100 pc(s).	
Type	KP-M12/-50	Version
Order No.	<a href="#">1498090000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307375	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

6 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	VPN/-6	Version
Order No.	<a href="#">1498610000</a>	cable lug, terminal end, 6 mm <sup>2</sup> , 6 mm <sup>2</sup>
GTIN (EAN)	4050118307931	
Qty.	100 pc(s).	

70 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KWPN-M16/-70 90	Version
Order No.	<a href="#">1497680000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307122	
Qty.	25 pc(s).	
Type	KWPN-M12/-70 90	Version
Order No.	<a href="#">1497660000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307092	
Qty.	25 pc(s).	
Type	KWPN-M8/-70 90	Version
Order No.	<a href="#">1497640000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307047	
Qty.	25 pc(s).	
Type	KWPN-M10/-70 90	Version
Order No.	<a href="#">1497650000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307177	
Qty.	25 pc(s).	



## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

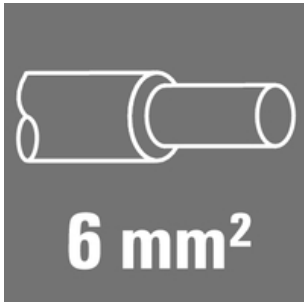
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

6 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M5/-6	Version
Order No.	<a href="#">1497840000</a>	cable lug, terminal end, 6 mm <sup>2</sup>
GTIN (EAN)	4050118307405	
Qty.	100 pc(s).	
Type	KP-M6/-6	Version
Order No.	<a href="#">1497850000</a>	cable lug, terminal end, 6 mm <sup>2</sup>
GTIN (EAN)	4050118307245	
Qty.	100 pc(s).	
Type	KP-M8/-6	Version
Order No.	<a href="#">1497860000</a>	cable lug, terminal end, 6 mm <sup>2</sup>
GTIN (EAN)	4050118307238	
Qty.	100 pc(s).	

16 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KWPN-M12/-16 90	Version
Order No.	<a href="#">1497480000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118306866	
Qty.	100 pc(s).	
Type	KWPN-M10/-16 90	Version
Order No.	<a href="#">1497470000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118307016	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

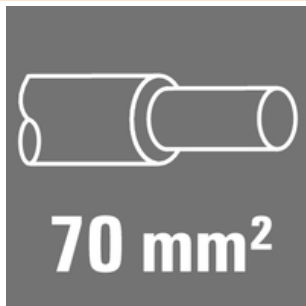
D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	KWPN-M6/-16 90	Version
Order No.	<a href="#">1497440000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118306644	
Qty.	100 pc(s).	
Type	KWPN-M8/-16 90	Version
Order No.	<a href="#">1497450000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118306873	
Qty.	100 pc(s).	

70 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M12/-70	Version
Order No.	<a href="#">1498150000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307467	
Qty.	50 pc(s).	
Type	KP-M14/-70	Version
Order No.	<a href="#">1498560000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307696	
Qty.	50 pc(s).	
Type	KP-M16/-70	Version
Order No.	<a href="#">1498160000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307481	
Qty.	50 pc(s).	
Type	KP-M8/-70	Version
Order No.	<a href="#">1498130000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307351	
Qty.	50 pc(s).	
Type	KP-M10/-70	Version
Order No.	<a href="#">1498140000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307429	
Qty.	50 pc(s).	
Type	KP-M20/-70	Version
Order No.	<a href="#">1498170000</a>	cable lug, terminal end, 70 mm <sup>2</sup>
GTIN (EAN)	4050118307344	
Qty.	50 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

16 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	VPN/-16	Version
Order No.	<a href="#">1498630000</a>	cable lug, terminal end, 16 mm <sup>2</sup> , 16 mm <sup>2</sup>
GTIN (EAN)	4050118307856	
Qty.	100 pc(s).	

50 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KWPN-M12/-50 90	Version
Order No.	<a href="#">1497620000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118306675	
Qty.	100 pc(s).	
Type	KWPN-M10/-50 90	Version
Order No.	<a href="#">1497610000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307078	
Qty.	100 pc(s).	
Type	KWPN-M8/-50 90	Version
Order No.	<a href="#">1497590000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118306699	
Qty.	100 pc(s).	
Type	KWPN-M16/-50 90	Version
Order No.	<a href="#">1497630000</a>	cable lug, terminal end, 50 mm <sup>2</sup>
GTIN (EAN)	4050118307115	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

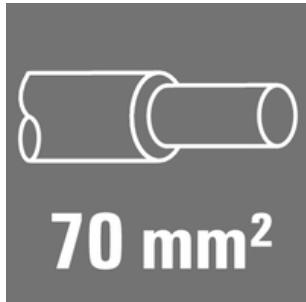
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

70 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	VPN/-70	Version
Order No.	<a href="#">1498670000</a>	cable lug, terminal end, 70 mm <sup>2</sup> , 70 mm <sup>2</sup>
GTIN (EAN)	4050118308020	
Qty.	50 pc(s).	

25 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KWPN-M10/-25 90	Version
Order No.	<a href="#">1497520000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118306989	
Qty.	100 pc(s).	
Type	KWPN-M6/-25 90	Version
Order No.	<a href="#">1497490000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118306668	
Qty.	100 pc(s).	
Type	KWPN-M8/-25 90	Version
Order No.	<a href="#">1497510000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118306972	
Qty.	100 pc(s).	
Type	KWPN-M12/-25 90	Version
Order No.	<a href="#">1497530000</a>	cable lug, terminal end, 25 mm <sup>2</sup>
GTIN (EAN)	4050118307108	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

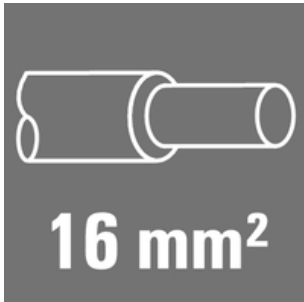
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

16 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M12/-16	Version
Order No.	<a href="#">1497960000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118307436	
Qty.	100 pc(s).	
Type	KP-M6/-16	Version
Order No.	<a href="#">1497930000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118307290	
Qty.	100 pc(s).	
Type	KP-M8/-16	Version
Order No.	<a href="#">1497940000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118307269	
Qty.	100 pc(s).	
Type	KP-M10/-16	Version
Order No.	<a href="#">1497950000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118307450	
Qty.	100 pc(s).	
Type	KP-M5/-16	Version
Order No.	<a href="#">1497920000</a>	cable lug, terminal end, 16 mm <sup>2</sup>
GTIN (EAN)	4050118307542	
Qty.	100 pc(s).	

## PZ PK 6/70

Weidmüller Interface GmbH &amp; Co. KG

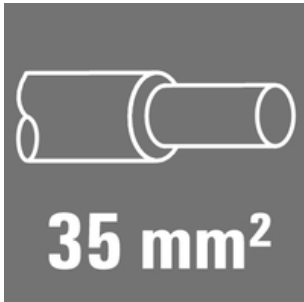
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

35 mm<sup>2</sup>

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

Type	KP-M10/-35	Version
Order No.	<a href="#">1498040000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307337	
Qty.	100 pc(s).	
Type	KP-M8/-35	Version
Order No.	<a href="#">1498030000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307511	
Qty.	100 pc(s).	
Type	KP-M16/-35	Version
Order No.	<a href="#">1498060000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307382	
Qty.	100 pc(s).	
Type	KP-M12/35	Version
Order No.	<a href="#">1498050000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307320	
Qty.	100 pc(s).	
Type	KP-M6/-35	Version
Order No.	<a href="#">1498020000</a>	cable lug, terminal end, 35 mm <sup>2</sup>
GTIN (EAN)	4050118307313	
Qty.	100 pc(s).	

**PZ PK 6/70****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****50 mm<sup>2</sup>**

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

**General ordering data**

Type	VPN/-50	Version
Order No.	<a href="#">1498660000</a>	cable lug, terminal end, 50 mm <sup>2</sup> , 50 mm <sup>2</sup>
GTIN (EAN)	4050118307948	
Qty.	50 pc(s).	

**25 mm<sup>2</sup>**

**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

**General ordering data**

Type	VPN/-25	Version
Order No.	<a href="#">1498640000</a>	cable lug, terminal end, 25 mm <sup>2</sup> , 25 mm <sup>2</sup>
GTIN (EAN)	4050118308013	
Qty.	100 pc(s).	