

**HDC 24D TSLU 1PG29G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

|            |   |
|------------|---|
| Version    | HDC enclosures, Size: 4, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp, lower side, high, Size of cable entries: PG 29 |
| Order No.  | <a href="#">1655270000</a>  |
| Type       | HDC 24D TSLU 1PG29G   |
| GTIN (EAN) | 4008190408275   |
| Qty.       | 1 pc(s).  |



## HDC 24D TSLU 1PG29G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |       |                 |            |
|------------|-------|-----------------|------------|
| Height     | 72 mm | Height (inches) | 2.835 inch |
| Width      | 43 mm | Width (inches)  | 1.693 inch |
| Net weight | 181 g |                 |            |

## Temperatures

|                   |                   |
|-------------------|-------------------|
| Limit temperature | -40 °C ... 125 °C |
|-------------------|-------------------|

## Dimensions

|                      |           |                     |       |
|----------------------|-----------|---------------------|-------|
| Cable entry          | w. thread | Height of housing B | 72 mm |
| Total length housing | 73 mm     | Width housing C     | 43 mm |

## General data

|                             |                             |                       |                             |
|-----------------------------|-----------------------------|-----------------------|-----------------------------|
| EMC housings                | No                          | Housing main material | diecast aluminium           |
| Material of locking element |                             | Protection degree     | IP65 (in plugged condition) |
| Surface finish              | Stainless steel, rust-proof |                       |                             |
|                             | Powder coating              |                       |                             |

## Version

|                              |                               |                                |                                     |
|------------------------------|-------------------------------|--------------------------------|-------------------------------------|
| BG                           | 4                             | Cable entry                    | w. thread                           |
| Clamp version                | End-locking clamp             | Colour (RAL)                   | RAL 7035                            |
| Design                       |                               | Design of housing              | Cable entry from side, Plug housing |
|                              | high                          |                                |                                     |
| Design of locking system     | End-locking clamp, lower side | Internal thread                | PG 29                               |
| Number of cable entry on top | 0                             | Number of cable entry sideways | 1                                   |
| Size                         | 4                             | Size of cable entries          | PG 29                               |
| Suitable for ModuPlug®       | Yes                           | Top part/bottom part/lid       | upper part                          |
| Type                         | Plug                          |                                |                                     |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000437    | ETIM 7.0    | EC000437    |
| ETIM 8.0    | EC000437    | ETIM 9.0    | EC000437    |
| ECLASS 9.0  | 27-44-02-02 | ECLASS 9.1  | 27-44-02-02 |
| ECLASS 10.0 | 27-44-02-02 | ECLASS 11.0 | 27-44-02-02 |
| ECLASS 12.0 | 27-44-02-02 | ECLASS 13.0 | 27-44-02-02 |

|                     |                         |
|---------------------|-------------------------|
| Substance           | Acetone                 |
| Chemical resistance | Conditionally resistant |
| Substance           | Drilling oil            |
| Chemical resistance | Resistant               |
| Substance           | Diesel                  |
| Chemical resistance | Resistant               |
| Substance           | Ethyl alcohol           |
| Chemical resistance | Resistant               |
| Substance           | Transmission oil        |
| Chemical resistance | Resistant               |



**HDC 24D TSLU 1PG29G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data**

|                     |                         |
|---------------------|-------------------------|
| Substance           | Hydraulic oil           |
| Chemical resistance | Resistant               |
| Substance           | Coolant                 |
| Chemical resistance | Resistant               |
| Substance           | Petroleum benzine       |
| Chemical resistance | Resistant               |
| Substance           | Sweat                   |
| Chemical resistance | Resistant               |
| Substance           | Premium gasoline        |
| Chemical resistance | Conditionally resistant |
| Substance           | Water                   |
| Chemical resistance | Resistant               |
| Substance           | UV                      |
| Chemical resistance | Unstable                |
| Substance           | Ozone                   |
| Chemical resistance | Unstable                |

**Environmental Product Compliance**

|                     |   |
|---------------------|---|
| REACH SVHC          | Lead 7439-92-1  |
| SCIP                | d447edfa-0214-4f34-b5ba-82eae491b46a  |
| Chemical resistance | de.myview.objectmodel.impl.BlockImpl@6d603508 de.myview.objectmodel.impl.BlockImpl@1194d4c8<br>de.myview.objectmodel.impl.BlockImpl@35e126f6 de.myview.objectmodel.impl.BlockImpl@707087ec<br>de.myview.objectmodel.impl.BlockImpl@1c54249f de.myview.objectmodel.impl.BlockImpl@2bd18149<br>de.myview.objectmodel.impl.BlockImpl@173bd453 de.myview.objectmodel.impl.BlockImpl@63006ebf<br>de.myview.objectmodel.impl.BlockImpl@5ecdde9c de.myview.objectmodel.impl.BlockImpl@7931c7c5<br>de.myview.objectmodel.impl.BlockImpl@30e11dfc de.myview.objectmodel.impl.BlockImpl@5074f8c9<br>de.myview.objectmodel.impl.BlockImpl@607de565 |

**Approvals**

Approvals



|                         |            |
|-------------------------|------------|
| ROHS                    | Conform    |
| UL File Number Search   | UL Website |
| Certificate No. (cURus) | E92202     |

**Downloads**

|   |  |
|---|--|
| Approval/Certificate/Document of Conformity | <a href="#">Manufacturer's declaration</a>   |
| Engineering Data                            | <a href="#">CAD data – STEP</a>  |
| Product Change Notification                 | <a href="#">20220214 Technical change to HDC housings</a><br><a href="#">20220214 Technische Änderung bei HDC-Gehäusen</a> |
| Technical Documentation                     | <a href="#">1655270000 HDC_24D_TSLU_1PG29G_STP_Blatt_1.pdf</a>   |
| Catalogues                                  | <a href="#">Catalogues in PDF-format</a>   |
| Brochures                                   | <a href="#">FL FIELDWIRING EN</a><br><a href="#">FL FIELDWIRING EN</a>   |

Creation date May 3, 2024 6:45:38 AM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.



### HDC 24D TSLU 1PG29G

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

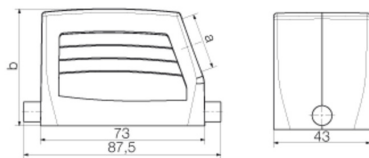



**HDC 24D TSLU 1PG29G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Cover**

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

|            |                            |  |
|------------|----------------------------|--|
| Type       | HDC 10B DMDQ 4BO           | Version  |
| Order No.  | <a href="#">1665250000</a> | HDC enclosures, Size: 4, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on upper side, Standard |
| GTIN (EAN) | 4008190421953              |  |
| Qty.       | 1 pc(s).                   |  |