

**HDC 16A DMDL 2B0****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, End-locking clamp, lower side, Standard
Order No.	<a href="#">1665910000</a>
Type	HDC 16A DMDL 2B0
GTIN (EAN)	4008190422943
Qty.	1 pc(s).

## HDC 16A DMDL 2BO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	89 mm	Depth (inches)	3.504 inch
Height	19.5 mm	Height (inches)	0.768 inch
Width	29.5 mm	Width (inches)	1.161 inch
Net weight	46 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Cable entry	For bases	Height of housing B	19.5 mm
Total length housing	79 mm	Width housing C	29.5 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element	Stainless steel, rust-proof	Protection degree	IP65 (in plugged condition)
Surface finish	Powder coating	Tightening torque	0.5 Nm

## Version

BG	5	Cable entry	For bases
Clamp version	End-locking clamp	Colour (RAL)	RAL 7035
Design	Standard	Design of housing	Cover for upper part of housing
Design of locking system	End-locking clamp, lower side	Sealing	NBR
Size	5	Suitable for ModuPlug®	No
Tightening torque	0.5 Nm	Top part/bottom part/lid	Cover
Type	Cover		

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant

## HDC 16A DMDL 2BO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@3c56f2fc de.myview.objectmodel.impl.BlockImpl@4d3cde9b de.myview.objectmodel.impl.BlockImpl@7d105d4 de.myview.objectmodel.impl.BlockImpl@527d696d de.myview.objectmodel.impl.BlockImpl@59b7a0cc de.myview.objectmodel.impl.BlockImpl@72d47567 de.myview.objectmodel.impl.BlockImpl@7da4214c de.myview.objectmodel.impl.BlockImpl@44ab0994 de.myview.objectmodel.impl.BlockImpl@207e600d de.myview.objectmodel.impl.BlockImpl@71d04628 de.myview.objectmodel.impl.BlockImpl@2da2a71f de.myview.objectmodel.impl.BlockImpl@31d9fc96 de.myview.objectmodel.impl.BlockImpl@62f48ca8

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">Manufacturer's declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Product Change Notification	<a href="#">20220214 Technical change to HDC housings</a> <a href="#">20220214 Technische Änderung bei HDC-Gehäusen</a>
Technical Documentation	<a href="#">1665910000 HDC 16A DMDL 2BO_STP_Blatt_1.pdf</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">FL FIELDWIRING EN</a>

Creation date April 28, 2024 1:32:56 PM CEST


Catalogue status 20.04.2024 / We reserve the right to make technical changes.

## HDC 16A DMDL 2B0

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

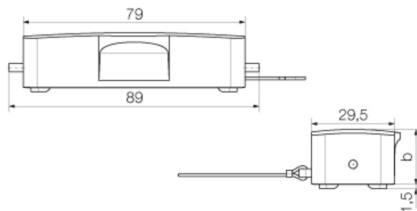

## HDC 16A DMDL 2BO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 16A SLU 2M20G	Version
Order No.	<a href="#">1788770000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard,
GTIN (EAN)	4032248206315	Size of cable entries: M 20
Qty.	1 pc(s).	
Type	HDC 16A SLU 1PG21G	Version
Order No.	<a href="#">1665090000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard,
GTIN (EAN)	4008190421793	Size of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 16A SLU 2PG16G	Version
Order No.	<a href="#">1665070000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard,
GTIN (EAN)	4008190421779	Size of cable entries: PG 16
Qty.	1 pc(s).	
Type	HDC 16A SLU 2M25G	Version
Order No.	<a href="#">1788760000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard,
GTIN (EAN)	4032248206308	Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 16A SLU 1M25G	Version
Order No.	<a href="#">1902330000</a>	HDC enclosures, Size: 5, Protection degree: IP65, IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard,
GTIN (EAN)	4032248591916	Size of cable entries: M 25
Qty.	1 pc(s).	

## HDC 16A DMDL 2BO

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 16A ALU	Version
Order No.	<a href="#">1664920000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Bulkhead housing, End-locking clamp, lower side, Standard
GTIN (EAN)	4008190421625	
Qty.	1 pc(s).	

## Coupling housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 16A KLU 1PG16G	Version
Order No.	<a href="#">1665450000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged condition), Coupling housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 16
GTIN (EAN)	4008190422158	
Qty.	1 pc(s).	

**HDC 16A DMDL 2BO****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

Type	HDC 16A KLU 1M25G	Version
Order No.	<a href="#">1788800000</a>	HDC enclosures, Size: 5, Protection degree: IP65 (in plugged
GTIN (EAN)	4032248206346	condition), Coupling housing, End-locking clamp, lower side, Standard,
Qty.	1 pc(s).	Size of cable entries: M 25