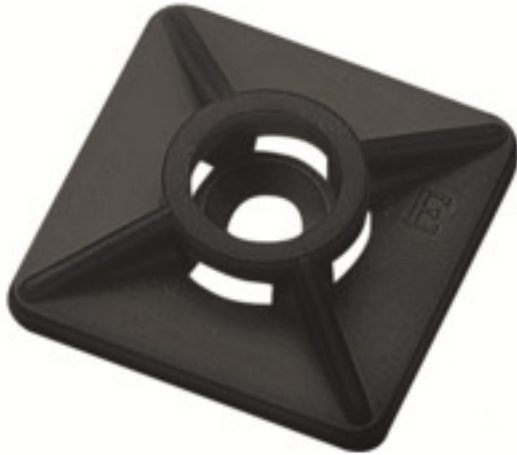


**CBH 27/27 BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration

Fastening of cables or bundles with ties into electrical switchgears and cabinets.

**General ordering data**

|            |                                       |
|------------|---------------------------------------|
| Version    | Cable ties, 27 x 27 mm, Plastic, 80 N |
| Order No.  | <a href="#">1697960000</a>            |
| Type       | CBH 27/27 BK                          |
| GTIN (EAN) | 4008190883034                         |
| Qty.       | 100 pc(s).                            |

**CBH 27/27 BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

|            |       |                 |            |
|------------|-------|-----------------|------------|
| Depth      | 2 mm  | Depth (inches)  | 0.079 inch |
| Height     | 27 mm | Height (inches) | 1.063 inch |
| Width      | 27 mm | Width (inches)  | 1.063 inch |
| Net weight | 1.6 g |                 |            |

**Temperatures**

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -40...105 °C |
|-----------------------------|--------------|

**Installation materials**

|                                   |               |                                   |        |
|-----------------------------------|---------------|-----------------------------------|--------|
| For re-opening                    | No            | Halogen                           | No     |
| Material                          | Plastic       | Max. cable tie width              | 4.8 mm |
| Operating temperature range, max. | 105 °C        | Operating temperature range, min. | -40 °C |
| Tensile strength                  | 80 N          | Tensile strength (Pound-force)    | 18 lbf |
| UL 94 flammability rating         | V-2           | UV-resistant                      | Yes    |
| Version                           | Self-adhesive |                                   |        |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000449    | ETIM 7.0    | EC000449    |
| ETIM 8.0    | EC000449    | ETIM 9.0    | EC000449    |
| ECLASS 9.0  | 23-15-90-07 | ECLASS 9.1  | 27-40-07-90 |
| ECLASS 10.0 | 27-40-07-90 | ECLASS 11.0 | 23-15-25-09 |
| ECLASS 12.0 | 23-15-25-09 | ECLASS 13.0 | 23-15-25-09 |

**Approvals**

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

**Downloads**

|            |  |
|------------|--|
| Catalogues | <a href="#">Catalogues in PDF-format</a> |
|------------|--|

## CBH 27/27 BK

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Dimensional drawing

