

**WKM 8/20****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking.

Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

**General ordering data**

Version	WKM, Conductor and cable markers, 7 - 115 mm, 20 x 8 mm, Wire and cable markers, Transparent
Order No.	<a href="#">1753490000</a>
Type	WKM 8/20
GTIN (EAN)	4032248010615
Qty.	50 pc(s).

**Technical data****Dimensions and weights**

Depth	3.5 mm	Depth (inches)	0.138 inch
Height	20 mm	Height (inches)	0.787 inch
Width	8 mm	Width (inches)	0.315 inch
Net weight	0.457 g		

**Temperatures**

Operating temperature range	-40...80 °C
-----------------------------	-------------

**General data**

Application/manufacture	Wire and cable markers		
Colour	Transparent		
Material	Polypropylene		
Number of markers per combination	1 MultiCard = Conductor and cable markers		
Number of markers per packaging unit	Form of supply	MultiCard	
Operating temperature range	-40...80 °C		
Operating temperature range, max.	80 °C		
Operating temperature range, min.	-40 °C		
Type of printing	neutral		
UL 94 flammability rating	HB		
Width	8 mm		

**Conductor and cable markers**

Conductor O.D.	7 - 115 mm	Conductor O.D., max.	115 mm
Conductor O.D., min.	7 mm	Conductor cross-section, max.	150 mm <sup>2</sup>
Conductor cross-section, min.	16 mm <sup>2</sup>	Cross-section for connected wire	16 - 150 mm <sup>2</sup>

**Classifications**

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

**Important note**

Product information	For cable ties with a width up to 7.7 mm
---------------------	--

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

### WKM 8/20

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Example of use



## WKM 8/20

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:


- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 7/20 SIRIUS MC NE TU	Version
Order No.	<a href="#">1736181696</a>	ESG, Device markers x 20 mm, PA 66, Colour: Turquoise, pluggable
GTIN (EAN)	4008190985967	
Qty.	200 pc(s).	
Type	ESG 7/20 SIRIUS MC NE GE	Version
Order No.	<a href="#">1736181687</a>	ESG, Device markers x 20 mm, PA 66, Colour: yellow, pluggable
GTIN (EAN)	4032248208265	
Qty.	200 pc(s).	
Type	ESG 7/20 SIRIUS MC NE WS	Version
Order No.	<a href="#">1736181044</a>	ESG, Device markers x 20 mm, PA 66, Colour: white, pluggable
GTIN (EAN)	4008190985950	
Qty.	200 pc(s).	

## ELS 8/20

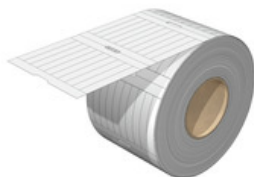

## ELS

ELS tags are special and non-adhesive insertable labels for WKM cable markers or for group tag carriers. The matt, thin but tear-resistant polyester provides very good labelling and excellent readability. Used in combination with water-repellent WKM sleeves, the solution guarantees particularly long-lasting identification of cables even in harsh environments.

## General ordering data

Type	ELS 8/20 MM GE	Version
Order No.	<a href="#">2005240000</a>	ELS, Insert markers, 20 x 8 mm, yellow
GTIN (EAN)	4050118390032	
Qty.	3,000 pc(s).	

**WKM 8/20****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

Type	ELS 8/20 MM WS	Version
Order No.	<a href="#">2005180000</a>	ELS, Insert markers, 20 x 8 mm, white
GTIN (EAN)	4050118389968	
Qty.	3,000 pc(s).	

**ESO insert tags****General ordering data**

Type	ESO 8/20 P DIN A4 WS	Version
Order No.	<a href="#">1919870000</a>	Terminal markers, Insert markers, 20 x 7 mm, white
GTIN (EAN)	4032248556861	
Qty.	10 pc(s).	
Type	ESO 8/20 P DIN A4 GE	Version
Order No.	<a href="#">1919880000</a>	Terminal markers, Insert markers, 20 x 7 mm, yellow
GTIN (EAN)	4032248556878	
Qty.	10 pc(s).	
Type	ESO 8/20 DIN A4 WS	Version
Order No.	<a href="#">1919890000</a>	Terminal markers, Insert markers, 20 x 7 mm, white
GTIN (EAN)	4032248556892	
Qty.	10 pc(s).	
Type	ESO 8/20 DIN A4 GE	Version
Order No.	<a href="#">1919900000</a>	Terminal markers, Insert markers, 20 x 7 mm, yellow
GTIN (EAN)	4032248556908	
Qty.	10 pc(s).	