

VP M25 K54**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	VPK (blanking plug in plastic), Blanking plug, in closed state, M 25, 10 mm, IP65, Polyamid 6 (PA6 - GF30)
Order No.	1776900000
Type	VP M25 K54
GTIN (EAN)	4032248156344
Qty.	100 pc(s).

VP M25 K54

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	5 mm	Height (inches)	0.197 inch
Length	7 mm	Length (inches)	0.276 inch
Diameter	25 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	9 mm	Net weight	4.2 g

Temperatures

Operating temperature	-40 °C...100 °C
-----------------------	-----------------

General information

Cable glands	metric	Diameter of sealing ring	25 mm
External thread	M 25	Halogen	No
Head diameter	30 mm	Length of thread	10 mm
Material	Polyamid 6 (PA6 - GF30)	Operating temperature range, max.	100 °C
Operating temperature range, min.	-40 °C	Pitch of thread	1.5 mm
Protection degree	IP54	Protection degree with GWDR	IP65
UL 94 flammability rating	V-2		

Classifications

ETIM 6.0	EC000451	ETIM 7.0	EC000451
ETIM 8.0	EC000451	ETIM 9.0	EC000451
ECLASS 9.0	27-14-44-25	ECLASS 9.1	27-14-44-33
ECLASS 10.0	27-14-44-25	ECLASS 11.0	27-14-44-25
ECLASS 12.0	27-14-08-05	ECLASS 13.0	27-14-08-05

Approvals

ROHS	Conform
------	---------

Downloads


Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	

VP M25 K54

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

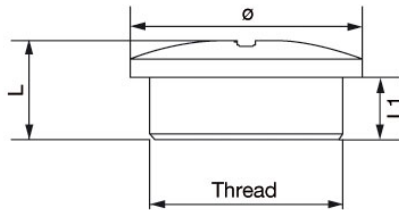

VP M25 K54**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Polyethylene flat gasket - GWDR PO**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M25-PO	Version
Order No.	1777950000	GWDR PO (flat gasket - polyethylene), Sealing ring, M 25, Polyethylene
GTIN (EAN)	4032248158218	
Qty.	50 pc(s).	

Neoprene flat gasket - GWDR NP

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M25-NP	Version
Order No.	1736250000	GWDR NP (flat gasket - neoprene), Sealing ring, M 25, Neoprene
GTIN (EAN)	4008190956042	
Qty.	100 pc(s).	

VP M25 K54**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Plastic lock nuts, grey**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU M25 - K GR	Version
Order No.	1772470000	SKMU PA (plastic locknut), Locknut, M 25, 6 mm, Polyamid 6 (PA6 -
GTIN (EAN)	4032248130214	GF30)
Qty.	100 pc(s).	