

SAI-Y-5S PARA 2M12**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**General ordering data**

| | |
|------------|----------------------------|
| | |
| Version | Y-plug, M12 / M12 |
| Order No. | 1783430000 |
| Type | SAI-Y-5S PARA 2M12 |
| GTIN (EAN) | 4032248183364 |
| Qty. | 1 pc(s). |

SAI-Y-5S PARA 2M12

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | |
|------------|------|
| Net weight | 23 g |
|------------|------|

Connection data

| | | | |
|-------------------------------------|------------|-------------------------------------|-------------------|
| Group outlet - plug-in connector | M12 pin | Single outlet 1 - plug-in connector | M12 socket |
| Single outlet 2 - plug-in connector | M12 socket | Tightening torque | M12: 0.8 - 1.2 Nm |

Technical data customisable plug-in connectors

| | | | |
|-----------------------|---------|------------------------------|--------------|
| Coding | A-coded | Contact surface | Au (Gold) |
| Housing main material | PBT | Number of poles | 5 |
| Pollution severity | 3 | Protection degree | IP67 |
| Rated current | 4 A | Rated voltage | 24 V |
| Shield connection | No | Temperature range of housing | -25...+90 °C |

Standards

| | |
|--------------------|-----------------|
| Connector standard | IEC 61076-2-101 |
|--------------------|-----------------|

General data

| | | | |
|--------------------------|-----------|------------------------------|--------------|
| Coding | A-coded | Conductor O.D. | - |
| Connection thread | M12 / M12 | Contact material, pin | CuZn |
| Contact material, socket | CuZn | Contact surface | Au (Gold) |
| Housing main material | PBT | Number of poles | 5 |
| Pollution severity | 3 | Protection degree | IP67 |
| Rated current | 4 A | Rated voltage | 24 V |
| Shield connection | No | Temperature range of housing | -25...+90 °C |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC002925 | ETIM 7.0 | EC002925 |
| ETIM 8.0 | EC002925 | ETIM 9.0 | EC002925 |
| ECLASS 9.0 | 27-44-01-06 | ECLASS 9.1 | 27-44-01-06 |
| ECLASS 10.0 | 27-44-01-06 | ECLASS 11.0 | 27-44-01-06 |
| ECLASS 12.0 | 27-44-01-06 | ECLASS 13.0 | 27-44-01-06 |

Approvals

Approvals



| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|------------------|--|
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |
| Brochures | FL FIELDWIRING EN FL FIELDWIRING EN |


SAI-Y-5S PARA 2M12

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

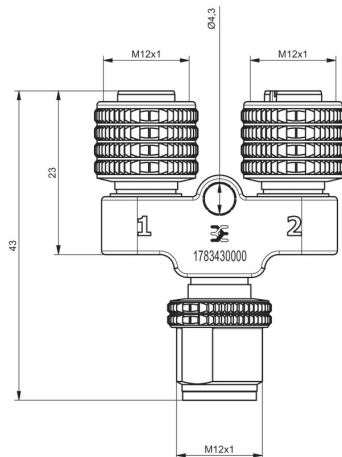

Dimensioned drawing

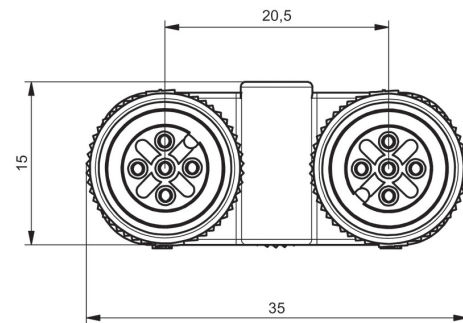

Wiring diagram

