

**HDC 48B TSLU 1M32G****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Version	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Cable entry from side, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32
Order No.	<a href="#">1788320000</a>
Type	HDC 48B TSLU 1M32G
GTIN (EAN)	4032248205851
Qty.	1 pc(s).

## HDC 48B TSLU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	151 mm	Depth (inches)	5.945 inch
Height	94 mm	Height (inches)	3.701 inch
Width	90 mm	Width (inches)	3.543 inch
Net weight	731 g		

## Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

## Dimensions

Cable entry	w. thread	Height of housing B	94 mm
Total length housing	132 mm	Width housing C	90 mm

## General data

EMC housings	No	Housing main material	diecast aluminium
Material of locking element		Protection degree	IP65 (in plugged condition)
	Stainless steel, rust-proof		
Surface finish	Powder coating	Tightening torque	1.2 Nm

## Version

BG	12	Cable entry	w. thread
Clamp version	End-locking clamp	Colour (RAL)	RAL 7035
Design		Design of housing	Cable entry from side, Plug housing
	Standard		
Design of locking system	End-locking clamp, lower side	Internal thread	M 32
Number of cable entry on top	0	Number of cable entry sideways	1
Size	12	Size of cable entries	M 32
Suitable for ModuPlug®	Yes	Tightening torque	1.2 Nm
Top part/bottom part/lid	upper part	Type	Plug

## Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ECLASS 9.0	27-44-02-02	ECLASS 9.1	27-44-02-02
ECLASS 10.0	27-44-02-02	ECLASS 11.0	27-44-02-02
ECLASS 12.0	27-44-02-02	ECLASS 13.0	27-44-02-02

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil

## HDC 48B TSLU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

Chemical resistance	Resistant
Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	d447edfa-0214-4f34-b5ba-82eae491b46a
Chemical resistance	de.myview.objectmodel.impl.BlockImpl@22b8e94b de.myview.objectmodel.impl.BlockImpl@38dd459c de.myview.objectmodel.impl.BlockImpl@794e8081 de.myview.objectmodel.impl.BlockImpl@4a573cc5 de.myview.objectmodel.impl.BlockImpl@2f407675 de.myview.objectmodel.impl.BlockImpl@7d6337a4 de.myview.objectmodel.impl.BlockImpl@7024fa01 de.myview.objectmodel.impl.BlockImpl@36651d4 de.myview.objectmodel.impl.BlockImpl@2f396c13 de.myview.objectmodel.impl.BlockImpl@4b83a047 de.myview.objectmodel.impl.BlockImpl@1c20afc4 de.myview.objectmodel.impl.BlockImpl@2d79b565 de.myview.objectmodel.impl.BlockImpl@49c40d2d

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

## HDC 48B TSLU 1M32G

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Technical data

## Downloads

Approval/Certificate/Document of Con-  
formity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[20220214 Technical change to HDC housings](#)

[20220214 Technische Änderung bei HDC-Gehäusen](#)

Technical Documentation

[1788320000 HDC\\_48B\\_TSLU\\_1M32G\\_STP\\_Blatt\\_1.pdf](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)


[FL FIELDWIRING EN](#)

### HDC 48B TSLU 1M32G

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

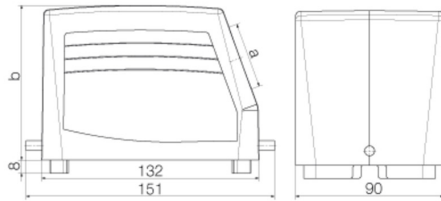

## HDC 48B TSLU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 48B ADLU	Version
Order No.	<a href="#">1222900000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Bulkhead housing, End-locking clamp, lower side, Standard, with cover
GTIN (EAN)	4008190138004	
Qty.	1 pc(s).	
Type	HDC 48B ALU	Version
Order No.	<a href="#">1295600000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Bulkhead housing, End-locking clamp, lower side, Standard, without cover
GTIN (EAN)	4050118092066	
Qty.	1 pc(s).	

## Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 48B SDLU 2PG29G	Version
Order No.	<a href="#">1667560000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: PG 29
GTIN (EAN)	4008190424763	
Qty.	1 pc(s).	

## HDC 48B TSLU 1M32G

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	HDC 48B SDLU 1M32G	Version
Order No.	<a href="#">1904150000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 32
GTIN (EAN)	4032248585700	
Qty.	1 pc(s).	
Type	HDC 48B SLU 1PG29G	Version
Order No.	<a href="#">1651100000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190299705	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 2M40G	Version
Order No.	<a href="#">1983500000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 40
GTIN (EAN)	4032248687787	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 2M50G	Version
Order No.	<a href="#">1983510000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 50
GTIN (EAN)	4032248687770	
Qty.	1 pc(s).	
Type	HDC 48B SLU 1M32G	Version
Order No.	<a href="#">1904190000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248585779	
Qty.	1 pc(s).	
Type	HDC 48B SLU 2M40G	Version
Order No.	<a href="#">1788360000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 40
GTIN (EAN)	4032248205899	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 2M32G	Version
Order No.	<a href="#">1788390000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 32
GTIN (EAN)	4032248205929	
Qty.	1 pc(s).	
Type	HDC 48B SDLU 1PG29G	Version
Order No.	<a href="#">1799810000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: PG 29
GTIN (EAN)	4032248247035	
Qty.	1 pc(s).	
Type	HDC 48B SLU 2M32G	Version
Order No.	<a href="#">1788370000</a>	HDC enclosures, Size: 12, Protection degree: IP65 (in plugged condition), Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205905	
Qty.	1 pc(s).	