

SAIE-M12B-5-0.5U-PG9**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Various build-in connectors are required for the connections on the device side of the sensor/actuator cabling. These are available in the versions M12, M8 and M5.

General ordering data

Version	Built-in plugs, M12, Female socket, straight, Mounting thread: PG 9, Number of poles: 5, Strand / cable length: 0.5 m, Front mounting
Order No.	1814890000
Type	SAIE-M12B-5-0.5U-PG9
GTIN (EAN)	4032248303120
Qty.	1 pc(s).

SAIE-M12B-5-0.5U-PG9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	31 g
------------	------

Technical data customisable plug-in connectors

Cable glands	PG 9	Coding	A-coded
Contact surface	Gold-plated	Housing main material	Zinc diecast
Number of poles	5	Plugging cycles	≥ 100
Protection degree	IP67, when screwed in	Rated current	4 A (4- and 5-pole) / 2 A (8-pole)
Rated voltage	60 V	Temperature range of housing	-30...+90 °C

Standards

Connector standard	IEC 61076-2-101
--------------------	-----------------

General data

Cable glands	PG 9	Cable length	0.5 m
Coding	A-coded	Conductor O.D.	-
Connection thread	M12	Contact surface	Gold-plated
Core cross-section	0.34 mm ²	Housing main material	Zinc diecast
Material	PVC	Mounting thread	PG 9
Number of poles	5	Plugging cycles	≥ 100
Protection degree	IP67, when screwed in	Rated current	4 A (4- and 5-pole) / 2 A (8-pole)
Rated voltage	60 V	Rated voltage	250 V (4-pole) / 125 V (5-pole) / 60 V (8-pole)
Strand / cable length	0.5 m	Temperature range of housing	-30...+90 °C
Type of mounting	Front mounting	Wire cross section (Print/Online)	0.34 (4- and 5-pole)/ 0.25 (8-pole)

Classifications

ETIM 6.0	EC002635	ETIM 7.0	EC003570
ETIM 8.0	EC003570	ETIM 9.0	EC003570
ECLASS 9.0	27-44-01-03	ECLASS 9.1	27-44-01-03
ECLASS 10.0	27-44-01-03	ECLASS 11.0	27-44-01-03
ECLASS 12.0	27-44-01-03	ECLASS 13.0	27-44-01-03

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	ebf89fc8-a87f-4691-b87a-dfb9921774b4

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E307231

Creation date May 13, 2024 9:05:39 PM CEST

Catalogue status 04.05.2024 / We reserve the right to make technical changes.

SAIE-M12B-5-0.5U-PG9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)

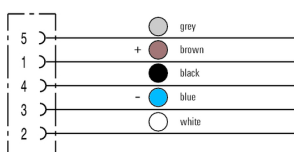
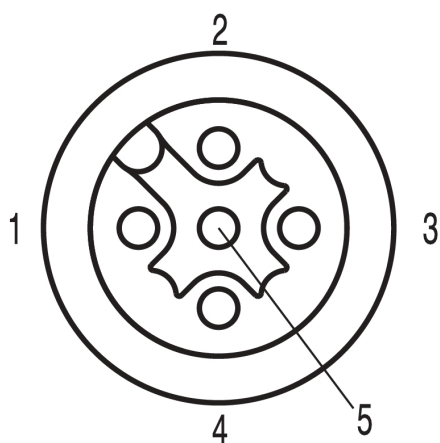
[FL FIELDWIRING EN](#)

SAIE-M12B-5-0.5U-PG9**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Wiring diagram****Pole scheme**

SAIE-M12B-5-0.5U-PG9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Brass lock nuts, nickel-plated



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU PG9-MS	Version
Order No.	1694080000	SKMU MS (brass locknut), Locknut, PG 9, 2.8 mm, Brass, nickel-plated
GTIN (EAN)	4008190872243	
Qty.	100 pc(s).	