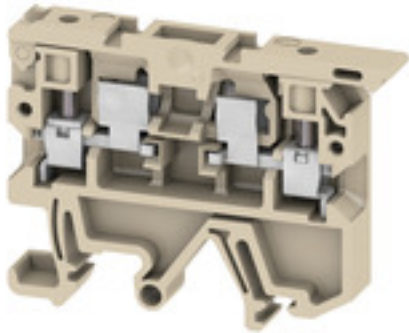


**ASK 1/EN LD 24V AC/DC DB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Similar to illustration

In some applications it is useful to protect the feed through connection with a separate fuse. Fuse terminal blocks are made up of one terminal block bottom section with a fuse insertion carrier. The fuses vary from pivoting fuse levers and pluggable fuse holders to screwable closures and flat plug-in fuses.

**General ordering data**

Version	Fuse terminal, Screw connection, Fuse cartridge, with LED, One end without connector, Screw connection, 4 mm <sup>2</sup> , 24 V, 6.3 A, G-Si. 5 x 20, dark beige
Order No.	<a href="#">1937670000</a>
Type	ASK 1/EN LD 24V AC/DC DB
GTIN (EAN)	4032248614752
Qty.	25 pc(s).

## ASK 1/EN LD 24V AC/DC DB

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	51.5 mm	Depth (inches)	2.028 inch
Height	58 mm	Height (inches)	2.283 inch
Width	8.1 mm	Width (inches)	0.319 inch
Net weight	13.6 g		

## Temperatures

Storage temperature	-25 °C...55 °C	Continuous operating temp., min.	-50 °C
Continuous operating temp., max.	100 °C		

## Material data

Material	PA 66	Colour	dark beige
UL 94 flammability rating	V-2		

## System specifications

Version	Screw connection, Fuse cartridge, with LED, One end without connector	Number of potentials	1
Number of levels	1	Number of clamping points per level	2
Number of potentials per tier	1	Levels cross-connected internally	No
PE connection	No	Rail	TS 35, TS 32
N-function	No	PE function	No
PEN function	No		

## Additional technical data

Installation advice	Direct mounting	Type of mounting	Snap-on
---------------------	-----------------	------------------	---------

## Conductors for clamping (rated connection)

Number of connections	2	Type of connection	Screw connection
-----------------------	---	--------------------	------------------

## Dimensions

TS 32 offset	10.5 mm	TS 35 offset	8.5 mm
--------------	---------	--------------	--------

## Fuse terminals

Cartridge fuse	G-Si. 5 x 20
----------------	--------------

## General

Installation advice	Direct mounting	Rail	TS 35, TS 32
---------------------	-----------------	------	--------------

## Rating data

Rated cross-section	4 mm <sup>2</sup>	Rated voltage	24 V
Rated DC voltage	24 V	Rated current	6.3 A
Volume resistance according to IEC 60947-7-x	1 mΩ	Power loss in accordance with IEC 60947-7-x	1.02 W

**ASK 1/EN LD 24V AC/DC DB**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Technical data****Classifications**

ETIM 6.0	EC000899	ETIM 7.0	EC000899
ETIM 8.0	EC000899	ETIM 9.0	EC000899
ECLASS 9.0	27-14-11-16	ECLASS 9.1	27-14-11-16
ECLASS 10.0	27-14-11-16	ECLASS 11.0	27-14-11-16
ECLASS 12.0	27-14-11-16	ECLASS 13.0	27-25-01-13

**Important note**

Product information      The voltage depends on the selected fuse element or the selected indicator light

**Approvals**

Approvals



ROHS      Conform

**Downloads**

Approval/Certificate/Document of Conformity	<a href="#">UKCA declaration of conformity</a>
User Documentation	<a href="#">StorageConditionsTerminalBlocks</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**ASK 1/EN LD 24V AC/DC DB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Marker holder**

The marker holder offer the possibility of additional mounting of standard markers with a pitch of 5 or 5.1 mm. The angled holders can be optionally snapped together and could be mounted in all standard marking channels of the Klippon® Connect modular terminal blocks. Fitting marker types could be found under the respective accessories of the designation marking holder.

**General ordering data**

Type	BZT 1 WS 10/5	Version
Order No.	<a href="#">1805490000</a>	Accessories, Marker holder
GTIN (EAN)	4032248270231	
Qty.	100 pc(s).	
Type	BZT 1 ZA WS 10/5	Version
Order No.	<a href="#">1805520000</a>	Accessories, Marker holder
GTIN (EAN)	4032248270248	
Qty.	100 pc(s).	