

**IE-BS-V04P-SCRJ2SC-SM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

PushPull plug-in connector set according to IEC  
61076-3-106 ver.4 (IEC24702), plastic with SC insert

**General ordering data**

Version	Flange FO, IP67, Version 4, coupling from SCRJ on 2*SC, Singlemode
Order No.	<a href="#">1963420000</a>
Type	IE-BS-V04P-SCRJ2SC-SM-C
GTIN (EAN)	4032248645510
Qty.	10 pc(s).

**IE-BS-V04P-SCRJ2SC-SM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	48.3 mm	Depth (inches)	1.902 inch
Height	38 mm	Height (inches)	1.496 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	29.3 g		

**Temperatures**

Operating temperature	-40 °C...70 °C
-----------------------	----------------

**General data**

Colour	Miscellaneous	Connection 1	SC
Connection 2	SCRJ	Description of article	Version 4, coupling from SCRJ on 2*SC
Fibre type	Singlemode	Housing main material	PA UL 94 V0
Insertion loss	≤ 0.5 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 40 dB

**General standards**

Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-4, IEC 61754-24
--------------------	---------------------------------------------------------

**Classifications**

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22

**Approvals**

ROHS	Conform
------	---------

**Downloads**

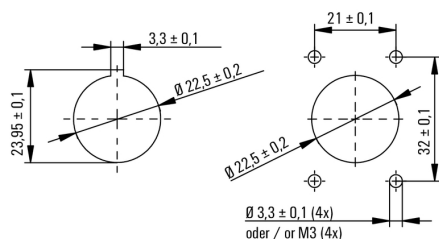
Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

**IE-BS-V04P-SCRJ2SC-SM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Drawings****Installation cut-out**

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

## IE-BS-V04P-SCRJ2SC-SM-C

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	<a href="#">1857440000</a>	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

## Dust caps



For protecting your devices against dust and dirt.

## General ordering data

Type	IE-BP-V04P	Version
Order No.	<a href="#">1963900000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248646326	
Qty.	10 pc(s).	