

**IE-BH-V04P****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

PushPull plug-in connector according to IEC  
61076-3-106 ver.4 (IEC24702), plastic, empty housing

**General ordering data**

Version	Empty enclosure, Flange-mounted housing, Variant 4 to IEC 61076-3-106, IP67
Order No.	<a href="#">1963520000</a>
Type	IE-BH-V04P
GTIN (EAN)	4032248645619
Qty.	10 pc(s).

## IE-BH-V04P

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	28.7 mm	Depth (inches)	1.13 inch
Height	38 mm	Height (inches)	1.496 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	14.5 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Colour	Miscellaneous	Housing main material	PA UL 94 V0
Plugging cycles	750	Protection degree	IP67
Type of mounting	4 screws, Central nut		

## General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 4
-------------------------	---------	--------------------	------------------------

## Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">DUXR.E316369</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

## IE-BH-V04P

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26


D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Installation cut-out

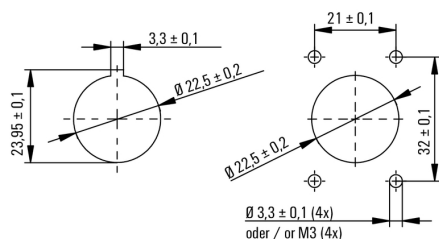

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

## IE-BH-V04P

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## LWL-LC

FO LC inserts for plug-in connectors ver.1 / 4 / 14



## General ordering data

Type	IE-BI-LCD-MM-C	Version
Order No.	<a href="#">1964420000</a>	LC insert, Bulkhead insert LC duplex, multimode
GTIN (EAN)	4032248649037	
Qty.	10 pc(s).	
Type	IE-BI-LCD-SM-C	Version
Order No.	<a href="#">1962880000</a>	LC insert, Bulkhead insert LC duplex, singlemode
GTIN (EAN)	4032248645077	
Qty.	10 pc(s).	

## RJ45

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,  
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

## General ordering data

Type	IE-BI-RJ45-C	Version
Order No.	<a href="#">1962840000</a>	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	<a href="#">1963830000</a>	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	<a href="#">1963840000</a>	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	<a href="#">1962850000</a>	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	

## IE-BH-V04P

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

## USB

USB inserts for FrontCom®



## General ordering data

Type	IE-BI-USB-A	Version
Order No.	<a href="#">1019570000</a>	USB insert, Flange insert, type A
GTIN (EAN)	4032248731602	
Qty.	10 pc(s).	

## Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	<a href="#">1857440000</a>	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

**IE-BH-V04P****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Hybrid**

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

**General ordering data**

Type	IE-BI-HYB-10P	Version
Order No.	<a href="#">1069010000</a>	Flange insert, for flange insert, Hybrid
GTIN (EAN)	4032248823970	
Qty.	10 pc(s).	
Type	IE-BIC-HYB-P-0,5-300	Version
Order No.	<a href="#">1096150000</a>	Crimp contact, for flange insert, Hybrid
GTIN (EAN)	4032248869114	
Qty.	300 pc(s).	

**Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V04P	Version
Order No.	<a href="#">1963900000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248646326	
Qty.	10 pc(s).	

**IE-BH-V04P****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****LWL-SC**

FO SC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-BI-SCRJ2SC-MM-C	Version
Order No.	<a href="#">1964430000</a>	SC insert, Bulkhead insert SCRJ to 2 SC, multimode
GTIN (EAN)	4032248649044	
Qty.	10 pc(s).	
Type	IE-BI-SCRJ2SC-SM-C	Version
Order No.	<a href="#">1962870000</a>	SC insert, Bulkhead insert SCRJ to 2 SC, singlemode
GTIN (EAN)	4032248645060	
Qty.	10 pc(s).	