

IE-FC-DIP-CI/3A/2ST/1D9**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Version	FrontCom, Insert plate, unshielded, 1 x GFCL, 1 x fuse, 2x Data, 1x Signal
Order No.	2003370000
Type	IE-FC-DIP-CI/3A/2ST/1D9
GTIN (EAN)	4050118387322
Qty.	1 pc(s).

IE-FC-DIP-CI/3A/2ST/1D9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	23 mm	Height (inches)	0.906 inch
Width	116.5 mm	Width (inches)	4.587 inch
Length	90.5 mm	Length (inches)	3.563 inch
Net weight	141.78 g		

Temperatures

Operating temperature	-35 °C...66 °C
-----------------------	----------------

General data

Material	Polycarbonate PC	Product type	Insert plate, unshielded
----------	------------------	--------------	--------------------------

Inserts

Insert GFCI / 2 x Power US pre-assembled	1	Insert fuse	1
Insert, data	2	Signal insert D-Sub 9-pole / VGA / HD-MI	1

Clampable conductors

Conductor connection cross-section, extremely flexible with wire end ferrule		1.5 ... 2.5 mm ²
Conductor connection cross-section, extremely flexible with wire end ferrule	max.	2.5 mm ²
	min.	1.5 mm ²
Conductor connection cross-section, extremely flexible without wire end ferrule ...		
Conductor connection cross-section, flexible with wire end ferrule	min.	1.5 mm ²
	max.	2.5 mm ²
Conductor connection cross-section, flexible with wire end ferrule		1.5 ... 2.5 mm ²
Conductor connection cross-section, flexible without wire end ferrule		...
Conductor connection cross-section, rigid	min.	1.5 mm ²
	max.	4 mm ²
Conductor connection cross-section, rigid		1.5 ... 4 mm ²
Stripping length		9 mm
Type of connection		Screw connection

Technical data GFCI

GFCI protected US outlet	2 pieces	Housing colour	grey
Operating voltage	125 V	Rated current	20 A
Self-test	automatically every 3 seconds	Status indication	red LED
Trip level, max.	6 mA	Trip level, min.	4 mA

Electrical properties

Operating voltage	125 V
-------------------	-------

IE-FC-DIP-CI/3A/2ST/1D9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

General standards

Certificate No. (CSA)	2000039-80039714	Certificate No. (cURus)	E223801
-----------------------	------------------	-------------------------	---------

Classifications

ETIM 6.0	EC000456	ETIM 7.0	EC000456
ETIM 8.0	EC000456	ETIM 9.0	EC000456
ECLASS 9.0	27-18-28-06	ECLASS 9.1	27-18-92-90
ECLASS 10.0	27-18-28-06	ECLASS 11.0	27-18-28-06
ECLASS 12.0	27-18-28-92	ECLASS 13.0	27-18-28-92

Environmental Product Compliance

REACH SVHC	Potassium perfluorobutane sulfonate 29420-49-3
SCIP	8a473a8a-33d4-4318-8088-c28f019e7f77

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E223801

Downloads

Engineering Data	CAD data – STEP
Product Change Notification	202201114 Technical change FrontCom GFCI 202201114 Technische Änderung zu FrontCom Vario GFCI
User Documentation	Designation key / Type key
Catalogues	Catalogues in PDF-format

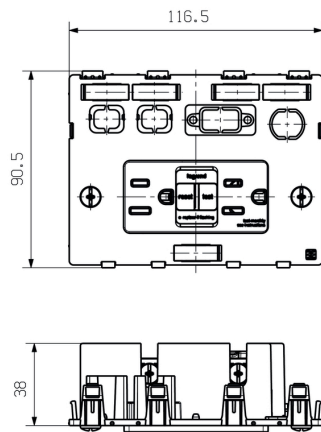
IE-FC-DIP-CI/3A/2ST/1D9

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing



IE-FC-DIP-CI/3A/2ST/1D9

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories**Accessories for FrontCom Vario****General ordering data**

Type	IE-FC-DFM-PWPC	Version
Order No.	2971460000	FrontCom, Touch-safe protection
GTIN (EAN)	4099986791541	
Qty.	1 pc(s).	

USB

USB inserts for FrontCom®

**General ordering data**

Type	IE-BI-USB-3.0-A	Version
Order No.	1487920000	USB insert, Flange insert, type A
GTIN (EAN)	4050118298208	
Qty.	1 pc(s).	
Type	IE-BI-USB-A	Version
Order No.	1019570000	USB insert, Flange insert, type A
GTIN (EAN)	4032248731602	
Qty.	10 pc(s).	
Type	IE-BI-USB-AB	Version
Order No.	1131380000	USB insert, Flange insert, type AB
GTIN (EAN)	4032248911844	
Qty.	10 pc(s).	

IE-FC-DIP-CI/3A/2ST/1D9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Fuse



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-FCI-PWCB-3A	Version
Order No.	1543690000	FrontCom, Fuse, Fuse insert
GTIN (EAN)	4050118348859	
Qty.	1 pc(s).	

Signal - VGA, HDMI



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-FCI-HDMI-FF	Version
Order No.	2003390000	FrontCom, HDMI coupling, Signal insert HDMI, Socket / socket
GTIN (EAN)	4050118387414	
Qty.	1 pc(s).	

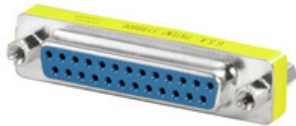
Type	IE-FCI-HD15-FF	Version
Order No.	1556290000	FrontCom, VGA coupling, Signal insert VGA/HD15, Socket / socket
GTIN (EAN)	4050118369755	
Qty.	1 pc(s).	

IE-FC-DIP-CI/3A/2ST/1D9**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Signal - D-SUB**

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-FCI-D9-FF	Version
Order No.	1450840000	FrontCom, Signal insert D-Sub, 9-pole, Socket / socket
GTIN (EAN)	4050118255737	
Qty.	1 pc(s).	
Type	IE-FCI-D9-FS	Version
Order No.	1450870000	FrontCom, Signal insert D-Sub, 9-pole, Socket / solder connection
GTIN (EAN)	4050118255393	
Qty.	1 pc(s).	
Type	IE-FCI-D9-FM	Version
Order No.	1450850000	FrontCom, Signal insert D-Sub, 9-pole, Plug, Socket connector
GTIN (EAN)	4050118255713	
Qty.	1 pc(s).	

IE-FC-DIP-CI/3A/2ST/1D9

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 7/20 SIRIUS MC NE WS	Version
Order No.	1736181044	ESG, Device markers x 20 mm, PA 66, Colour: white, pluggable
GTIN (EAN)	4008190985950	
Qty.	200 pc(s).	

RJ45



RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14, HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

General ordering data

Type	IE-BI-RJ45-C	Version
Order No.	1962840000	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	

IE-FC-DIP-CI/3A/2ST/1D9**Weidmüller Interface GmbH & Co. KG**

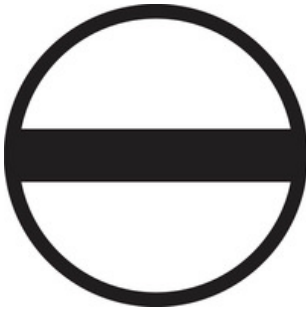
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories**

Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	

Slotted screwdriver

Slotted screwdriver with rounded blade SD DIN 5265,
ISO 2380/2, output to DIN 5264, ISO 2380/1.
ChromTop tip, SoftFinish grip

General ordering data

Type	SDS 0.4X2.5X75	Version
Order No.	9009030000	Screwdriver, Screwdriver
GTIN (EAN)	4032248266944	
Qty.	1 pc(s).	