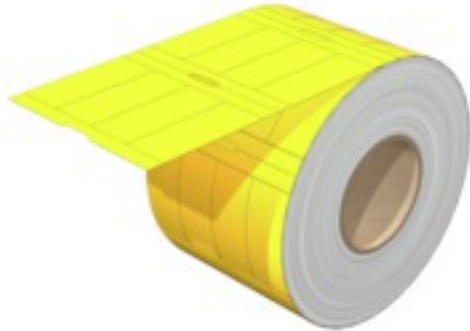


ELS 16/40 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**ELS**

ELS tags are special and non-adhesive insertable labels for WKM cable markers or for group tag carriers. The matt, thin but tear-resistant polyester provides very good labelling and excellent readability. Used in combination with water-repellent WKM sleeves, the solution guarantees particularly long-lasting identification of cables even in harsh environments.

General ordering data

Version	ELS, Insert markers, 40 x 16 mm, yellow
Order No.	2005260000
Type	ELS 16/40 MM GE
GTIN (EAN)	4050118389975
Qty.	2,000 pc(s).
compatible printer	2599430000 2599440000

ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.14 mm	Depth (inches)	0.006 inch
Height	40 mm	Height (inches)	1.575 inch
Width	16 mm	Width (inches)	0.63 inch
Net weight	0.168 g		

Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

General data

Colour	yellow	Halogen	No
Material	Polyester	Number per roll	2,000
Operating temperature range	-40...150 °C	Operating temperature range, max.	150 °C
Operating temperature range, min.	-40 °C	UL 94 flammability rating	HB
Version	halogen-free	Width	16 mm

Conductor and cable markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

Approvals

ROHS	Conform
------	---------

Downloads


Engineering Data	CAD data – STEP
Engineering Data	Zuken E3.S
Catalogues	Catalogues in PDF-format

ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

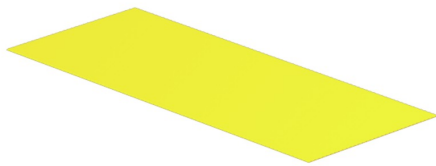

ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

WKM for inlay tags



The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking.

Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

General ordering data

Type	WKM 18/43	Version
Order No.	1610700000	WKM, Conductor and cable markers, 7 - 115 mm, 43 x 18 mm, Wire
GTIN (EAN)	4008190204488	and cable markers, Transparent
Qty.	50 pc(s).	

ELS 16/40 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

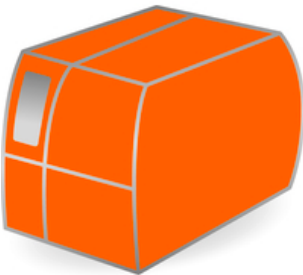THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).