

IE-CDR-V14MSCPOF/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FreeCon Active PROFINET repeater for PushPull Var.14
plug-in connectors according to IEC 61076-3-117 and
PushPull Power according to the PROFINET specification

General ordering data

Version	PROFINET POF Repeater, FreeCon, IP65
Order No.	2455360000
Type	IE-CDR-V14MSCPOF/VAPM-C II
GTIN (EAN)	4050118469967
Qty.	1 pc(s).

IE-CDR-V14MSCPOF/VAPM-C II

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	53 mm	Depth (inches)	2.087 inch
Width	100 mm	Width (inches)	3.937 inch
Length	130.4 mm	Length (inches)	5.134 inch
Net weight	0.773 g		

Temperatures

Operating temperature	-20 °C...55 °C
-----------------------	----------------

General data

Data interface	PROFINET PushPull SCRJ POF (V14)	Plugging cycles	≥ 100
Power interface	PROFINET PushPull Power	Protection degree	IP65
UL 94 flammability rating	V-0	Wiring	PROFINET

Electrical properties

Baud rate	100 MB	Current consumption	200 mA typical
LED indicator	FO1: port active, FO2: port active, SF: general error, BF: bus error, US1: voltage 1 (electronics), US2: voltage 2, ACT1: activity Port 1, ACT2: activity Port 2	Operating voltage	24 V
Operational voltage range	18...30 V DC	Protocol	PROFINET IRT

General standards

Certificate no. (cULus)	E141197	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
Network standard	IEC 61158, IEC 61784	PROFINET specification	Conformance Class C acc. V2.3

Classifications

ETIM 6.0	EC000732	ETIM 7.0	EC000732
ETIM 8.0	EC000732	ETIM 9.0	EC000732
ECLASS 9.0	19-17-02-06	ECLASS 9.1	19-17-01-25
ECLASS 10.0	19-17-02-06	ECLASS 11.0	19-17-02-06
ECLASS 12.0	19-17-02-06	ECLASS 13.0	19-17-02-06

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

Important note

Product information	Further development of 1253240000, IE-CDR-V14MSCPOF/VAPM-C. For commissioning, the new GSDML file (see Downloads) must be installed.
---------------------	--

IE-CDR-V14MSCPOF/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E141197

Downloads

Approval/Certificate/Document of Conformity	PNO_Zertifikat_2455360000 IE-CDR-V14MSCPOF/VAPM-C II
Engineering Data	CAD data – STEP
Product Change Notification	PCN DE FreeCon Active POF Repeater PCN DE FreeCon Active POF Repeater
Software	Runtime Software – CFG configurator - Weidmueller_FreeCon Firmware – Firmware ABCC_40_PIR-FO_7360_1_13_05.hiff Device description – GSDML-V2.35 POF
User Documentation	Firmware update manual Manual EN Manual DE
Catalogues	Catalogues in PDF-format


IE-CDR-V14MSCPOF/VAPM-C II

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Drawings


Dimensioned drawing

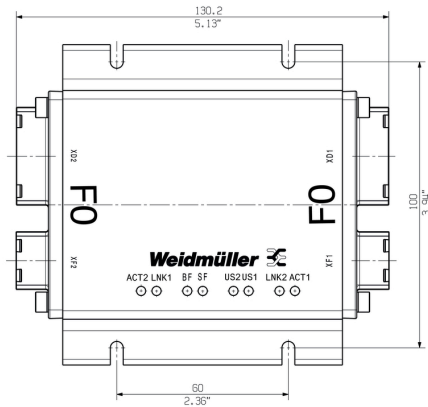

Dimensioned drawing

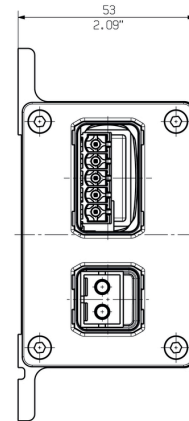

Wiring diagram

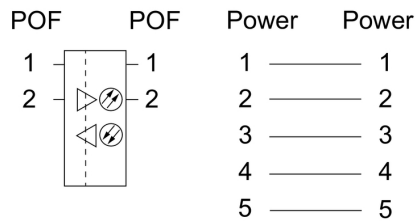

IE-CDR-V14MSCPOF/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Sets**

PushPull Power plug-in connector according to PROFINET specification

General ordering data

Type	IE-PS-VAPM-5P-2.5	Version
Order No.	2465440000	Power connector, Plug, PROFINET, Set of connectors
GTIN (EAN)	4050118522136	
Qty.	1 pc(s).	