

IE-BHD-VAPM**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

PushPull Power plug-in connector according to PROFINET specification

General ordering data

Version	Power connector, Device flange, PROFINET
Order No.	2493490000
Type	IE-BHD-VAPM
GTIN (EAN)	4050118529104
Qty.	1 pc(s).

IE-BHD-VAPM

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	42 mm	Height (inches)	1.654 inch
Width	36.2 mm	Width (inches)	1.425 inch
Length	14.2 mm	Length (inches)	0.559 inch
Net weight	23 g		

Temperatures

Operating temperature	-40 °C...80 °C
-----------------------	----------------

General data

Colour	Silver grey	Housing main material	Zinc diecast, nickel-plated
Plugging cycles	500	Pollution severity	2
Protection degree	IP67	Sealing material	NBR
Shielding	unshielded	Type of interlock	Push Pull
Type of mounting	4 screws		

General standards

Certificate No. (UR)	E92202
----------------------	--------

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90

Approvals

Approvals



UL File Number Search	UL Website
Certificate No. (UR)	E92202

Downloads

Approval/Certificate/Document of Conformity	PROFINET Manufacturer's Declaration
Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format


IE-BHD-VAPM

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

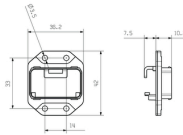

Installation cut-out

