

ES EPG/HPG 60 HEX 50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration****Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 1.5 Ah

General ordering data

Version	Crimping tool insert, Hexagonal crimp
Order No.	2505200000
Type	ES EPG/HPG 60 HEX 50
GTIN (EAN)	4050118519600
Qty.	1 pc(s).

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.866 inch
Height	42 mm	Height (inches)	1.654 inch
Width	42 mm	Width (inches)	1.654 inch
Net weight	138 g		

Crimp inserts

Crimp cross-section aluminium	35	Crimp cross-section copper	50
Crimping width	5 mm	Crimping width in mm	5
Identification number	14		

Description of contact

Conductor cross-section, max. AWG	1	Type of contact	DIN 46235 cable lug, DIN 46267 Part 1 cable lug
-----------------------------------	---	-----------------	---

tool data crimping

Cable lug cross section	nominal	50 mm ²
Crimping type/profile	Hexagonal crimp	

Classifications

ETIM 6.0	EC001282	ETIM 7.0	EC001282
ETIM 8.0	EC001282	ETIM 9.0	EC001282
ECLASS 9.0	21-04-90-90	ECLASS 9.1	21-01-90-90
ECLASS 10.0	21-04-90-90	ECLASS 11.0	21-04-90-90
ECLASS 12.0	21-04-90-90	ECLASS 13.0	21-04-90-90

Downloads

Catalogues	Catalogues in PDF-format
------------	--

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPLN/-50	Version
Order No.	1492930000	cable lug, terminal end, 50 mm ² , 50 mm ²
GTIN (EAN)	4050118302684	
Qty.	100 pc(s).	

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data

Type	HPG 60	Version
Order No.	2453820000	6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp,
GTIN (EAN)	4050118468427	Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

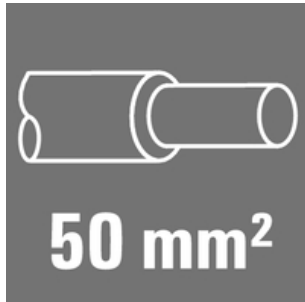
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M6/-50 S	Version
Order No.	1494820000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118304114	
Qty.	25 pc(s).	
Type	KRN-M10/-50 S	Version
Order No.	1494840000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118304619	
Qty.	25 pc(s).	
Type	KRN-M8/-50 S	Version
Order No.	1494830000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118304404	
Qty.	25 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KP-M20/-50	Version
Order No.	1498120000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307597	
Qty.	100 pc(s).	
Type	KP-M6/-50	Version
Order No.	1498510000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118308006	
Qty.	100 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KP-M8/-50	Version
Order No.	1498070000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307566	
Qty.	100 pc(s).	
Type	KP-M14/-50	Version
Order No.	1498570000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118308105	
Qty.	100 pc(s).	
Type	KP-M16/-50	Version
Order No.	1498110000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307474	
Qty.	100 pc(s).	
Type	KP-M12/-50	Version
Order No.	1498090000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307375	
Qty.	100 pc(s).	
Type	KP-M10/-50	Version
Order No.	1498080000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307559	
Qty.	100 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M12/-50 90	Version
Order No.	1495990000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305654	
Qty.	100 pc(s).	
Type	KWN-M8/-50 90	Version
Order No.	1495970000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305425	
Qty.	100 pc(s).	
Type	KWN-M20/-50 90	Version
Order No.	1494710000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118304442	
Qty.	100 pc(s).	
Type	KWN-M14/50 90	Version
Order No.	1494650000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118304251	
Qty.	100 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KWN-M16/-50 90	Version
Order No.	1496000000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305630	
Qty.	100 pc(s).	
Type	KWN-M10/-50 90	Version
Order No.	1495980000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305494	
Qty.	100 pc(s).	
Type	KWN-M6/-50 90	Version
Order No.	1495950000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305388	
Qty.	100 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

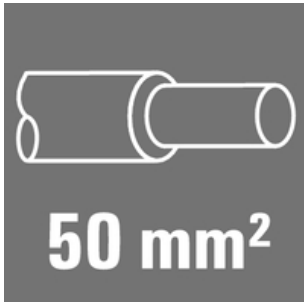
Type	KWPN-M16/-50 90	Version
Order No.	1497630000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307115	
Qty.	100 pc(s).	
Type	KWPN-M12/-50 90	Version
Order No.	1497620000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306675	
Qty.	100 pc(s).	
Type	KWPN-M8/-50 90	Version
Order No.	1497590000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306699	
Qty.	100 pc(s).	
Type	KWPN-M10/-50 90	Version
Order No.	1497610000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118307078	
Qty.	100 pc(s).	

ES EPG/HPG 60 HEX 50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****50 mm²**

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/50	Version
Order No.	1493070000	cable lug, terminal end, 50 mm ² , 50 mm ²
GTIN (EAN)	4050118302691	
Qty.	100 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/-50	Version
Order No.	1494750000	cable lug, terminal end, 50 mm ² , 50 mm ²
GTIN (EAN)	4050118304381	
Qty.	50 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KSN/-50	Version
Order No.	1492820000	cable lug, terminal end, 50 mm ² , 50 mm ²
GTIN (EAN)	4050118302769	
Qty.	50 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M10/-50	Version
Order No.	1496610000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306064	
Qty.	100 pc(s).	
Type	KRN-M12/-50	Version
Order No.	1496620000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305722	
Qty.	100 pc(s).	
Type	KRN-M16/-50	Version
Order No.	1496630000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306200	
Qty.	100 pc(s).	
Type	KRN-M20/-50	Version
Order No.	1495840000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305364	
Qty.	100 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KRN-M6/-50	Version
Order No.	1496590000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305746	
Qty.	100 pc(s).	
Type	KRN-M8/-50	Version
Order No.	1496600000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306149	
Qty.	100 pc(s).	
Type	KRN-M14/-50	Version
Order No.	1495750000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305197	
Qty.	100 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M12/-50 45	Version
Order No.	1496300000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306040	
Qty.	50 pc(s).	
Type	KWN-M6/-50 45	Version
Order No.	1496270000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305937	
Qty.	50 pc(s).	
Type	KWN-M10/-50 45	Version
Order No.	1496290000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118305760	
Qty.	50 pc(s).	
Type	KWN-M8/-50 45	Version
Order No.	1496280000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118306101	
Qty.	50 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Tools

**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 1.5 Ah

General ordering data

Type	EPG 60	Version
Order No.	2453810000	Pressing tools, Tools, Pressing tool, 6mm ² , 300mm ² , Hexagonal crimp,
GTIN (EAN)	4050118468434	WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

50 mm²**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KQN-M10/-50	Version
Order No.	1493160000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118303049	
Qty.	50 pc(s).	
Type	KQN-M12/-50	Version
Order No.	1493170000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118303216	
Qty.	50 pc(s).	
Type	KQN-M20/-50	Version
Order No.	1493530000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118303513	
Qty.	50 pc(s).	
Type	KQN-M8/-50	Version
Order No.	1493150000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118302868	
Qty.	50 pc(s).	

ES EPG/HPG 60 HEX 50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KQN-M6/-50	Version
Order No.	1493510000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118303179	
Qty.	50 pc(s).	
Type	KQN-M16/-50	Version
Order No.	1493180000	cable lug, terminal end, 50 mm ²
GTIN (EAN)	4050118302844	
Qty.	50 pc(s).	

50 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPN/-50	Version
Order No.	1498660000	cable lug, terminal end, 50 mm ² , 50 mm ²
GTIN (EAN)	4050118307948	
Qty.	50 pc(s).	