

FF-FIMT 3X 54


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

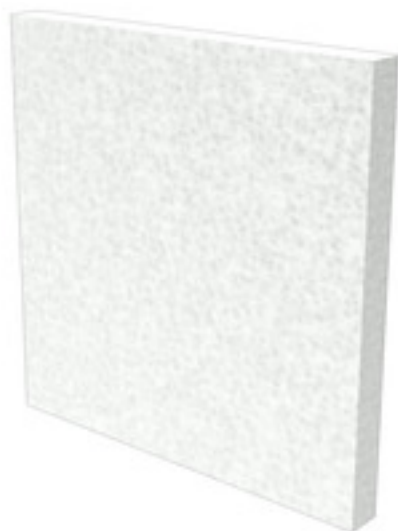

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

Általános rendelési adatok

Verzió	Filter mat, IP54, fehér
Rendelési szám	2556720000
Típus	FF-FIMT 3X 54
GTIN (EAN)	4050118567342
Qty.	5 Stück

FF-FIMT 3X 54

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Műszaki adatok

Méretetek és tömegek

Magasság	170 mm	Magasság (coll)	6,693 inch
Szélesség	170 mm	Szélesség (coll)	6,693 inch
Nettó tömeg	9,2 g		

Hőmérsékletek

Üzemi hőmérsékleti tartomány	-40...55 °C
------------------------------	-------------

General data

Felszerelés típusa	Felpattintható	Filter class	G 4
Protection class (UL)	Type 12	Szín	fehér
With filter	Igen	Üzemi hőmérsékleti tartomány	-40...55 °C

Besorolások

ETIM 6.0	EC002513	ETIM 7.0	EC002513
ETIM 8.0	EC002513	ETIM 9.0	EC002513
ECLASS 9,1	27-18-07-06	ECLASS 10.0	27-18-07-06
ECLASS 11.0	27-18-07-06	ECLASS 12.0	27-18-07-06
ECLASS 13.0	27-18-07-06		

Tanúsítványok

ROHS	Megfelel
------	----------

Letöltések

User Documentation	Operating instructions
Katalógusok	Catalogues in PDF-format