 


**FF-EMC 43 54/230V GY****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

For use near electromagnetic fields. Secure contact surface without the need for a beryllium copper seal and particularly environmentally friendly as no metal reinforced plastics are required.

**General ordering data**

Version	Filter fan, IP54, grey
Order No.	<a href="#">2557390000</a>
Type	FF-EMC 43 54/230V GY
GTIN (EAN)	4050118568028
Qty.	1 pc(s).
Available until	2023-11-10

## FF-EMC 43 54/230V GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	119 mm	Depth (inches)	4.685 inch
Height	252 mm	Height (inches)	9.921 inch
Width	252 mm	Width (inches)	9.921 inch
Net weight	1,330 g		

## Temperatures

Operating temperature range	-40...55 °C
-----------------------------	-------------

## General data

Colour	grey		
Current consumption	Mains frequency	50 Hz	
	Current	0.32 A	
	Mains frequency	60 Hz	
	Current	0.26 A	
EMC version	EN 61000-3-2,-3, EN 61000-6-2, 3		
Fan type	Shelf		
Filter class	G 4		
Fuse	6 A		
Height of installation cut-outs	224 mm		
MTBF	40,000 h		
Mounting depth	113 mm		
Mounting height	6 mm		
Noise emission	42 dB(A)		
Operating temperature range	-40...55 °C		
Power	Mains frequency	50 Hz	
	nominal	45 W	
	Mains frequency	60 Hz	
	nominal	39 W	
Protection class (UL)	Type 12		
Rated AC voltage	230 V		
Rated voltage	230 V AC $\pm$ 10%		
Size	4		
Type of connection	Spring contact		
Type of mounting	Snap-on		
UL 94 flammability rating	V-0		
Volume flow with exhaust filter	Mains frequency	50 Hz	
	Volume flow	231 m <sup>3</sup> /h	
	Exhaust filter	IP54	
	Mains frequency	60 Hz	
	Volume flow	265 m <sup>3</sup> /h	
	Exhaust filter	IP54	
Volume flow, free-blowing	Mains frequency	50 Hz	
	Volume flow	256 m <sup>3</sup> /h	
	Mains frequency	60 Hz	
	Volume flow	292 m <sup>3</sup> /h	
Volume flow, free-blowing at 50 Hz	256 m <sup>3</sup> /h		
Volume flow, free-blowing at 60 Hz	292 m <sup>3</sup> /h		
Width of installation cut-outs	224 mm		
With filter	Yes		

**FF-EMC 43 54/230V GY****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Classifications**

ETIM 6.0	EC000320	ETIM 7.0	EC000320
ETIM 8.0	EC000320	ETIM 9.0	EC000320
ECLASS 9.1	27-18-07-16	ECLASS 10.0	27-18-07-16
ECLASS 11.0	27-18-07-16	ECLASS 12.0	27-18-07-16
ECLASS 13.0	27-18-07-16		

**Approvals**

ROHS	Conform
------	---------

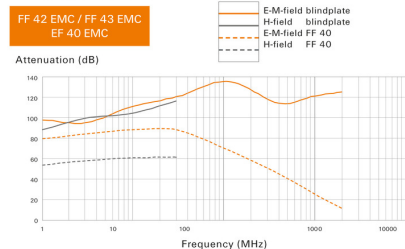
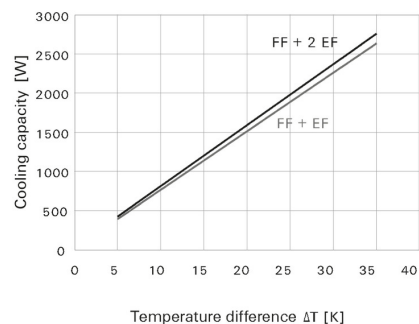
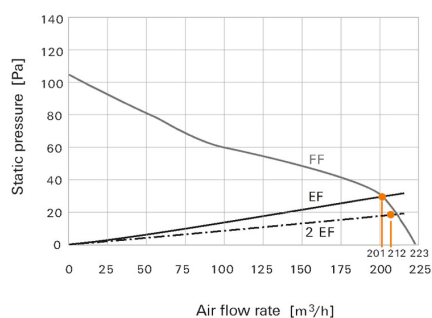
**Downloads**

Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity</a>
User Documentation	<a href="#">Installation- and operating instructions</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**FF-EMC 43 54/230V GY**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings****Graph****Shielding effectiveness measurements****Graph****Graph**

## FF-EMC 43 54/230V GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Exhaust filter



The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats. Thought out details as the functional flap cover enable a fast and tool-less change of the filter mats which saves time and money.

## General ordering data

Type	EF-EMC 40 54 GY	Version
Order No.	<a href="#">2557650000</a>	Exhaust filter, IP54, grey
GTIN (EAN)	4050118568295	
Qty.	1 pc(s).	
Type	EF-EMC 40 55 BK	Version
Order No.	<a href="#">2557680000</a>	Exhaust filter, IP55, black
GTIN (EAN)	4050118568325	
Qty.	1 pc(s).	
Type	EF-EMC 40 55 GY	Version
Order No.	<a href="#">2557670000</a>	Exhaust filter, IP55, grey
GTIN (EAN)	4050118568318	
Qty.	1 pc(s).	
Type	EF-EMC 40 54 BK	Version
Order No.	<a href="#">2557660000</a>	Exhaust filter, IP54, black
GTIN (EAN)	4050118568301	
Qty.	1 pc(s).	

## Filter fan



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

## General ordering data

Type	FF-FIMT 4X 55	Version
Order No.	<a href="#">2556800000</a>	Filter mat, IP55, white
GTIN (EAN)	4050118567427	
Qty.	5 pc(s).	
Type	FF-FIMT 4X 54	Version
Order No.	<a href="#">2556790000</a>	Filter mat, IP54, white
GTIN (EAN)	4050118567410	
Qty.	5 pc(s).	