

IE-CDM-V14MRJSCP/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FreeCon Active PROFINET media converter with diagnostic functionality, for PushPull Var.14 plug-in connector acc. to IEC 61076-3-117 with RJ45 and SC-RJ POF acc. to IEC 61754-24 and PushPull Power acc. to PROFINET specification.

General ordering data

Version	POF media converter, FreeCon, IP65
Order No.	2588270000
Type	IE-CDM-V14MRJSCP/VAPM-C II
GTIN (EAN)	4050118598322
Qty.	1 pc(s).

IE-CDM-V14MRJSCP/VAPM-C II

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	130.4 mm	Depth (inches)	5.134 inch
Height	53 mm	Height (inches)	2.087 inch
Width	100 mm	Width (inches)	3.937 inch
Net weight	557.7 g		

Temperatures

Operating temperature	-20 °C...55 °C
-----------------------	----------------

General data

Data interface	PROFINET PushPull SCRJ POF (V14), PROFINET PushPull RJ45 (V14)	Housing main material	Aluminium profile, Zinc die cast, electroplated lid
Plugging cycles	≥ 100	Power interface	PROFINET PushPull Power
Protection degree	IP65	UL 94 flammability rating	V-0
Wiring	PROFINET		

Electrical properties

Baud rate	100 MB	Current consumption	200 mA typical
LED indicator	P1: port active, P2: port active, SF: general error, BF: bus error, US1: voltage 1 (electronics), US2: voltage 2, ACT1: activity Port1, ACT2: activity Port2	Operating voltage	24 V
Operational voltage range	18...30 V DC	Protocol	PROFINET IRT

General standards

Certificate no. (cULus)	E141197	Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24, IEC 60603-7-51
Network standard	IEC 61158, IEC 61784	PROFINET specification	Conformance Class C acc. V2.3

Classifications

ETIM 6.0	EC001467	ETIM 7.0	EC001467
ETIM 8.0	EC001467	ETIM 9.0	EC001467
ECLASS 9.0	19-17-01-14	ECLASS 9.1	19-17-01-14
ECLASS 10.0	19-17-01-32	ECLASS 11.0	19-17-01-32
ECLASS 12.0	19-17-01-32	ECLASS 13.0	19-17-01-14

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	b14ea46f-06a9-4191-9f88-14cc6c04a8a8

Important note

Product information	Further development of 1324440000, IE-CDM-V14MRJSCP/VAPM-C. For commissioning, the new GSDML file (see Downloads) must be installed.
---------------------	--

IE-CDM-V14MRJSCP/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E141197

Downloads

Approval/Certificate/Document of Conformity	Profinet Certification EU declaration of conformity
Engineering Data	CAD data – STEP
Software	Runtime Software – CFG configurator - Weidmueller_FreeCon Firmware – Firmware 1_02_01 / GSD - V2.34
User Documentation	Manual DE Hardware Installation Guide
Catalogues	Catalogues in PDF-format


IE-CDM-V14MRJSCP/VAPM-C II

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Drawings


Dimensioned drawing

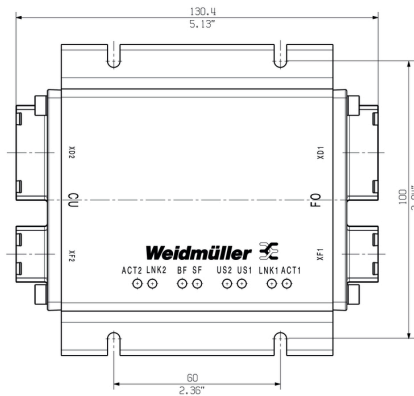

Dimensioned drawing

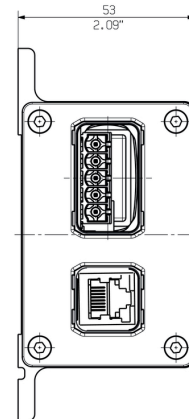

Wiring diagram

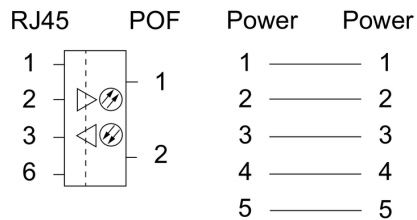

IE-CDM-V14MRJSCP/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****SC-RJ**

PushPull plug-in connector set according to IEC
61076-3-117 ver.14 (PROFINET), metal incl. SC insert

General ordering data

Type	IE-PS-V14M-2SC-POF	Version
Order No.	1191550000	FO connector, Version 14, SC-RJ POF, IP67
GTIN (EAN)	4032248974436	
Qty.	10 pc(s).	
Type	IE-PS-V14M-2SC-POF-QA	Version
Order No.	2568260000	FO connector, Version 14, SC-RJ POF, reconnectable, IP67
GTIN (EAN)	4050118578928	
Qty.	10 pc(s).	

Sets

PushPull Power plug-in connector according to PROFINET
specification

General ordering data

Type	IE-PS-VAPM-5P-2.5	Version
Order No.	2465440000	Power connector, Plug, PROFINET, Set of connectors
GTIN (EAN)	4050118522136	
Qty.	1 pc(s).	

IE-CDM-V14MRJSCP/VAPM-C II**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Sets - RJ45**

PushPull plug-in connector set according to IEC
61076-3-117 ver.14 (PROFINET), metal incl. RJ45 insert

General ordering data

Type	IE-PS-V14M-RJ45-FH-P	Version
Order No.	1012170000	Plug insert RJ45 tool-free, Variant 14 metal, Cat.5 (ISO/IEC 11801)
GTIN (EAN)	4032248719815	
Qty.	10 pc(s).	