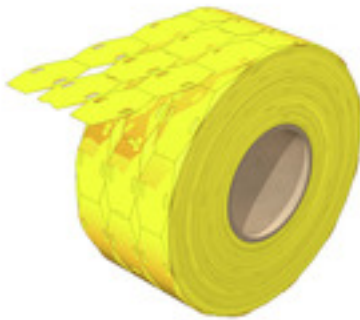


**SFX-VT 9/24 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Highly flexible: SFX**

SFX markers are the preferred choice for labelling cables if you prefer the classic cable tie solution. Cables do not always run in a straight line. The material used in SFX markers addresses this fact with highly flexible polyurethane. The marker follows each curve of the cable and latches on with ease. Your advantages at a glance: Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours

Individually labeled with the M-Print® PRO

Easy and fast printing with the THM MultiMark

**General ordering data**

Version	SlimFix, Conductor and cable markers, 7 -, 26 x 15 mm, yellow
Order No.	<a href="#">2621460000</a>
Type	SFX-VT 9/24 MM GE
GTIN (EAN)	4050118625585
Qty.	1,000 pc(s).
compatible printer	<a href="#">2599430000</a> <a href="#">2599440000</a>

**SFX-VT 9/24 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Height	26 mm	Height (inches)	1.024 inch
Width	15 mm	Width (inches)	0.591 inch
Net weight	0.2 g		

**Temperatures**

Operating temperature range	-55...105 °C
-----------------------------	--------------

**General data**

Colour	yellow	Halogen	No
Material	Polyolefine	Operating temperature range	-55...105 °C
Operating temperature range, max.	105 °C	Operating temperature range, min.	-55 °C
Size of labelling field	23.5 x 9 mm	UL 94 flammability rating	HB
Version	halogen-free	Width	15 mm

**Conductor and cable markers**

Cable tie passage	Flat	Conductor O.D.	7 -
Conductor O.D., min.	7 mm	Halogen	No
Suitable cable tie	Plastic		

**Classifications**

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
White paper	<a href="#">Fact Sheet PV Markierer</a> <a href="#">Fact Sheet EN PV Markers</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**SFX-VT 9/24 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**



**SFX-VT 9/24 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MM PLUS ROLLER 110
Order No.	<a href="#">2672590000</a>
GTIN (EAN)	4050118708097
Qty.	1 pc(s).

**Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM-HS 60/300 SW	Version
Order No.	<a href="#">2448880000</a>	Ink ribbon
GTIN (EAN)	4050118462944	
Qty.	1 pc(s).	

**SFX-VT 9/24 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	THM MMP ROLLER 115
Order No.	<a href="#">1357420000</a>
GTIN (EAN)	4050118160314
Qty.	1 pc(s).