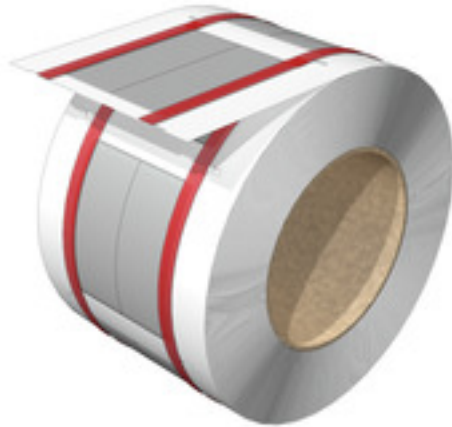


HS-FR 19.1-38.1/25 MM W**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 19.1 - 38.1 mm, 24.9 x 60.8 mm, white
Order No.	2621720000
Type	HS-FR 19.1-38.1/25 MM W
GTIN (EAN)	4050118625325
Qty.	200 pc(s).
compatible printer	2599430000 2599440000

HS-FR 19.1-38.1/25 MM W**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	0.77 mm	Depth (inches)	0.03 inch
Height	24.9 mm	Height (inches)	0.98 inch
Width	60.8 mm	Width (inches)	2.394 inch
Net weight	2.35 g		

Temperatures

Operating temperature range	-55...125 °C
-----------------------------	--------------

General data

Colour	white	Halogen	No
Material	Polyolefine	Operating temperature range	-55...125 °C
Operating temperature range, max.	125 °C	Operating temperature range, min.	-55 °C
Size of labelling field	60.8 x 24.9 mm	Width	60.8 mm

Conductor and cable markers

Conductor O.D.	19.1 - 38.1 mm	Conductor O.D., max.	38.1 mm
Conductor O.D., min.	19.1 mm	Conductor cross-section, max.	240 mm ²
Conductor cross-section, min.	70 mm ²	Cross-section for connected wire	70 - 240 mm ²
Halogen	No	Rate of shrinkage	2:1
Recommended shrinking temperature	90 °C	Wire connection cross section AWG, max.	AWG 450 MCM
Wire connection cross section AWG, min.	AWG 2/0		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--

HS-FR 19.1-38.1/25 MM W

Weidmüller Interface GmbH & Co. KG


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings

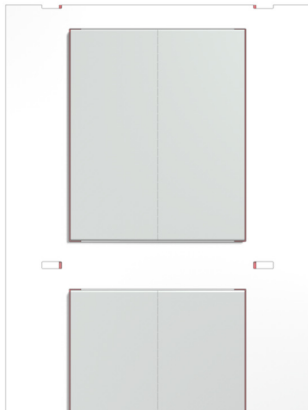

HS-FR 19.1-38.1/25 MM W**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).

Ink ribbons

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-HS 60/300 SW	Version
Order No.	2448880000	Ink ribbon
GTIN (EAN)	4050118462944	
Qty.	1 pc(s).	

HS-FR 19.1-38.1/25 MM W**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).