

FP ENC BSTS 155 2M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The FieldPower® housings are highly robust and meet the highest UL flammability class 5 VA.

- The "TS 35 PT6" mounting rail module and PT6 contact unit are easy to snap on.
- Hinged seals allow pre-assembled plug cables to also be used.
- The high cover versions enable the device to be installed.

For cable seals consult accessories.

General ordering data

| | |
|------------|--|
| Version | FieldPower® enclosures, 196 mm, 196 mm, 155 mm, IP65, in complete state, Polycarbonate, glass-fibre reinforced polycarbonate, black, Transparent |
| Order No. | 2659760000 |
| Type | FP ENC BSTS 155 2M |
| GTIN (EAN) | 4050118704730 |
| Qty. | 1 pc(s). |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|----------|-----------------|------------|
| Depth | 155 mm | Depth (inches) | 6.102 inch |
| Height | 196 mm | Height (inches) | 7.717 inch |
| Width | 196 mm | Width (inches) | 7.717 inch |
| Net weight | 691.82 g | | |

Temperatures

| | | | |
|---------------------|----------------|-----------------------|----------------|
| Storage temperature | -40 °C...85 °C | Operating temperature | -40 °C...85 °C |
|---------------------|----------------|-----------------------|----------------|

General data

| | | | |
|-----------------------|--|---------------------------|---|
| Material | Polycarbonate, glass fibre reinforced, Polycarbonate | Enclosure material | Polycarbonate, glass-fibre reinforced polycarbonate |
| Silicone | No | Colour | black, Transparent |
| Protection degree | IP65, in complete state | UL 94 flammability rating | V-0 |
| Torque for lid screws | 2 Nm | Lid attachment | TX20 screws |
| Type of mounting | Screw mounting, Fixing lugs | Installation advice | Lid screws included |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000261 | ETIM 7.0 | EC000261 |
| ETIM 8.0 | EC000261 | ETIM 9.0 | EC000261 |
| ECLASS 9.0 | 27-18-01-01 | ECLASS 9.1 | 27-18-92-90 |
| ECLASS 10.0 | 27-18-01-01 | ECLASS 11.0 | 27-18-01-01 |
| ECLASS 12.0 | 27-18-01-01 | ECLASS 13.0 | 27-18-01-01 |

Environmental Product Compliance

| | |
|------------|--|
| REACH SVHC | Potassium perfluorobutane sulfonate 29420-49-3 |
| SCIP | 5f19cd84-8946-4797-9386-3ac323b95c10 |

Approvals

Approvals



| | |
|-------------------------|------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate no. (cULus) | E256877 |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads



| | |
|---|--|
| Approval/Certificate/Document of Conformity | UL Certificate FieldPower® complete enclosures Manufacturer's Declaration FieldPower® Enclosure parts |
| Engineering Data | CAD data – STEP Application notes – Application note FieldPower® size 2 and 3 plastic enclosure temperature information Application notes – Applikationshinweis FieldPower® Größe 2 und 3 Kunststoffgehäuse Temperaturbewertung Success story – FieldPower® customer reference PRO-EL Success story – FieldPower® Kundenreferenz PRO-EL Application note FieldPower® ur20 and uc20 Applikationshinweis FieldPower® ur20 und uc20 |
| User Documentation | Manual FieldPower® enclosure size 2 |
| Catalogues | Catalogues in PDF-format |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

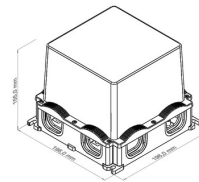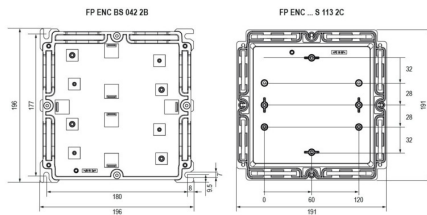

FP ENC BSTS 155 2M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany


www.weidmueller.com**Accessories****Terminal rails for plastic cover**

Extensive range of accessories for the FieldPower® boxes.

Cable seals, terminal rails, locking elements and much more.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | FP ENC DR07 142 XC P | Version |
| Order No. | 2633510000 | Field Power® terminal rail, Steel, galvanized, 142 mm, for plastic lid |
| GTIN (EAN) | 4050118664393 | |
| Qty. | 5 pc(s). | |

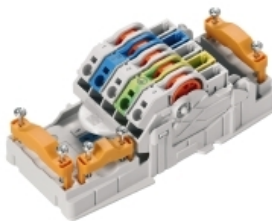AC

Power distribution using uncut cables with cross-sections from 1.5 to 6 mm².

Power supply / T-branch tap via PUSH IN connection (0.5 to 10 mm²) and/or plug-in connection (0.5 to 4 mm²). Coloured markings provide clear assignment of wires.

- Power supply
- Power distribution
- Power branching

General ordering data

| | | |
|------------|----------------------------|---|
| Type | PT6 | Version |
| Order No. | 1957620000 | FieldPower® contact element, AC, IP20, Insulation displacement connection (IDC), PUSH IN, Number of poles : 5 |
| GTIN (EAN) | 4032248642489 | |
| Qty. | 1 pc(s). | |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Terminal rails for lower parts of enclosure



Extensive range of accessories for the FieldPower® boxes.

Cable seals, terminal rails, locking elements and much more.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | TS 35 PT6 | Version |
| Order No. | 1170690000 | Field Power® terminal rail, Steel, galvanized, 54 mm, for base part |
| GTIN (EAN) | 4032248962532 | |
| Qty. | 10 pc(s). | |

| | | |
|------------|----------------------------|--|
| Type | FP ENC DR07 142 XB | Version |
| Order No. | 2633450000 | Field Power® terminal rail, Steel, galvanized, 142 mm, for base part |
| GTIN (EAN) | 4050118664416 | |
| Qty. | 5 pc(s). | |

Plastic lock nuts, grey



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | SKMU M20 - K GR | Version |
| Order No. | 1772460000 | SKMU PA (plastic locknut), Locknut, M 20, 6 mm, Polyamid 6 (PA6 - GF30) |
| GTIN (EAN) | 4032248130207 | |
| Qty. | 100 pc(s). | |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Bits E6,3 - Torx®



The Weidmüller bits are standard bits which are highly popular with users thanks to their good quality, large range and efficiency. The computer-controlled hardening method enables Weidmüller to guarantee a consistently high standard of quality.

The high-quality raw materials used make it possible to reach torques far higher than any of those specified in the relevant DIN standards:

- DIN 5261 for PH/PZ bits,
- DIN 5263 for slotted bits,
- Camcar standard for TORX bits

That means a long life at high torques and hence ideal conditions for standard situations.


The benefits:

- Suitable for all types of screws. Because of their excellent hardness values of 59-61 HRC, they are suitable for use with both manual and power tools.
- Good wearing resistance and thus a long life expectancy.
- Optimum fit in all DIN screws means low wear and optimum torque transmission.
- Manufactured to meet professional quality criteria according to relevant ISO standards with a consistently high standard of quality.

General ordering data

| | | |
|------------|----------------------------|---------------|
| Type | BIT E6,3 T20 X 150 | Version |
| Order No. | 2821510000 | Mounting tool |
| GTIN (EAN) | 4064675359050 | |
| Qty. | 50 pc(s). | |

DC

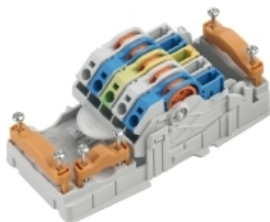

Power distribution using uncut cables with cross-sections from 1.5 to 6 mm².

Power supply / T-branch tap via PUSH IN connection (0.5 to 10 mm²) and/or plug-in connection (0.5 to 4 mm²). Coloured markings provide clear assignment of wires.

- Power supply
- Power distribution
- Power branching

General ordering data

| | | |
|------------|----------------------------|--|
| Type | PT6 DC | Version |
| Order No. | 1126840000 | FieldPower® contact element, DC, IP20, Insulation displacement |
| GTIN (EAN) | 4032248908462 | connection (IDC), PUSH IN, Number of poles : 5 |
| Qty. | 1 pc(s). | |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Adapters

**HQ adapter for FieldPower®**

Tool-free installation like a FieldPower cable seal
Suitable for the HQ 4/2, HQ 8 and HQ 17 plug-in connector inserts

Optionally with lockable protective cover (protection against being switched on again, in accordance with EN 60204-1)

General ordering data

| | | |
|------------|----------------------------|---|
| Type | BG ARGH HQP ALU PT6 | Version |
| Order No. | 1532200000 | Adapter, Field Power® sealing insert, HQ adapter, IP65, with |
| GTIN (EAN) | 4050118337433 | corresponding enclosure, Polycarbonate, glass fibre reinforced, |
| Qty. | 1 pc(s). | lockable: No |
| Type | BG ARGH HQP ALU PT6 CS | Version |
| Order No. | 1532210000 | Adapter, Field Power® sealing insert, HQ adapter, IP65, with |
| GTIN (EAN) | 4050118337600 | corresponding enclosure, Polycarbonate, glass fibre reinforced, |
| Qty. | 1 pc(s). | lockable: Yes |

AC/DC



Power distribution using uncut cables with cross-sections from 1.5 to 6 mm².

Power supply / T-branch tap via PUSH IN connection (0.5 to 10 mm²) and/or plug-in connection (0.5 to 4 mm²).

Coloured markings provide clear assignment of wires.

- Power supply
- Power distribution
- Power branching

General ordering data

| | | |
|------------|----------------------------|--|
| Type | PT6 230/BUS | Version |
| Order No. | 1269960000 | FieldPower® contact element, AC, IP20, Insulation displacement |
| GTIN (EAN) | 4050118058239 | connection (IDC), PUSH IN, Number of poles : 5 |
| Qty. | 1 pc(s). | |
| Type | PT6 DC 1/2/PE/3/4 | Version |
| Order No. | 1534930000 | FieldPower® contact element, DC, IP20, Insulation displacement |
| GTIN (EAN) | 4050118338775 | connection (IDC), PUSH IN, Number of poles : 5 |
| Qty. | 1 pc(s). | |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

IP68 version



In addition to the extensive range of enclosures, Weidmüller offers a variety of cable glands for a wide range of applications.

The cable glands made of brass, plastic and stainless steel meet the most various IP protection classes to suit any industrial enclosure.

Depending on the series of cable glands and the application, the cable glands are approved and tested according to VDE, UL, UR, cULus, DNV GL or EN 45545.

General ordering data

| Type | VG M20 - K 68 | Version |
|------------|----------------------------|---|
| Order No. | 2811470000 | VG K (standard plastic cable gland), Cable glands, straight, M 20, 10 |
| GTIN (EAN) | 4064675292227 | mm, OD min. 10 - OD max. 14 mm, IP54, IP66, IP67, IP68 - 5 bar (30 |
| Qty. | 50 pc(s). | min.), Polyamide 6 |
| Type | VG M20-1/K68 | Version |
| Order No. | 1772300000 | VG K (standard plastic cable gland), Cable glands, straight, M 20, 10 |
| GTIN (EAN) | 4032248129966 | mm, OD min. 6 - OD max. 12 mm, IP54, IP66, IP67, IP68 - 5 bar (30 |
| Qty. | 50 pc(s). | min.), Polyamide 6 |

DMS PRO



Weidmüller torque screwdrivers have an ergonomic design and are therefore ideal for use with one hand. They can be used without causing fatigue in all installation positions. Apart from that, they incorporate an automatic torque limiter and have a good reproducibility accuracy.

General ordering data

| Type | DMS PRO | Version |
|------------|----------------------------|---------------|
| Order No. | 1479120000 | Mounting tool |
| GTIN (EAN) | 4050118287011 | |
| Qty. | 1 pc(s). | |

FP ENC BSTS 155 2M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Seals


Intelligent cabling solutions can save you valuable time and money.

The FieldPower® modular system contains the right solution for every cabling task.

Foldable seals for the use of pre-assembled cables

Seals available with M16 and M20 connection thread
Integration of operating and signalling devices into the seal possible

General ordering data

| | | |
|------------|----------------------------|--|
| Type | DG M16 PT6 | Version |
| Order No. | 2545540000 | Field Power® sealing insert, Seal with connection thread, IP65, with |
| GTIN (EAN) | 4050118555523 | corresponding enclosure, EPDM |
| Qty. | 1 pc(s). | |
| Type | DG M20 PT6 | Version |
| Order No. | 2545550000 | Field Power® sealing insert, Seal with connection thread, IP65, with |
| GTIN (EAN) | 4050118555530 | corresponding enclosure, EPDM |
| Qty. | 1 pc(s). | |
| Type | RKDG D15 PT6 | Version |
| Order No. | 4323220000 | Field Power® sealing insert, Foldable seal, IP65 with corresponding |
| GTIN (EAN) | 4032248641222 | housing, IP65, with corresponding enclosure, EPDM, 13 mm ² , 15 mm ² |
| Qty. | 10 pc(s). | |
| Type | RKDG D9 PT6 | Version |
| Order No. | 4329610000 | Field Power® sealing insert, Foldable seal, IP65 with corresponding |
| GTIN (EAN) | 4032248668687 | housing, IP65, with corresponding enclosure, EPDM, 7 mm ² , 9 mm ² |
| Qty. | 10 pc(s). | |
| Type | RKDGE D2X6,5 PT6 | Version |
| Order No. | 2443800000 | Field Power® sealing insert, Slotted sealing insert, IP54, in |
| GTIN (EAN) | 4050118457704 | combination with RKDG D17 PT6, with corresponding enclosure, TPE- |
| Qty. | 10 pc(s). | V, 6.5 mm ² |
| Type | RKDG D11 PT6 | Version |
| Order No. | 4323210000 | Field Power® sealing insert, Foldable seal, IP65 with corresponding |
| GTIN (EAN) | 4032248641215 | housing, IP65, with corresponding enclosure, EPDM, 9 mm ² , 11 mm ² |
| Qty. | 10 pc(s). | |
| Type | DG D0 PT6 | Version |
| Order No. | 4323240000 | Field Power® sealing insert, Blank seal, IP65, with corresponding |
| GTIN (EAN) | 4032248641246 | enclosure, EPDM |
| Qty. | 10 pc(s). | |
| Type | RKDG D17 PT6 | Version |
| Order No. | 4324010000 | Field Power® sealing insert, Foldable seal, IP65 with corresponding |
| GTIN (EAN) | 4032248641284 | housing, IP65, with corresponding enclosure, EPDM, 15 mm ² , 17 mm ² |
| Qty. | 10 pc(s). | |
| Type | RKDG D18 WG PT6 | Version |
| Order No. | 2491870000 | Field Power® sealing insert, Seal, IP54, with corresponding enclosure, |
| GTIN (EAN) | 4050118501537 | EPDM, 18.5 mm ² , 20.5 mm ² |
| Qty. | 10 pc(s). | |
| Type | RKDGE D4X4 PT6 | Version |
| Order No. | 2443760000 | Field Power® sealing insert, Slotted sealing insert, IP54, in |
| GTIN (EAN) | 4050118457643 | combination with RKDG D17 PT6, with corresponding enclosure, TPE- |
| Qty. | 10 pc(s). | V, 4 mm ² |

FP ENC BSTS 155 2M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories**

| | | |
|------------|----------------------------|--|
| Type | RKDG D24 WG PT6 | Version |
| Order No. | 1069060000 | Field Power® sealing insert, Seal, IP54, with corresponding enclosure, |
| GTIN (EAN) | 4032248827053 | EPDM |
| Qty. | 10 pc(s). | |
| Type | RKDG D13 PT6 | Version |
| Order No. | 4323230000 | Field Power® sealing insert, Foldable seal, IP65 with corresponding |
| GTIN (EAN) | 4032248641239 | housing, IP65, with corresponding enclosure, EPDM, 11 mm ² , 13 mm ² |
| Qty. | 10 pc(s). | |
| Type | RKDG 2XD8.5 WG PT6 | Version |
| Order No. | 1114530000 | Field Power® sealing insert, Seal, IP54, with corresponding enclosure, |
| GTIN (EAN) | 4032248892624 | EPDM, 8.5 mm ² , 10.5 mm ² |
| Qty. | 10 pc(s). | |