

HDC MHP 70 MC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Flexible**

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

General ordering data

Version	Power module
Order No.	2668190000
Type	HDC MHP 70 MC
GTIN (EAN)	4050118767537
Qty.	1 pc(s).

HDC MHP 70 MC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	34 mm	Depth (inches)	1.339 inch
Height	46.65 mm	Height (inches)	1.837 inch
Width	14.5 mm	Width (inches)	0.571 inch
Net weight	10.1 g		

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

General data

Insulation strength	$10^{12} \Omega$	Material	Polycarbonate, glass fibre reinforced
Number of poles	2	Plugging cycles	≥ 500
Pollution severity	3	Rated current (DIN EN 61984)	70 A
Rated impulse voltage (DIN EN 61984)	8 kV	Rated voltage (DIN EN 61984)	1,000 V
Rated voltage according to UL/CSA	600 V	Required plug-in slots	1
Series	ModuPlug	Surge voltage category	III
Type	Male	UL 94 flammability rating	V-0

PE connection data

Connection type PE	Screw connection via module frame
--------------------	-----------------------------------

Version

Conductor cross-section, max.	25 mm ²	Conductor cross-section, min.	6 mm ²
Stripping length, rated connection	15 mm	Type of connection	Crimp connection

Classifications

ETIM 6.0	EC002312	ETIM 7.0	EC002312
ETIM 8.0	EC002312	ETIM 9.0	EC002312
ECLASS 9.0	27-44-02-92	ECLASS 9.1	27-44-02-18
ECLASS 10.0	27-44-02-92	ECLASS 11.0	27-44-02-92
ECLASS 12.0	27-44-02-92	ECLASS 13.0	27-44-02-92

Environmental Product Compliance

REACH SVHC	Potassium perfluorobutane sulfonate 29420-49-3
SCIP	1609748e-c278-4c9b-b3d1-e6215d2988cd

Approvals

Approvals



UL File Number Search	UL Website
Certificate No. (cURus)	E92202

HDC MHP 70 MC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Con-
formity

[Manufacturer's declaration](#)

Engineering Data

[CAD data – STEP](#)

Catalogues


[Catalogues in PDF-format](#)

HDC MHP 70 MC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

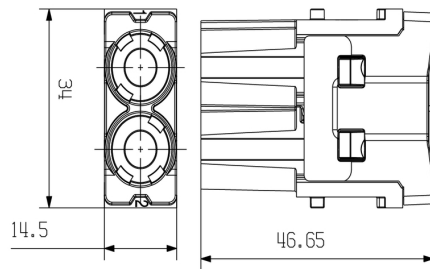

HDC MHP 70 MC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

70 A crimp contacts



Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

General ordering data

Type	HDC MHP70 M 25	Version
Order No.	2668370000	Male, silver
GTIN (EAN)	4050118803013	
Qty.	10 pc(s).	
Type	HDC MHP70 M 16	Version
Order No.	2668360000	Male, silver
GTIN (EAN)	4050118802795	
Qty.	10 pc(s).	
Type	HDC MHP70 M 16 P	Version
Order No.	2691250000	Male, silver
GTIN (EAN)	4050118803020	
Qty.	10 pc(s).	
Type	HDC MHP70 M 25 P	Version
Order No.	2691260000	Male, silver
GTIN (EAN)	4050118803037	
Qty.	10 pc(s).	
Type	HDC MHP70 M 6 P	Version
Order No.	2691190000	Male, silver
GTIN (EAN)	4050118802887	
Qty.	10 pc(s).	
Type	HDC MHP70 M 6	Version
Order No.	2668280000	Male, silver
GTIN (EAN)	4050118802788	
Qty.	10 pc(s).	
Type	HDC MHP70 M 10	Version
Order No.	2668350000	Male, silver
GTIN (EAN)	4050118802290	
Qty.	10 pc(s).	
Type	HDC MHP70 M 10 P	Version
Order No.	2691240000	Male, silver
GTIN (EAN)	4050118802900	
Qty.	10 pc(s).	