

**THM PV 89/60 B/DR RT****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

UV-radiation causes high stress and aging of plastic in the outdoor application.

Our new THM PV labels resist these influences and are extremely durable in outdoor use.

Compact designed packaging are our TABPACK-PV. These are pre-printed warning labels, which should be a part of the basic equipment of a professional photovoltaic builder.

Your advantages at a glance:

- Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours
- Individually labeled with the M-Print® PRO
- Easy and fast printing with the THM MultiMark

**General ordering data**

Version	Device markers, Device markers, 60 x 89 mm, red
Order No.	<a href="#">2817450000</a>
Type	THM PV 89/60 B/DR RT
GTIN (EAN)	4064675322764
Qty.	450 pc(s).
compatible printer	<a href="#">2599430000</a>

## THM PV 89/60 B/DR RT

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	0.1 mm	Depth (inches)	0.004 inch
Height	60 mm	Height (inches)	2.362 inch
Width	89 mm	Width (inches)	3.504 inch
Net weight	0.953 g		

## General data

Adhesive	Polyacrylate adhesive	Approval acc. to UL 969	Yes
Colour	red	Halogen	Yes
Material	Vinyl film	Operating temperature range, max.	-50 °C
Operating temperature range, min.	110 °C	Printed characters	Symbols
UL 94 flammability rating	V-0	Width	89 mm

## Conductor and cable markers

Halogen	Yes
---------	-----

## Device markers

Halogen	Yes
---------	-----

## Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

## Approvals

ROHS	Conform
------	---------

## Downloads


Engineering Data	<a href="#">CAD data – STEP</a>
White paper	<a href="#">Fact Sheet PV Markierer</a> <a href="#">Fact Sheet EN PV Markers</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

### THM PV 89/60 B/DR RT

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

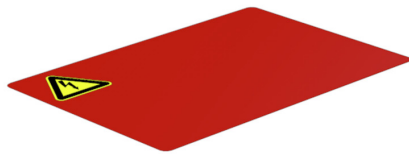

**THM PV 89/60 B/DR RT****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	THM MMP ROLLER 115
Order No.	<a href="#">1357420000</a>
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

**Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM 110/300 WS	Version
Order No.	<a href="#">2918800000</a>	Ink ribbon
GTIN (EAN)	4099986574878	
Qty.	1 pc(s).	
Type	RIBBON MM 110/360 SW	Version
Order No.	<a href="#">2005070000</a>	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

### THM PV 89/60 B/DR RT

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	MM PLUS ROLLER 110
Order No.	<a href="#">2672590000</a>
GTIN (EAN)	4050118708097
Qty.	1 pc(s).