

**IE-PS-VAPM-5P-2.5-QT****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**SNAP IN** 

PushPull Power plug-in connector according to PROFINET specification

**General ordering data**

Version	Power connector, Plug, PROFINET
Order No.	<a href="#">2912590000</a>
Type	IE-PS-VAPM-5P-2.5-QT
GTIN (EAN)	4099986536418
Qty.	1 pc(s).

**IE-PS-VAPM-5P-2.5-QT****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Height	36.2 mm	Height (inches)	1.425 inch
Width	26.8 mm	Width (inches)	1.055 inch
Length	85.4 mm	Length (inches)	3.362 inch
Net weight	96 g		

**Temperatures**

Operating temperature	-40 °C...70 °C
-----------------------	----------------

**General data**

Cable sealing material	EPDM	Colour	Silver grey
Connection 1	PushPull Power	Connection 2	SNAP IN
Contact material	Cu-alloy	Contact surface	Gold over nickel
Housing main material	Zinc diecast, nickel-plated	Number of poles	5
Plugging cycles	≥ 100	Pollution severity	2
Protection degree	IP65, IP67	Sealing material	NBR
Sheath diameter, max.	13 mm	Sheath diameter, min.	8 mm
Shielding	unshielded	Type of interlock	Push Pull
UL 94 flammability rating	V-2	Wire connection cross section, finely stranded, max.	2.5 mm <sup>2</sup>
Wire connection cross section, finely stranded, min.	0.75 mm <sup>2</sup>		

**Electrical properties**

Current-carrying capacity at 50 °C	16 A	Operating voltage	24 V
------------------------------------	------	-------------------	------

**General standards**

Certificate No. (UR)	Connector standard	in accordance with PROFINET specification, IEC 61076-3-126
E92202		

**Standards**

Connector standard	in accordance with PROFINET specification, IEC 61076-3-126
--------------------	--

**Classifications**

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90

**Important note**

Product information	For cables with outer diameter 6-8 mm, order additional reducing seal.
---------------------	--

## IE-PS-VAPM-5P-2.5-QT

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search UL Website

Certificate No. (UR) E92202

## Downloads

Approval/Certificate/Document of Con-  
formity [PROFINET Manufacturer's Declaration](#)Engineering Data [CAD data – STEP](#)Catalogues [Catalogues in PDF-format](#)


## IE-PS-VAPM-5P-2.5-QT

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany


[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Dimensioned drawing

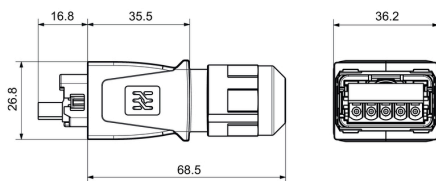

### Drawing

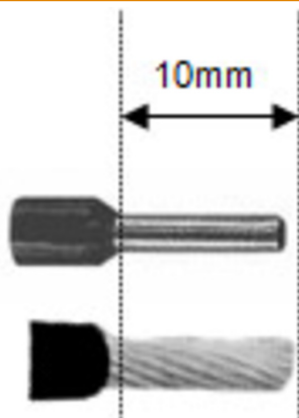

When using wire-end-ferrules, we recommend the length of 10 mm.

**IE-PS-VAPM-5P-2.5-QT****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Individual parts**

PushPull Power plug-in connector according to PROFINET specification

**General ordering data**

Type	IE-REDU-6-8-PS-VAPM	Version
Order No.	<a href="#">2531330000</a>	Power connector, Plug, Sealing insert, PROFINET
GTIN (EAN)	4050118545227	
Qty.	10 pc(s).	