

**THM MULTIMARK TWIN****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Version	Marking systems, Thermotransfer, 300 DPI, Shrink-fit sleeves
Order No.	<a href="#">2931860000</a>
Type	THM MULTIMARK TWIN
GTIN (EAN)	4099986669895
Qty.	1 pc(s).

## THM MULTIMARK TWIN

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	395 mm	Depth (inches)	15.551 inch
Height	544 mm	Height (inches)	21.417 inch
Width	248 mm	Width (inches)	9.764 inch
Net weight	21,000 g		

## Labelling systems

Interface	LAN, USB 2.0	Marker type	Shrink-fit sleeves
Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10, Windows 11	Print resolution, max.	300 DPI
Printing method	Thermotransfer	Printing speed	150 mm/s
Software	M-Print® PRO	Type	THM TwinMark printer
Voltage supply	100...240 V AC		

## Classifications

ETIM 6.0	EC000610	ETIM 7.0	EC000610
ETIM 8.0	EC000610	ETIM 9.0	EC000610
ECLASS 9.0	24-32-11-90	ECLASS 9.1	24-32-11-02
ECLASS 10.0	24-32-11-90	ECLASS 11.0	24-32-11-90
ECLASS 12.0	24-32-11-90	ECLASS 13.0	24-32-11-90

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">CE Declaration of conformity</a> <a href="#">UKCA Declaration of conformity</a>
User Documentation	<a href="#">Manual THM MultiMark TWIN - DE</a> <a href="#">Manual THM MultiMark TWIN - EN</a> <a href="#">Manual THM MultiMark TWIN - IT</a> <a href="#">Manual THM MultiMark TWIN - NL</a> <a href="#">Manual THM MultiMark TWIN - FR</a> <a href="#">Manual THM MultiMark TWIN - ES</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

## THM MULTIMARK TWIN

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Ink ribbons




These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	RIBBON HSS HF EL 40/300 ...	Version
Order No.	<a href="#">1426210000</a>	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 pc(s).	
Type	RIBBON MM-HS 60/300 SW	Version
Order No.	<a href="#">2448880000</a>	Ink ribbon
GTIN (EAN)	4050118462944	
Qty.	1 pc(s).	

### THM MULTIMARK PLUS

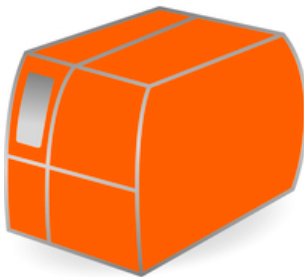

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	MM PLUS ROLLER 110	
Order No.	<a href="#">2672590000</a>	
GTIN (EAN)	4050118708097	
Qty.	1 pc(s).	
Type	THM PLUS M PERFORATOR	Version
Order No.	<a href="#">1540770000</a>	Cutting kit
GTIN (EAN)	4050118345711	
Qty.	1 pc(s).	