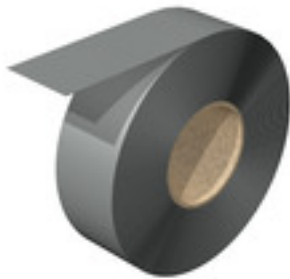


THM PV EL 30 SI 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

UV-radiation causes high stress and aging of plastic in the outdoor application.

Our new THM PV labels resist these influences and are extremely durable in outdoor use.

Compact designed packaging are our TABPACK-PV. These are pre-printed warning labels, which should be a part of the basic equipment of a professional photovoltaic builder.

Your advantages at a glance:

- Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours
- Individually labeled with the M-Print® PRO
- Easy and fast printing with the THM MultiMark

General ordering data

| | |
|------------|---|
| Version | Device markers, Device markers, 30 x , silver |
| Order No. | 2969100000 |
| Type | THM PV EL 30 SI 30M |
| GTIN (EAN) | 4099986783768 |
| Qty. | 1 pc(s). |

THM PV EL 30 SI 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

| | | | |
|------------|-----------|-----------------|--------------|
| Depth | 0.1 mm | Depth (inches) | 0.004 inch |
| Height | 30 mm | Height (inches) | 1.181 inch |
| Length | 30,000 mm | Length (inches) | 1,181.1 inch |
| Net weight | 100 g | | |

General data

| | | | |
|-----------------------------------|-----------------------|-----------------------------------|-----------|
| Adhesive | Polyacrylate adhesive | Colour | silver |
| Halogen | Yes | Length | 30,000 mm |
| Material | Vinyl film | Operating temperature range, max. | -50 °C |
| Operating temperature range, min. | 110 °C | Printed characters | without |
| UL 94 flammability rating | V-0 | | |

Conductor and cable markers

| | |
|---------|-----|
| Halogen | Yes |
|---------|-----|

Device markers

| | |
|---------|-----|
| Halogen | Yes |
|---------|-----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001288 | ETIM 7.0 | EC001288 |
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ECLASS 9.0 | 27-40-06-29 | ECLASS 9.1 | 27-40-06-29 |
| ECLASS 10.0 | 27-40-06-29 | ECLASS 11.0 | 27-28-11-04 |
| ECLASS 12.0 | 27-28-11-04 | ECLASS 13.0 | 27-28-11-04 |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|------------|--|
| Catalogues | Catalogues in PDF-format |
|------------|--|

THM PV EL 30 SI 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

