

**SSS RELAIS 5V/24V 2ADC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Similar to illustration

Individual relays for TERMSERIES

- Solid-state relays
- Different output versions

**General ordering data**

Version	TERMSERIES, Solid-state relay, Rated control voltage: 2.5 V DC...5 V DC...6 V DC , Rated switching voltage: 3...33 V DC, Continuous current: 2 A, Plug-in connection
Order No.	<a href="#">4064310000</a>
Type	SSS RELAIS 5V/24V 2ADC
GTIN (EAN)	4032248365524
Qty.	1 pc(s).

## SSS RELAIS 5V/24V 2ADC

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	15 mm	Depth (inches)	0.591 inch
Height	28 mm	Height (inches)	1.102 inch
Width	5 mm	Width (inches)	0.197 inch
Net weight	2.05 g		

## Temperatures

Storage temperature	-40 °C...70 °C	Operating temperature	-20 °C...60 °C
Humidity	40 °C / 93 % rel. humidity, no condensation		

## Probability of failure

MTTF	1,118 Jahre
------	-------------

## Control side

Rated control voltage	2.5 V DC...5 V DC...6 V DC	Nominal control current	9 mA DC (±10%)
Power rating	45 mW	Status indicator	No

## Load side

Rated switching voltage	3...33 V DC	Continuous current	2 A
Rated switching current	2 A DC	Inrush current	15 A / 10 ms
Switch-on delay	<55 µs	Switch-off delay	<600 µs
Voltage drop at max. load	≤ 120 mV	Leakage current	<10 µA
Min. switching current	5 mA	Short-circuit-proof	No
Protective circuit, load side	Free-wheeling diode	Contact type	1 NO contact (MOS-FET)

## General data

Colour	black
--------	-------

## Insulation coordination

Clearance and creepage distances for control side - load side	≥ 5.5 mm	Dielectric strength for control side - load side	2.5 kV <sub>eff</sub>
---------------------------------------------------------------	----------	--------------------------------------------------	-----------------------

## Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

## Classifications

ETIM 6.0	EC001504	ETIM 7.0	EC001504
ETIM 8.0	EC001504	ETIM 9.0	EC001504
ECLASS 9.0	27-37-16-04	ECLASS 9.1	27-37-16-04
ECLASS 10.0	27-37-16-04	ECLASS 11.0	27-37-16-04
ECLASS 12.0	27-37-16-04	ECLASS 13.0	27-37-16-04

## Approvals

ROHS	Conform
------	---------

### SSS RELAIS 5V/24V 2ADC

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Downloads

Engineering Data

[CAD data – STEP](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures


## SSS RELAIS 5V/24V 2ADC

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Wiring diagram

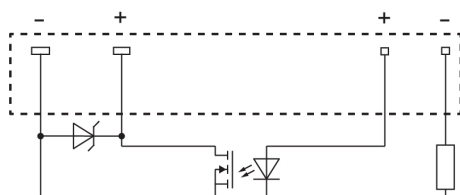

View of pins from below

## Dimensional drawing

