

**KEBXHS202015S4B1 AK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Similar to illustration**

Klippon® EBx HS stainless steel enclosures, where the lid is fixed by Hinge and Screws, are offered as high quality products with leading performance characteristics in oil and chemistry hazardous industry. It is certified and complied with the international standards - like ATEX and IECEx approval.

**General ordering data**

Version	Klippon EBx HS (Essential Box Ex - Hinge Screw), Empty enclosure, Height: 200 mm, Width: 200 mm, Depth: 150 mm, Gland plates: Bottom, Material: Stainless steel 1.4404 (316L), Brushed, silver
Order No.	<a href="#">8000071017</a>
Type	KEBXHS202015S4B1 AK
GTIN (EAN)	4064675304777
Qty.	1 pc(s).
Local product	Only available in certain countries

Creation date April 26, 2024 6:09:45 AM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.

## KEBXHS202015S4B1 AK

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## General ordering data

Local product	Only available in certain countries
---------------	-------------------------------------

## Dimensions and weights

Depth	150 mm	Depth (inches)	5.905 inch
Height	200 mm	Height (inches)	7.874 inch
Width	200 mm	Width (inches)	7.874 inch
Mounting dimension - height	160 mm	Mounting dimension - width	160 mm
Net weight	3,300 g		

## Temperatures

Operating temperature	-55 °C...135 °C
-----------------------	-----------------

## Cable glands, left

M12	40	M16	24
M20	14	M25	7
M32	5	M40	2
M50	2		

## Cable glands, right

M12	40	M16	24
M20	14	M25	7
M32	5	M40	2
M50	2		

## Cable glands, top/bottom

M12	30	M16	17
M20	8	M25	3
M32	3	M40	2

## Certificate numbers enclosure

Approval conditions	ATEX, IECEx, INMETRO	Attestation of Conformity No. (AoC)	DE PS265x 210819 000ISS01
Certificate No. (ATEX)	IBEXU21ATEX1016U	Certificate No. (IECEx)	IECExIBE21.0006U
Certificate no. Terminal Box (ATEX)	IBExU 21ATEX 1017 X	Certificate no. Terminal Box (IECEx)	IECEx IBE 21.0012
Certificate no. Terminal Box (INMETRO)	LMP 21.0602X	Certificate no. empty enclosure (ATEX)	IBExU 21ATEX 1016 U
Certificate no. empty enclosure (IECEx)	IECEx IBE 21.0006U	Certificate no. empty enclosure (INMETRO)	LMP 21.0601U
Declaration of Conformity No. (DoC LVD)	DE PS265X 210819 001ISS01		

## KEBXHS202015S4B1 AK

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## General information

AF size	10 mm	Access opening: height	149.6 mm
Access opening: width		Areas of use	Chemical industry, Explosive risk zone, Oil and gas industry, Onshore, Process industry, Building systems and technology, Machine construction, Packaging industry
	143.6 mm		
Enclosure attachment	4 or 6, M6 blind thread hole on backside; optionally via additional mounting feet	Flange plate	Yes
Flange plate mounting	M6 hexagonal head screws 10 SW	Gland plates	Bottom
Impact resistance	7 J ATEX version, 10 J version standard	Integral fixing	4, 6 or 9 stud bolts M6 inner (female) thread
Lid	Yes	Lid attachment	M6 hex-head slotted screws SW10 + hinges
Material	Stainless steel 1.4404 (316L)	Material thickness	1.5 mm
Material thickness of cover	1.5 mm	Material thickness of flange	3 mm
Max. payload	4 kg	Number of lid screws	2
Opening angle lid	125 °	Operating temperature, max.	135 °C
Operating temperature, min.	-55 °C	Position PE bolts	Enclosure side C
Protection class (UL)	Type 1, Type 4, Type 4X	Protection degree	IP66
Seal material		Standards	EN 60079-0, IEC 60079-0, EN 60079-7, IEC 60079-7, EN 60079-11, IEC 60079-11, EN 60079-31, IEC 60079-31
	Silicone (cover + flange)		
Surface finish	Brushed	Torque for lid screws	2.5 Nm

## Housing earth

Earth, enclosure, internal	Welded-on M6 stainless-steel earth stud in enclosure body and lid.
----------------------------	--

## horizontal assembly

WDU 10 / ZDU 10	1x10	WDU 16 / ZDU 16	1x8
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x22	WDU 35 / ZDU 35	1x6
WDU 4 / ZDU 4	1x18	WDU 6 / ZDU 6	1x13

## vertical assembly

WDU 10 / ZDU 10	1x10	WDU 16 / ZDU 16	1x8
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x22	WDU 35 / ZDU 35	1x6
WDU 4 / ZDU 4	1x18	WDU 6 / ZDU 6	1x13

## Classifications

ETIM 6.0	EC002503	ETIM 7.0	EC002503
ETIM 8.0	EC002503	ETIM 9.0	EC002503
ECLASS 9.0	27-18-05-02	ECLASS 9.1	27-18-05-02
ECLASS 10.0	27-18-05-02	ECLASS 11.0	27-18-05-02
ECLASS 12.0	27-18-05-02	ECLASS 13.0	27-18-05-02

**KEBXHS202015S4B1 AK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Important note**

Product information

All articles with M6 threaded rivet as standard; UL variants with M10 earth bolt on request

**Approvals**

Approvals



ROHS

Conform

**Downloads**

Approval/Certificate/Document of Conformity

[IBEXU21ATEX1017X](#)[IBEXU21ATEX1016U](#)[IECEXIBE21.0012](#)[IECEXIBE21.0006U](#)[UKCA TÜV 22 UKEX 7098 X](#)[UKCA TÜV 22 UKEX 7097 U](#)[Attestation of Conformity - Klippon EBx Empty Enclosures - AoC DE PS265x 210819 000ISS01](#)[CERTIFICADO LMP 21.0601U KLIPPON EBx](#)[CERTIFICADO LMP 21.0602X KLIPPON EBx](#)[EU Declaration of Conformity - Klippon EBx Empty Enclosures LVD - DoC DE PS265X 210819 001ISS01](#)

Engineering Data

[CAD data – STEP](#)

Catalogues

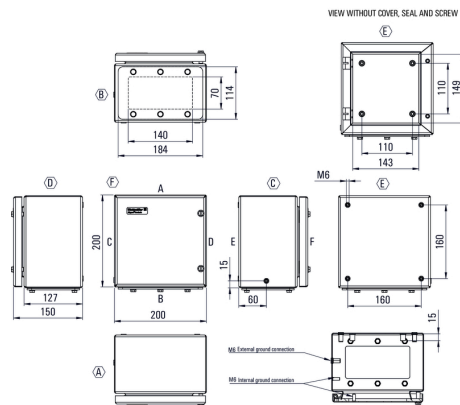
[Catalogues in PDF-format](#)

**KEBXHS202015S4B1 AK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Drawings**

**KEBXHS202015S4B1 AK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Mounting feet**

With the additionally available mounting feet, the enclosures can also be mounted from outside the enclosure.

**General ordering data**

Type	KEB MOFT SMALL S4 SET	Version
Order No.	<a href="#">2660200318</a>	Klippon EB (Essential Box), Mounting foot, Height: 38 mm, Width: 55
GTIN (EAN)	4064675275695	mm, Depth: 10.5 mm, Material: Steel, untreated, silver
Qty.	1 pc(s).	

**Slotted screwdriver**

VDE insulated screwdriver sets, for working on live parts up to 1000 V AC and 1500 V DC, DIN EN 60900. IEC 900. Each piece is "GS" safety tested. Blade made from fully hardened, high-alloy chromium-vanadium-molybdenum steel, gun-metal finish.

**General ordering data**

Type	SDIS SLIM 1.2X6.5X150	Version
Order No.	<a href="#">2749640000</a>	Mounting tool, Blade width (B): 6.5 mm, Blade length: 150 mm, Blade
GTIN (EAN)	4050118896381	thickness (A): 1.2 mm
Qty.	1 pc(s).	

## KEBXHS202015S4B1 AK

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Mounting plates



Mounting plates, with and without hole patterns, for longitudinal and transverse mounting of DIN mounting rails or components directly onto the mounting plate.

## General ordering data

Type	KEB MOPL 2020 S2N H	Version
Order No.	<a href="#">8000074314</a>	Klippon EB (Essential Box), Mounting plate, Height: 140 mm, Width:
GTIN (EAN)	4064675425250	140 mm, Depth: 1.5 mm, Material: Stainless steel 1.4301 (304),
Qty.	1 pc(s).	untreated, silver
Type	GFSC M5X10 TX20 SET	Version
Order No.	<a href="#">1274150000</a>	Klippon EB (Essential Box), Mounting screw, Height: 13.3 mm, Width:
GTIN (EAN)	4050118063820	8.5 mm, Depth: 8.5 mm, Material: Steel, galvanized, galvanic zinc
Qty.	1 pc(s).	plated and passivated, silver
Type	KEB MOPL 2020 MSZN	Version
Order No.	<a href="#">8000074117</a>	Klippon EB (Essential Box), Mounting plate, Height: 140 mm, Width:
GTIN (EAN)	4064675425151	140 mm, Depth: 1.5 mm, Material: Sheet steel, galvanized, silver
Qty.	1 pc(s).	

## Spacer



Stainless steel spacers in three lengths to increase the distance between the mounting rails or DIN rails and the rear wall of the enclosure.

## General ordering data

Type	SP M6 15 MSZN	Version
Order No.	<a href="#">3896100000</a>	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190857851	Depth: 15 mm, Material: Steel, silver
Qty.	2 pc(s).	
Type	SP M6 30 MSZN	Version
Order No.	<a href="#">3896300000</a>	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850241	Depth: 30 mm, Material: Steel, silver
Qty.	2 pc(s).	
Type	SP M6 20 MSZN	Version
Order No.	<a href="#">3896200000</a>	Klippon EB (Essential Box), Spacer, Height: 11.2 mm, Width: 10 mm,
GTIN (EAN)	4008190850234	Depth: 20 mm, Material: Steel, silver
Qty.	2 pc(s).	

## KEBXHS202015S4B1 AK

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Type label holder



There are a variety of designed label holders available for prominent display as required and for additional nameplates as needed.

## General ordering data

Type	TPSDHA KEB 130X50 S4B R	Version
Order No.	<a href="#">8000075816</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 50 mm, Width:
GTIN (EAN)	4064675425366	171 mm, Depth: 16.5 mm, Material: Stainless steel 1.4404 (316L),
Qty.	1 pc(s).	Brushed, silver
Type	TPSDHA KEB 100X25 S4B R	Version
Order No.	<a href="#">8000075818</a>	Klippon EB (Essential Box), Enclosures, Riveted, Height: 25 mm, Width:
GTIN (EAN)	4064675425632	141 mm, Depth: 16.5 mm, Material: Stainless steel 1.4404 (316L),
Qty.	1 pc(s).	Brushed, silver

## Installation material

**Integrate, expand and customise - the perfect supplement to every application**

The fully structured range of system accessories for the new Klippon® TB enclosure series allows you to easily adapt the enclosures to meet the specific requirements of every application.

**Mounting hardware kits**

Mounting hardware kits are available for quick and easy installation of type label holders, document holders and rain hoods.

The **label fastening set – SD** is required to install a plastic (Trafolyte) ID or type label. With the aid of this set can you mount the ID or type label directly on the enclosure cover. The label fastening set has been specially developed for this purpose. Only by using this fastening set can you ensure that there will be no leaks into the enclosure or damage to the label.

The **universal fastening set – TPSD** has been developed to enable secure and quick installation of type label holders, rain covers or document holders, for example. By using this fastening set, the risk of leaks can be minimised, if not avoided.

## General ordering data

Type	LKSC M6X8 A2 TX30	Version
Order No.	<a href="#">2704960000</a>	Klippon TB (Terminal Box), Set of fixings, Height: 11.3 mm, Width:
GTIN (EAN)	4050118753196	13.6 mm, Depth: 13.6 mm, Material: Stainless steel, rust-proof,
Qty.	500 pc(s).	untreated, silver