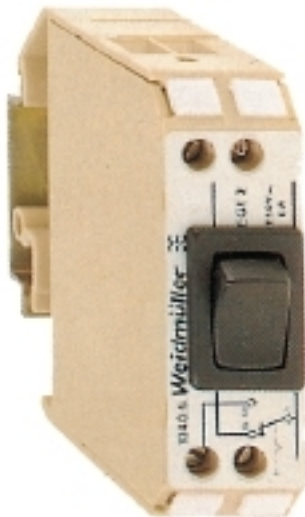


**EGT EG1 35 1A + 1R****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The profiles of the switch and button components match those of the electronic components.

Switches and buttons facilitate commissioning, servicing, monitoring and repair of industrial installations.

**General ordering data**

Version	, Function component 1 NC contact, 1 NO contacts, Screw connection
Order No.	<a href="#">8002290000</a>
Type	EGT EG1 35 1A + 1R
GTIN (EAN)	4008190046965
Qty.	10 pc(s).

**EGT EG1 35 1A + 1R****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Height	50 mm	Height (inches)	1.969 inch
Width	18 mm	Width (inches)	0.709 inch
Length	58 mm	Length (inches)	2.283 inch
Net weight	38.61 g		

**Temperatures**

Storage temperature	-40 °C...100 °C	Operating temperature	-25 °C...85 °C
---------------------	-----------------	-----------------------	----------------

**Output**

Rated switching voltage	250 V AC	AC switching capacity (resistive), max.	750 VA @ 250 V
AC switching capacity, max.	750 VA	Switching capacity	250 V
DC switching capacity (resistive), max.	150 W @ 30 V	DC switching capacity, max.	150 W
Switching capacity	30 V		

**General data**

Rail	TS 32, TS 35	Colour	beige
------	--------------	--------	-------

**Connection data**

Wire connection method	Screw connection	Clamping range, rated connection	6 mm <sup>2</sup>
Clamping range, min.	0.5 mm <sup>2</sup>	Clamping range, max.	6 mm <sup>2</sup>
Wire connection cross section, finely stranded, max.	4 mm <sup>2</sup>		

**Classifications**

ETIM 6.0	EC002498	ETIM 7.0	EC002498
ETIM 8.0	EC002498	ETIM 9.0	EC002498
ECLASS 9.0	27-37-92-01	ECLASS 9.1	27-37-92-01
ECLASS 10.0	27-37-13-92	ECLASS 11.0	27-37-13-92
ECLASS 12.0	27-37-13-92	ECLASS 13.0	27-37-13-92

**Approvals**

Approvals



ROHS

Conform

**Downloads**

Approval/Certificate/Document of Conformity

[Application notes – EU Konformitätserklärung / EU Declaration of Conformity](#)

Catalogues

[Catalogues in PDF-format](#)

## EGT EG1 35 1A + 1R

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Steel



Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

## General ordering data

Type	TS 35X7.5 2M/ST/ZN	Version
Order No.	<a href="#">0383400000</a>	Terminal rail, without slot, Accessories, 35 x 7.5 x 2000 mm, Steel,
GTIN (EAN)	4008190088026	galvanic zinc plated and passivated
Qty.	2 m	
Type	TS 35X15/2.3 2M/ST/ZN	Version
Order No.	<a href="#">0498000000</a>	Terminal rail, without slot, Accessories, 35 x 15 x 2000 mm, Steel,
GTIN (EAN)	4008190042493	galvanic zinc plated and passivated
Qty.	2 m	

## SAK-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

Type	EW 35	Version
Order No.	<a href="#">0383560000</a>	End bracket, Wemid, beige, Rail: TS 35, when screwed in
GTIN (EAN)	4008190181314	
Qty.	50 pc(s).	

**EGT EG1 35 1A + 1R****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Steel**

Steel DIN rails are the most widespread on the market. Among metal DIN rails, they have the lowest shortcircuit protection, similar to stainless steel.

**General ordering data**

Type	TS 32X15 2M/ST/ZN	Version
Order No.	<a href="#">0122800000</a>	Terminal rail, without slot, Accessories, 33 x 15 x 2000 mm, Steel,
GTIN (EAN)	4008190066307	galvanic zinc plated and passivated
Qty.	2 m	

**TS 32****TS 32**

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

**General ordering data**

Type	EWK 2	Version
Order No.	<a href="#">0199360000</a>	End bracket, Wemid, beige, Rail: TS 32, when screwed in
GTIN (EAN)	4008190023546	
Qty.	50 pc(s).	