

**RIM 2 6/24VDC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image****General ordering data**

Version	RIDERSERIES RCL, LED module with freewheel diode, Rated control voltage: 6...24 V DC, Plug-in connection
Order No.	<a href="#">8690950000</a>
Type	RIM 2 6/24VDC
GTIN (EAN)	4032248361632
Qty.	20 pc(s).

**RIM 2 6/24VDC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	34.5 mm	Depth (inches)	1.358 inch
Height	9 mm	Height (inches)	0.354 inch
Width	12.5 mm	Width (inches)	0.492 inch
Net weight	1.6 g		

**Temperatures**

Storage temperature	-40 °C...70 °C	Operating temperature	-40 °C...70 °C
Humidity	40 °C / 93 % rel. humidity, no condensation		

**Control side**

Rated control voltage	6...24 V DC	Status indicator	red LED
Protective circuit	Free-wheeling diode		

**General data**

Colour	black
--------	-------

**Connection data**

Wire connection method	Plug-in connection
------------------------	--------------------

**Classifications**

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ECLASS 9.1	27-37-10-10	ECLASS 10.0	27-37-10-10
ECLASS 11.0	27-37-16-92	ECLASS 12.0	27-37-16-92
ECLASS 13.0	27-37-16-92		

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
------------	----------------

**Approvals**

ROHS	Conform
------	---------

**Downloads**

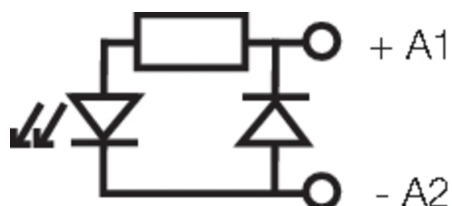
Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**RIM 2 6/24VDC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Drawings****Wiring diagram****Dimensional drawing**