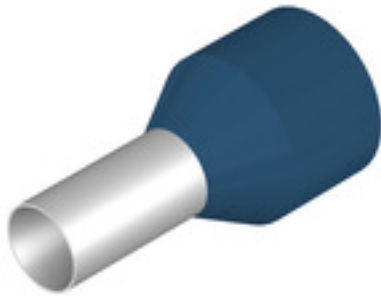


H16,0/25,5X BL SV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- Polypropylene conical cable entry
 - Heat-resistant up to 105°C
- for conductors from 1.5 to 16 mm² (AWG 16-6)
tin-plated copper
dimensional tolerances to DIN 46228 part 4

General ordering data

Version	Wire-end ferrule, Standard, 26 mm, 12 mm, blue
Order No.	9006870000
Type	H16,0/25,5X BL SV
GTIN (EAN)	4008190332327
Qty.	100 pc(s).
Packaging	Multipack bag

H16,0/25,5X BL SV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	0.93 g
------------	--------

Technical data

Description of article	Wire end ferrule for short-circuit-proof and earth-fault-proof lines, blue	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	11.9 mm	Colour code	Weidmueller
Conductor cross-section	16 mm ²	Contact surface diameter (D1)	6 mm
Contact surface length (L2)	12 mm	L1 in mm	25.5 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.3 mm
Stripping length	26 mm	Wire connection cross section AWG, max.	AWG 6

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ECLASS 9.0	27-40-02-01	ECLASS 9.1	27-40-02-01
ECLASS 10.0	27-40-02-01	ECLASS 11.0	27-40-02-01
ECLASS 12.0	27-40-02-01	ECLASS 13.0	27-40-02-01

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

H16,0/25,5X BL SV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Drawing**