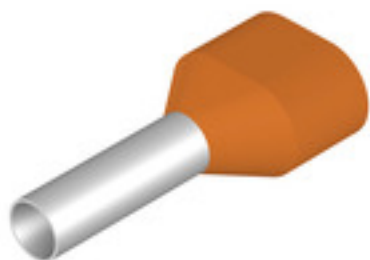


**H4,0/22T ZH OR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

- supplied loose in poly-bag
- DIN colour code
- other colour code

**General ordering data**

|            |   |
|------------|---|
| Version    | Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, orange |
| Order No.  | <a href="#">9037670000</a>                                    |
| Type       | H4,0/22T ZH OR  |
| GTIN (EAN) | 4008190493431   |
| Qty.       | 100 pc(s).  |
| Packaging  | loose   |

## H4,0/22T ZH OR

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

|            |        |
|------------|--------|
| Net weight | 0.48 g |
|------------|--------|

## Technical data

| Description of article | Twin wire end ferrule, or-<br>ange | Version | Twin wire-end ferrule |
|------------------------|------------------------------------|---------|-----------------------|
|------------------------|------------------------------------|---------|-----------------------|

## Wire-end ferrules

|   |               |                             |                   |
|---|---------------|-----------------------------|-------------------|
| Collar height (A)                       | 9 mm          | Collar width (B)            | 5.2 mm            |
| Colour code                             | Telemecanique | Conductor cross-section     | 4 mm <sup>2</sup> |
| Contact surface diameter (D1)           | 3.5 mm        | Contact surface length (L2) | 12 mm             |
| L1 in mm                                | 22 mm         | Metal sleeve thickness (S1) | 0.2 mm            |
| Plastic collar thickness (S2)           | 0.5 mm        | Stripping length            | 15 mm             |
| Wire connection cross section AWG, max. | AWG 12        |                             |                   |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC000005    | ETIM 7.0    | EC000005    |
| ETIM 8.0    | EC000005    | ETIM 9.0    | EC000005    |
| ECLASS 9.0  | 27-40-02-01 | ECLASS 9.1  | 27-40-02-01 |
| ECLASS 10.0 | 27-40-02-01 | ECLASS 11.0 | 27-40-02-01 |
| ECLASS 12.0 | 27-40-02-01 | ECLASS 13.0 | 27-40-02-01 |

## Approvals

Approvals



|                         |            |
|-------------------------|------------|
| ROHS                    | Conform    |
| UL File Number Search   | UL Website |
| Certificate no. (cULus) | E499744    |

## Downloads

|                    |  |
|--------------------|--|
| Engineering Data   | <a href="#">CAD data – STEP</a>  |
| Engineering Data   | <a href="#">Zuken E3.S</a>   |
| User Documentation | <a href="#">Technical information - EN</a><br><a href="#">Technical information - DE</a> |
| Catalogues         | <a href="#">Catalogues in PDF-format</a>   |
| Brochures          |  |

**H4,0/22T ZH OR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Drawings****Drawing**