

**MULTI-STRIPAX 16 SL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

**General ordering data**

|            |                                   |
|------------|-----------------------------------|
| Version    | Tools, Stripping and cutting tool |
| Order No.  | <a href="#">9202220000</a>        |
| Type       | MULTI-STRIPAX 16 SL               |
| GTIN (EAN) | 4032248486151                     |
| Qty.       | 1 pc(s).                          |

**MULTI-STRIPAX 16 SL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

|            |        |                 |            |
|------------|--------|-----------------|------------|
| Depth      | 40 mm  | Depth (inches)  | 1.575 inch |
| Height     | 85 mm  | Height (inches) | 3.346 inch |
| Width      | 250 mm | Width (inches)  | 9.842 inch |
| Net weight | 550 g  |                 |            |

**Technical data**

|                        |   |
|------------------------|---|
| Description of article | Stripping and cutting tool for PVC-insulated conductors, 16 mm <sup>2</sup> with special configurations |
|------------------------|---|

**Stripping tools**

|                               |   |  |                     |
|-------------------------------|---|--|---------------------|
| Cable type                    | Flexible and solid conductors with PVC insulation | Conductor cross-section (cutting capacity) | 6 mm <sup>2</sup>   |
| Conductor cross-section, max. | 16 mm <sup>2</sup>                                | Conductor cross-section, min.              | 6 mm <sup>2</sup>   |
| Stripping length, min.        | 2 mm  | Stripping range AWG, max.                  | 6 AWG               |
| Stripping range AWG, min.     | 8 AWG   | max. cutting capacity, fine-strand         | 6 mm <sup>2</sup>   |
| max. cutting capacity, ribbon | 10,2 mm x 4 mm                                    | max. cutting capacity, solid               | 2.5 mm <sup>2</sup> |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC002109    | ETIM 7.0    | EC002109    |
| ETIM 8.0    | EC002109    | ETIM 9.0    | EC002109    |
| ECLASS 9.0  | 21-04-37-06 | ECLASS 9.1  | 21-04-37-06 |
| ECLASS 10.0 | 21-04-37-06 | ECLASS 11.0 | 21-04-37-06 |
| ECLASS 12.0 | 21-04-37-06 | ECLASS 13.0 | 21-04-37-06 |

**Environmental Product Compliance**

|            |                                      |
|------------|--------------------------------------|
| REACH SVHC | Lead 7439-92-1                       |
| SCIP       | cf06c250-ed1e-4a45-9c1b-c5c8cbf13bf0 |

**Downloads**

|                    |  |
|--------------------|--|
| User Documentation | <a href="#">Manual</a>                   |
| Catalogues         | <a href="#">Catalogues in PDF-format</a> |
| Brochures          |  |

### MULTI-STRIPAX 16 SL

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Example of use



## MULTI-STRIPAX 16 SL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Accessories / replacement parts

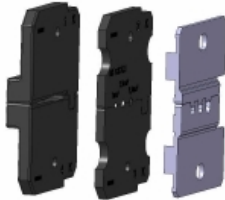

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

## General ordering data

|            |                            |                     |
|------------|----------------------------|---------------------|
| Type       | AIE MULTI-STRIPAX ASI      | Version             |
| Order No.  | <a href="#">9202300000</a> | Insert              |
| GTIN (EAN) | 4032248486250              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | ERAN MULTI-STRIPAX         | Version             |
| Order No.  | <a href="#">9203100000</a> | Spare stop set      |
| GTIN (EAN) | 4032248538102              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | AIE MULTI-STRIPAX PV       | Version             |
| Order No.  | <a href="#">1204280000</a> | Insert              |
| GTIN (EAN) | 4032248987030              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | AIE M-SPX 1.5-6.0 S        | Version             |
| Order No.  | <a href="#">9204570000</a> | Insert              |
| GTIN (EAN) | 4032248671113              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | AIE MULTI-STRIPAX GKWLW    | Version             |
| Order No.  | <a href="#">9205770000</a> | Insert              |
| GTIN (EAN) | 4032248836291              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | AIE MULTI-STRIPAX POF      | Version             |
| Order No.  | <a href="#">1212770000</a> | Insert              |
| GTIN (EAN) | 4032248994434              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | ERME MULTI-STRIPAX         | Version             |
| Order No.  | <a href="#">9203070000</a> | Spare cutting blade |
| GTIN (EAN) | 4032248538096              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | AIE MULTI-SPX 0.75-4°SL    | Version             |
| Order No.  | <a href="#">9203730000</a> | Insert              |
| GTIN (EAN) | 4032248576449              |                     |
| Qty.       | 1 pc(s).                   |                     |
| Type       | AIE MULTI-STRIPAX 16 SL    | Version             |
| Order No.  | <a href="#">9202270000</a> | Insert              |
| GTIN (EAN) | 4032248486212              |                     |
| Qty.       | 1 pc(s).                   |                     |

Creation date April 29, 2024 10:01:10 PM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.

**MULTI-STRIPAX 16 SL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

|            |                            |         |
|------------|----------------------------|---------|
| Type       | AIE MULTI-STRIPAX AWG      | Version |
| Order No.  | <a href="#">9202280000</a> | Insert  |
| GTIN (EAN) | 4032248486236              |         |
| Qty.       | 1 pc(s).                   |         |
| Type       | AIE M-SPX 0.25-1.5 S       | Version |
| Order No.  | <a href="#">9204550000</a> | Insert  |
| GTIN (EAN) | 4032248671090              |         |
| Qty.       | 1 pc(s).                   |         |
| Type       | AIE MULTI-STRIPAX 6-16     | Version |
| Order No.  | <a href="#">9202260000</a> | Insert  |
| GTIN (EAN) | 4032248486205              |         |
| Qty.       | 1 pc(s).                   |         |