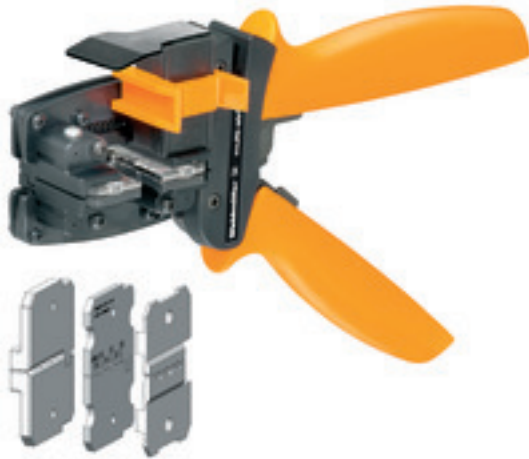


**MULTI-STRIPAX AWG****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

**General ordering data**

Version	Tools, Stripping and cutting tool
Order No.	<a href="#">9202230000</a>
Type	MULTI-STRIPAX AWG
GTIN (EAN)	4032248486168
Qty.	1 pc(s).

**MULTI-STRIPAX AWG****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Depth	40 mm	Depth (inches)	1.575 inch
Height	85 mm	Height (inches)	3.346 inch
Width	250 mm	Width (inches)	9.842 inch
Net weight	520.28 g		

**Technical data**

Description of article	Stripping and cutting tool for AWG conductors with PVC and PTFE etc. insulation
------------------------	---

**Stripping tools**

Cable type	AWG conductor with PTFE and PVC insulation	Conductor cross-section (cutting capacity)	6 mm <sup>2</sup>
Conductor cross-section, max.	6 mm <sup>2</sup>	Conductor cross-section, min.	0.12 mm <sup>2</sup>
Copper cable - flexible, max.	6 mm <sup>2</sup>	Stripping length, min.	2 mm
Stripping range AWG, max.	16 AWG	Stripping range AWG, min.	26 AWG
max. cutting capacity, fine-strand	6 mm <sup>2</sup>	max. cutting capacity, ribbon	10,2 mm x 4 mm
max. cutting capacity, solid	2.5 mm <sup>2</sup>		

**Classifications**

ETIM 6.0	EC002109	ETIM 7.0	EC002109
ETIM 8.0	EC002109	ETIM 9.0	EC002109
ECLASS 9.0	21-04-37-06	ECLASS 9.1	21-04-37-06
ECLASS 10.0	21-04-37-06	ECLASS 11.0	21-04-37-06
ECLASS 12.0	21-04-37-06	ECLASS 13.0	21-04-37-06

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
SCIP	cf06c250-ed1e-4a45-9c1b-c5c8cbf13bf0

**Downloads**

User Documentation	<a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

### MULTI-STRIPAX AWG

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Example of use



## MULTI-STRIPAX AWG

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Accessories / replacement parts

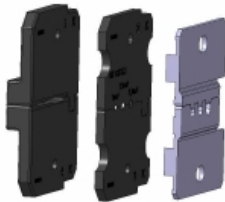

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

## General ordering data

Type	AIE MULTI-STRIPAX 6-16	Version
Order No.	<a href="#">9202260000</a>	Insert
GTIN (EAN)	4032248486205	
Qty.	1 pc(s).	
Type	AIE MULTI-SPX 0.75-4²SL	Version
Order No.	<a href="#">9203730000</a>	Insert
GTIN (EAN)	4032248576449	
Qty.	1 pc(s).	
Type	AIE MULTI-STRIPAX AWG	Version
Order No.	<a href="#">9202280000</a>	Insert
GTIN (EAN)	4032248486236	
Qty.	1 pc(s).	
Type	AIE MULTI-STRIPAX PV	Version
Order No.	<a href="#">1204280000</a>	Insert
GTIN (EAN)	4032248987030	
Qty.	1 pc(s).	
Type	AIE MULTI-STRIPAX ASI	Version
Order No.	<a href="#">9202300000</a>	Insert
GTIN (EAN)	4032248486250	
Qty.	1 pc(s).	
Type	AIE MULTI-STRIPAX POF	Version
Order No.	<a href="#">1212770000</a>	Insert
GTIN (EAN)	4032248994434	
Qty.	1 pc(s).	
Type	ERME MULTI-STRIPAX	Version
Order No.	<a href="#">9203070000</a>	Spare cutting blade
GTIN (EAN)	4032248538096	
Qty.	1 pc(s).	
Type	AIE M-SPX 0.25-1.5 S	Version
Order No.	<a href="#">9204550000</a>	Insert
GTIN (EAN)	4032248671090	
Qty.	1 pc(s).	
Type	AIE MULTI-STRIPAX GKWLW	Version
Order No.	<a href="#">9205770000</a>	Insert
GTIN (EAN)	4032248836291	
Qty.	1 pc(s).	

Creation date April 29, 2024 9:34:55 PM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.

**MULTI-STRIPAX AWG****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

Type	AIE MULTI-STRIPAX 16 SL	Version
Order No.	<a href="#">9202270000</a>	Insert
GTIN (EAN)	4032248486212	
Qty.	1 pc(s).	
Type	ERAN MULTI-STRIPAX	Version
Order No.	<a href="#">9203100000</a>	Spare stop set
GTIN (EAN)	4032248538102	
Qty.	1 pc(s).	
Type	AIE M-SPX 1.5-6.0 S	Version
Order No.	<a href="#">9204570000</a>	Insert
GTIN (EAN)	4032248671113	
Qty.	1 pc(s).	