

MULTI-STRIPAX 0.25-1.5S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

General ordering data

| | |
|------------|-----------------------------------|
| Version | Tools, Stripping and cutting tool |
| Order No. | 9204540000 |
| Type | MULTI-STRIPAX 0.25-1.5S |
| GTIN (EAN) | 4032248671083 |
| Qty. | 1 pc(s). |

MULTI-STRIPAX 0.25-1.5S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

| | | | |
|------------|--------|-----------------|------------|
| Depth | 40 mm | Depth (inches) | 1.575 inch |
| Height | 85 mm | Height (inches) | 3.346 inch |
| Width | 250 mm | Width (inches) | 9.842 inch |
| Net weight | 556 g | | |

Technical data

| | |
|------------------------|---|
| Description of article | Stripping and cutting tool for VDE cables with PVC insulation, 0.25 - 1.5 mm ² |
|------------------------|---|

Stripping tools

| | | | |
|-------------------------------|---|--|---------------------|
| Cable type | Flexible and solid conductors with PVC insulation | Conductor cross-section (cutting capacity) | 6 mm ² |
| Conductor cross-section, max. | 1.5 mm ² | Conductor cross-section, min. | 25 mm ² |
| Stripping length, min. | 2 mm | Stripping range AWG, max. | 14 AWG |
| Stripping range AWG, min. | 23 AWG | max. cutting capacity, fine-strand | 6 mm ² |
| max. cutting capacity, ribbon | 10,2 mm x 4 mm | max. cutting capacity, solid | 2.5 mm ² |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC002109 | ETIM 7.0 | EC002109 |
| ETIM 8.0 | EC002109 | ETIM 9.0 | EC002109 |
| ECLASS 9.0 | 21-04-37-06 | ECLASS 9.1 | 21-04-37-06 |
| ECLASS 10.0 | 21-04-37-06 | ECLASS 11.0 | 21-04-37-06 |
| ECLASS 12.0 | 21-04-37-06 | ECLASS 13.0 | 21-04-37-06 |

Environmental Product Compliance

| | |
|------------|--------------------------------------|
| REACH SVHC | Lead 7439-92-1 |
| SCIP | cf06c250-ed1e-4a45-9c1b-c5c8cbf13bf0 |

Downloads

| | |
|--------------------|--|
| User Documentation | Manual |
| Catalogues | Catalogues in PDF-format |
| Brochures | |

MULTI-STRIPAX 0.25-1.5S

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Example of use



MULTI-STRIPAX 0.25-1.5S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Accessories / replacement parts

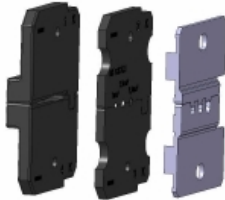

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

General ordering data

| | | |
|------------|----------------------------|---------------------|
| Type | AIE M-SPX 0.25-1.5 S | Version |
| Order No. | 9204550000 | Insert |
| GTIN (EAN) | 4032248671090 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-SPX 0.75-4²SL | Version |
| Order No. | 9203730000 | Insert |
| GTIN (EAN) | 4032248576449 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-STRIPAX POF | Version |
| Order No. | 1212770000 | Insert |
| GTIN (EAN) | 4032248994434 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-STRIPAX ASI | Version |
| Order No. | 9202300000 | Insert |
| GTIN (EAN) | 4032248486250 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-STRIPAX PV | Version |
| Order No. | 1204280000 | Insert |
| GTIN (EAN) | 4032248987030 | |
| Qty. | 1 pc(s). | |
| Type | AIE M-SPX 1.5-6.0 S | Version |
| Order No. | 9204570000 | Insert |
| GTIN (EAN) | 4032248671113 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-STRIPAX 16 SL | Version |
| Order No. | 9202270000 | Insert |
| GTIN (EAN) | 4032248486212 | |
| Qty. | 1 pc(s). | |
| Type | ERME MULTI-STRIPAX | Version |
| Order No. | 9203070000 | Spare cutting blade |
| GTIN (EAN) | 4032248538096 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-STRIPAX AWG | Version |
| Order No. | 9202280000 | Insert |
| GTIN (EAN) | 4032248486236 | |
| Qty. | 1 pc(s). | |

Creation date April 29, 2024 1:28:01 PM CEST

Catalogue status 20.04.2024 / We reserve the right to make technical changes.

MULTI-STRIPAX 0.25-1.5S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories**

| | | |
|------------|----------------------------|----------------|
| Type | AIE MULTI-STRIPAX GKWLW | Version |
| Order No. | 9205770000 | Insert |
| GTIN (EAN) | 4032248836291 | |
| Qty. | 1 pc(s). | |
| Type | ERAN MULTI-STRIPAX | Version |
| Order No. | 9203100000 | Spare stop set |
| GTIN (EAN) | 4032248538102 | |
| Qty. | 1 pc(s). | |
| Type | AIE MULTI-STRIPAX 6-16 | Version |
| Order No. | 9202260000 | Insert |
| GTIN (EAN) | 4032248486205 | |
| Qty. | 1 pc(s). | |