

MPC 12/17/07 7035**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

Small and medium-sized polycarbonate enclosures

The polycarbonate enclosures of the MPC series are ideal for building into electrical, electromechanical and pneumatic devices as well as PCBs. The enclosures are used in situations with extreme mechanical and chemical conditions.

Features:

- 17 sizes in 2 versions
- Grey or transparent cover
- Cover with lead-seal holes
- Mounting holes outside the seal area
- Receptacle threads for rail mounting, mounting plates and circuit board
- Comprehensive accessories
- Weidmüller can manufacture and supply the enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

General ordering data

Version	MPC (polycarbonate empty enclosure), Empty enclosure, Height: 125 mm, Width: 175 mm, Depth: 75 mm, Material: Polycarbonate, untreated, Light Grey
Order No.	9535290000
Type	MPC 12/17/07 7035
GTIN (EAN)	4032248009183
Qty.	1 pc(s).

MPC 12/17/07 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	75 mm	Depth (inches)	2.953 inch
Height	125 mm	Height (inches)	4.921 inch
Width	175 mm	Width (inches)	6.89 inch
Net weight	373 g		

Temperatures

Operating temperature	-50 °C...130 °C
-----------------------	-----------------

Cable glands, right

M12	6	M16	4
M20	4		

Cable glands, top/bottom

M12	4	M16	3
M20	3		

General information

Access opening: height	121.5 mm	Access opening: width	171.5 mm
Areas of use	Building systems and technology, Transportation, Packaging industry, Machine construction	Enclosure attachment	
Flange plate	No	Impact resistance	Holes 4.5 mm IK08
Installation advice	Screw mounting	Integral fixing	thanks to self-tapping screws
Lid	Yes	Lid attachment	4 polyamide crosshead screws
Material	Polycarbonate	Material thickness	3.5 mm
Number of lid screws	4	Operating temperature, max.	130 °C
Operating temperature, min.	-50 °C	Protection degree	IP66, IP67
Seal material	Polyurethane	Surface finish	untreated
Torque for lid screws	0.8 Nm		

horizontal assembly

WDU 10 / ZDU 10	1x11	WDU 2,5 / ZDU 2,5 / IDU 2,5	1x22
WDU 4 / ZDU 4	1x19	WDU 6 / ZDU 6	1x14

vertical assembly

WDU 10 / ZDU 10	1x11	WDU 2,5 / ZDU 2,5 / IDU 2,5	1x22
WDU 4 / ZDU 4	1x19	WDU 6 / ZDU 6	1x14

Classifications

ETIM 6.0	EC000261	ETIM 7.0	EC000261
ETIM 8.0	EC000261	ETIM 9.0	EC000261
ECLASS 9.0	27-18-01-01	ECLASS 9.1	27-18-92-90
ECLASS 10.0	27-18-01-01	ECLASS 11.0	27-18-01-01
ECLASS 12.0	27-18-01-01	ECLASS 13.0	27-18-01-01

MPC 12/17/07 7035

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Downloads


Approval/Certificate/Document of Conformity	EU Declaration of Conformity - MPC Empty Enclosures - DoC DE PS2420 201008 001ISS00 EU Declaration of Conformity - Klippon K Terminal Box - DoC DE PS270X 160308 002ISS03
Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	

MPC 12/17/07 7035

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

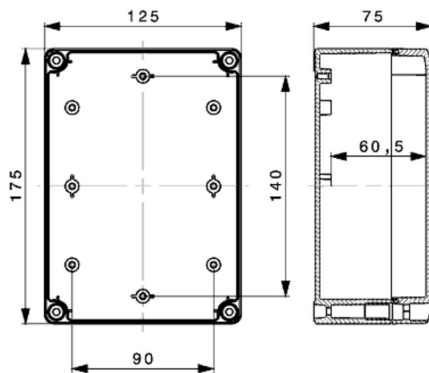

MPC 12/17/07 7035**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****External fixing lugs**

External attachment lugs 4-part set

**General ordering data**

Type	MF MPC	Version	
Order No.	953560000	MPC (polycarbonate empty enclosure), Mounting foot, Fixing lugs,	
GTIN (EAN)	4032248009381	Height: 30 mm, Width: 15 mm, Depth: 10 mm, Material: Plastic	
Qty.	1 pc(s).		

Ventilation plugs - DAE

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	DAE M12 PA LONG	Version	
Order No.	1868570000	DAE (ventilation element), Compensating element, straight, M 12, 10	
GTIN (EAN)	4032248440429	mm, IP66, IP68, IP69K, Polyamide 6	
Qty.	10 pc(s).		
Type	DAE M12 SS	Version	
Order No.	1868550000	DAE (ventilation element), Compensating element, straight, M 12, 10	
GTIN (EAN)	4032248440405	mm, IP66, IP68, IP69K, Stainless steel 1.4305 (303)	
Qty.	10 pc(s).		

MPC 12/17/07 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

MPC

Mounting plates, 1.5 mm sheet steel, galvanised



General ordering data

Type	MP MPC 12/17	Version
Order No.	9535560000	MPC (polycarbonate empty enclosure), Mounting plate, Mounting
GTIN (EAN)	4032248009299	plate, Height: 125 mm, Width: 175 mm, Material: Sheet steel,
Qty.	1 pc(s).	galvanized, galvanized

Earthing stud

Accessories



General ordering data

Type	PEBZ M10 BR SET	Version
Order No.	1277220000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067019	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Brass
Type	PEBZ M6 S4 SET	Version
Order No.	1283430000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073607	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)
Type	PEBZ M10 S4 SET	Version
Order No.	1283440000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073362	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)
Type	PEBZ M6 BR SET	Version
Order No.	1277250000	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067149	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Brass

MPC 12/17/07 7035**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****TS 35**

Accessories

**General ordering data**

Type	TS35X7.5 ST MPC1725 VER	Version
Order No.	8000037600	Rail, TS 35, TS 35 x 7.5, Width: 90 mm, without slot, Steel, galvanic
GTIN (EAN)	4050118653120	zinc plated and passivated
Qty.	20 pc(s).	

Screws

Depending on the terminal block or also accessories, we offer different types of screws as additional items or also spare parts.

General ordering data

Type	FKSC M4X6 D8/SW2	Version
Order No.	1567480000	SAK Series, Allen hex screw, Screws, Number of poles: 1
GTIN (EAN)	4008190033491	
Qty.	100 pc(s).	

MPC 12/17/07 7035

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Fixing Material

Accessories



General ordering data

Type	SC MPC	Version
Order No.	9535640000	MPC (polycarbonate empty enclosure), Mounting screw, Screws,
GTIN (EAN)	4032248009428	Height: 12.5 mm, Width: 7 mm, Depth: 12.5 mm, Material: Steel,
Qty.	100 pc(s).	galvanised

Hinge

MPC series, hinges, set of 2



General ordering data

Type	HG MPC	Version
Order No.	9535590000	MPC (polycarbonate empty enclosure), External joint, Hinge, Material:
GTIN (EAN)	4032248009329	Plastic
Qty.	1 pc(s).	

MPC 12/17/07 7035**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****TS 15**

Accessories

**General ordering data**

Type	TS15X5 ST MPC1217 VER	Version
Order No.	8000037598	Rail, TS 15, Width: 4.13 mm, without slot, Steel, galvanized,
GTIN (EAN)	4050118653106	chromium-plated
Qty.	20 pc(s).	